

**TS 32X15 2M/CRN****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Product image**

Stainless steel is a collective term for all types of steel (alloys) with a high degree of purity and corrosion resistance.

**General ordering data**

|            |   |
|------------|---|
| Version    | Terminal rail, without slot, Accessories, 33 x 15 x 2000 mm, Stainless steel, rust-proof, untreated |
| Order No.  | <a href="#">0293220000</a>  |
| Type       | TS 32X15 2M/CRN   |
| GTIN (EAN) | 4032248014026   |
| Qty.       | 2 m   |

## TS 32X15 2M/CRN

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

|            |          |                 |            |
|------------|----------|-----------------|------------|
| Depth      | 15 mm    | Depth (inches)  | 0.591 inch |
| Height     | 33 mm    | Height (inches) | 1.299 inch |
| Width      | 2,000 mm | Width (inches)  | 78.74 inch |
| Net weight | 701 g    |                 |            |

## Mounting rail

|                             |                             |          |
|-----------------------------|-----------------------------|----------|
| Installation advice         | Direct mounting             |          |
| Length of the terminal rail | min.                        | 0 mm     |
|                             | nominal                     | 2,000 mm |
|                             | max.                        | 2,000 mm |
| Material                    | Stainless steel, rust-proof |          |
| Pre-punched mounting rail   | No                          |          |
| Slit gap                    |                             |          |
| Slit length                 |                             |          |
| Slit width                  |                             |          |
| Standards                   | DIN EN 60715                |          |
| Surface finish              | untreated                   |          |
| Thickness                   | 1.5 mm                      |          |

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC001285    | ETIM 7.0    | EC001285    |
| ETIM 8.0    | EC001285    | ETIM 9.0    | EC001285    |
| ECLASS 9.0  | 27-40-06-02 | ECLASS 9.1  | 27-40-06-02 |
| ECLASS 10.0 | 27-40-06-02 | ECLASS 11.0 | 27-40-06-02 |
| ECLASS 12.0 | 27-40-06-02 | ECLASS 13.0 | 27-40-06-02 |

## Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

## Downloads

|                    |   |
|--------------------|---|
| Engineering Data   | <a href="#">CAD data – STEP</a>                 |
| Engineering Data   | <a href="#">Zuken E3.S</a>                      |
| User Documentation | <a href="#">StorageConditionsTerminalBlocks</a> |
| Catalogues         | <a href="#">Catalogues in PDF-format</a>        |
| Brochures          |   |

### TS 32X15 2M/CRN

**Weidmüller Interface GmbH & Co. KG**


Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

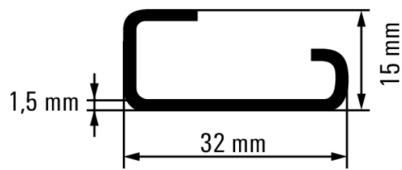

**TS 32X15 2M/CRN****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Screws**

Depending on the terminal block or also accessories, we offer different types of screws as additional items or also spare parts.

**General ordering data**

|            |                            |   |
|------------|----------------------------|---|
| Type       | FKSC M5X8 D9/SW2.5         | Version   |
| Order No.  | <a href="#">0295900000</a> | SAK Series, Allen hex screw, Screws, Number of poles: 1 |
| GTIN (EAN) | 4008190133337              |   |
| Qty.       | 50 pc(s).                  |   |