

**HDC IP68 24B COVER****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The new RockStar® enclosures are resistant to seawater and offer a high degree of shock resistance, meet IP 68 and IP 69K, and have been developed for use under extreme environmental conditions and designed for the high vibration requirements acc. to DIN EN 61373 cat. 2 (bogie). As such, this housing family is ideally suited for fault- and maintenance-free operation of heavy-duty connectors in transport and traffic engineering as well as in power engineering and in applications with extreme requirements. During development, measures were also implemented to make the enclosures extremely EMC-resistant.

**General ordering data**

|            |   |
|------------|---|
| Version    | HDC enclosures, Size: 8, Protection degree: IP66 (in plugged condition), IP68 (in plugged condition), Cover for lower part of housing, Clamping yoke connection, Standard |
| Order No.  | <a href="#">1083090000</a>  |
| Type       | HDC IP68 24B COVER  |
| GTIN (EAN) | 4032248846726   |
| Qty.       | 1 pc(s).  |

## HDC IP68 24B COVER

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

|            |        |                 |            |
|------------|--------|-----------------|------------|
| Depth      | 191 mm | Depth (inches)  | 7.52 inch  |
| Height     | 31 mm  | Height (inches) | 1.22 inch  |
| Width      | 58 mm  | Width (inches)  | 2.283 inch |
| Net weight | 205 g  |                 |            |

## Temperatures

|                   |                   |
|-------------------|-------------------|
| Limit temperature | -50 °C ... 125 °C |
|-------------------|-------------------|

## Dimensions

|                     |       |                      |        |
|---------------------|-------|----------------------|--------|
| Height of housing B | 31 mm | Total length housing | 191 mm |
|---------------------|-------|----------------------|--------|

## General data

|                             |                             |                       |  |
|-----------------------------|-----------------------------|-----------------------|--|
| EMC housings                | Yes                         | Housing main material | diecast aluminium  |
| Material of locking element |                             | Protection degree     | IP66 (in plugged condition), IP68 (in plugged condition) |
|                             | Stainless steel, rust-proof |                       |  |
| Surface finish              | Powder coating              | Tightening torque     | 6.5 Nm   |

## Version

|                   |                                 |                          |                          |
|-------------------|---------------------------------|--------------------------|--------------------------|
| BG                | 8                               | Clamp version            | Clamping yoke connection |
| Colour (RAL)      | RAL 9011, RAL 9005              | Design                   | Standard                 |
| Design of housing | Cover for lower part of housing | Design of locking system | Clamping yoke connection |
| Size              | 8                               | Suitable for ModuPlug®   | Yes                      |
| Tightening torque | 6.5 Nm                          | Top part/bottom part/lid | Cover                    |
| Type              | Cover                           |                          |                          |

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC000437    | ETIM 7.0    | EC000437    |
| ETIM 8.0    | EC000437    | ETIM 9.0    | EC000437    |
| ECLASS 9.0  | 27-44-02-02 | ECLASS 9.1  | 27-44-02-02 |
| ECLASS 10.0 | 27-44-02-02 | ECLASS 11.0 | 27-44-02-02 |
| ECLASS 12.0 | 27-44-02-02 | ECLASS 13.0 | 27-44-02-02 |

|                     |                         |
|---------------------|-------------------------|
| Substance           | Acetone                 |
| Chemical resistance | Resistant               |
| Substance           | Diesel oil              |
| Chemical resistance | Unstable                |
| Substance           | Ethyl alcohol           |
| Chemical resistance | Resistant               |
| Substance           | Transmission oil        |
| Chemical resistance | Conditionally resistant |
| Substance           | Hydraulic oil           |
| Chemical resistance | Conditionally resistant |
| Substance           | Petroleum benzine       |

**HDC IP68 24B COVER****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data**

|                     |                         |
|---------------------|-------------------------|
| Chemical resistance | Unstable                |
| Substance           | Sweat                   |
| Chemical resistance | Conditionally resistant |
| Substance           | Premium gasoline        |
| Chemical resistance | Unstable                |
| Substance           | Water                   |
| Chemical resistance | Resistant               |
| Substance           | UV                      |
| Chemical resistance | Resistant               |
| Substance           | Ozone                   |
| Chemical resistance | Resistant               |

**Approvals**

Approvals



ROHS

Conform

**Downloads**

Approval/Certificate/Document of Conformity

[Manufacturer's declaration](#)

Engineering Data

[CAD data – STEP](#)

Product Change Notification

[20220214 Technical change to HDC housings](#)[20220214 Technische Änderung bei HDC-Gehäusen](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures


[FL FIELDWIRING EN](#)[FL FIELDWIRING EN](#)

## HDC IP68 24B COVER

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

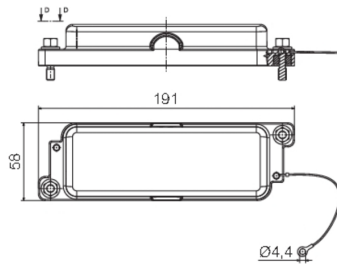

**HDC IP68 24B COVER****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Socket wrench sets**

Allen key made from fully hardened, high-alloy chromium-vanadium- steel, acc. to DIN ISO 2936 L (DIN 911), high-quality refined surface.

**General ordering data**

|            |                            |               |
|------------|----------------------------|---------------|
| Type       | SK WSD-S 1,5-10,0          | Version       |
| Order No.  | <a href="#">9008850000</a> | Mounting tool |
| GTIN (EAN) | 4032248266609              |               |
| Qty.       | 1 pc(s).                   |               |