

IE-PIC-HYB-S-0,5-300**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14

General ordering data

Version	Crimp contact, for plug insert, Hybrid
Order No.	1096180000
Type	IE-PIC-HYB-S-0,5-300
GTIN (EAN)	4032248869152
Qty.	300 pc(s).

IE-PIC-HYB-S-0,5-300**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Net weight	0.27 g
------------	--------

General data

Wire connection cross section, finely stranded, max.	0.5 mm ²	Wire connection cross section, finely stranded, min.	0.2 mm ²
Wire cross-section, finely stranded, max. (AWG)	AWG 20	Wire cross-section, finely stranded, min. (AWG)	AWG 24

Electrical properties

Rated voltage	24 V
---------------	------

Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ETIM 9.0	EC001121
ECLASS 9.0	27-44-03-90	ECLASS 9.1	27-44-09-90
ECLASS 10.0	27-44-03-90	ECLASS 11.0	27-44-03-90
ECLASS 12.0	27-44-03-90	ECLASS 13.0	27-44-03-90

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	67cf1078-beca-4687-860b-dc475a6ec24a

Important note

Product information	Hybrid, 10-pole. Inserts for plug-in connectors Variant 14
---------------------	--

Approvals

ROHS	Conform
------	---------

Downloads

Approval/Certificate/Document of Conformity	PROFINET Manufacturer's Declaration
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN PI PROFINET CABLING EN FL FIELDWIRING EN PI PROFINET CABLING EN


IE-PIC-HYB-S-0,5-300

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

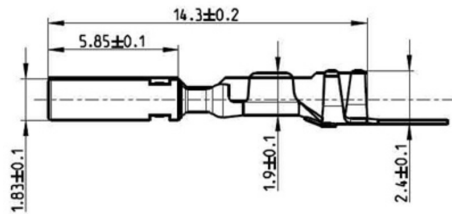

IE-PIC-HYB-S-0,5-300

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories**Crimping tools****Crimping tools for Weidmüller contacts for RSV and DSTV-HD systems**

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation
- With end stop for exact positioning of the contacts

General ordering data

Type	HTF HYB	Version
Order No.	1119580000	Pressing tool, Crimping tool for contacts, 0.08mm ² , 1mm ² ,
GTIN (EAN)	4032248900626	FoderBcrimp
Qty.	1 pc(s).	