

IE-CD-V14MSCRJ-MM-C-MA**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Coupling FreeCon design for Fibre-optic plug-in connectors PushPull Var.14 according to IEC 61076-3-117, metal

General ordering data

Version	Junction box, FreeCon, SCRJ, Plug-in connector, IP65
Order No.	1318150000
Type	IE-CD-V14MSCRJ-MM-C-MA
GTIN (EAN)	4050118123982
Qty.	1 pc(s).

IE-CD-V14MSCRJ-MM-C-MA**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Depth	43.9 mm	Depth (inches)	1.728 inch
Height	52 mm	Height (inches)	2.047 inch
Width	41 mm	Width (inches)	1.614 inch
Net weight	224.56 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Colour	silver	Housing main material	Aluminium profile, Cover: die-cast zinc, painted
Protection degree	IP65	Type of mounting	Screw mounting

General standards

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-117 Var. 14, IEC 61754-24
-------------------------	---------	--------------------	---------------------------------------

Optical properties of fibre-optic coupling

Insertion attenuation (fibre-optic coupling)	<0.2 dB
--	---------

Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-03-92
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Approvals

Approvals



UL File Number Search	UL Website
Certificate no. (cULus)	E316369

Downloads

Approval/Certificate/Document of Conformity	PROFINET Manufacturer's Declaration
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN

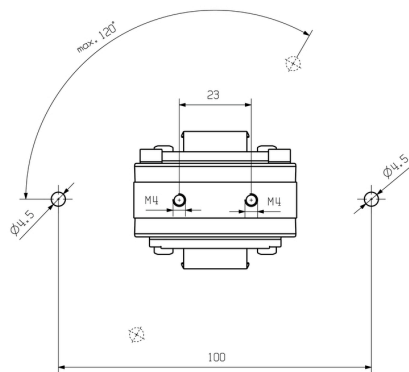
Creation date April 26, 2024 10:01:36 AM CEST

Catalogue status 20.04.2024 / We reserve the right to make technical changes.

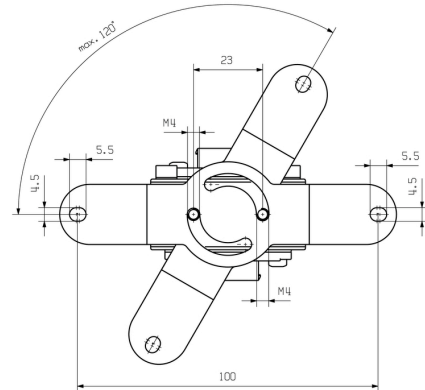
IE-CD-V14MSCRJ-MM-C-MA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

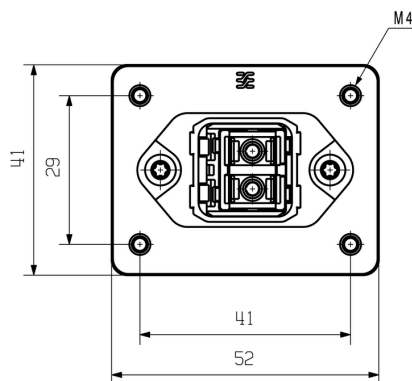
www.weidmueller.com

Drawings
Dimensioned drawing


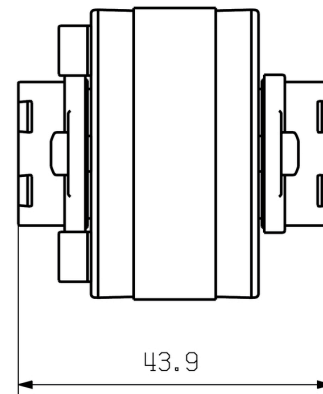
Bottom view

Dimensioned drawing


Bottom view with mounting foot

Dimensioned drawing


Front view

Dimensioned drawing


Side view

IE-CD-V14MSCRJ-MM-C-MA**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Dust caps**

For protecting your devices against dust and dirt.

General ordering data

Type	IE-BP-V14P	Version
Order No.	1058310000	Flange-mounted housing, protective cap
GTIN (EAN)	4032248799404	
Qty.	10 pc(s).	

SC-RJPushPull plug-in connector set according to IEC
61076-3-117 ver. 14 (PROFINET), metal incl. SC insert**General ordering data**

Type	IE-PS-V14M-2SC-POF	Version
Order No.	1191550000	FO connector, Version 14, SC-RJ POF, IP67
GTIN (EAN)	4032248974436	
Qty.	10 pc(s).	