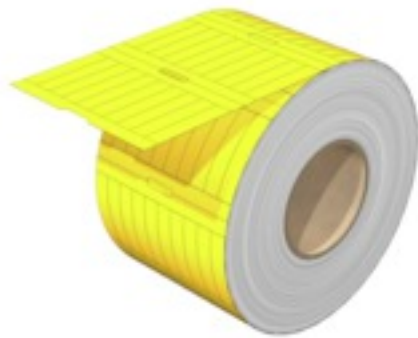


**ELS 6/30 MM GE****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**ELS**

ELS tags are special and non-adhesive insertable labels for WKM cable markers or for group tag carriers. The matt, thin but tear-resistant polyester provides very good labelling and excellent readability. Used in combination with water-repellent WKM sleeves, the solution guarantees particularly long-lasting identification of cables even in harsh environments.

**General ordering data**

|                    |   |
|--------------------|---|
| Version            | ELS, Insert markers, 30 x 6 mm, yellow                |
| Order No.          | <a href="#">2010620000</a>                            |
| Type               | ELS 6/30 MM GE  |
| GTIN (EAN)         | 4050118397178   |
| Qty.               | 3,000 pc(s).  |
| compatible printer | <a href="#">2599430000</a> <a href="#">2599440000</a> |

## ELS 6/30 MM GE

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

|            |         |                 |            |
|------------|---------|-----------------|------------|
| Depth      | 0.14 mm | Depth (inches)  | 0.006 inch |
| Height     | 30 mm   | Height (inches) | 1.181 inch |
| Width      | 6 mm    | Width (inches)  | 0.236 inch |
| Net weight | 0.06 g  |                 |            |

## Temperatures

|                             |              |
|-----------------------------|--------------|
| Operating temperature range | -40...150 °C |
|-----------------------------|--------------|

## General data

|                                   |              |                                   |        |
|-----------------------------------|--------------|-----------------------------------|--------|
| Colour                            | yellow       | Halogen                           | No     |
| Material                          | Polyester    | Number per roll                   | 3,000  |
| Operating temperature range       | -40...150 °C | Operating temperature range, max. | 150 °C |
| Operating temperature range, min. | -40 °C       | UL 94 flammability rating         | HB     |
| Version                           | halogen-free | Width                             | 6 mm   |

## Conductor and cable markers

|         |    |
|---------|----|
| Halogen | No |
|---------|----|

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC001530    | ETIM 7.0    | EC001530    |
| ETIM 8.0    | EC001530    | ETIM 9.0    | EC001530    |
| ECLASS 9.0  | 27-40-04-01 | ECLASS 9.1  | 27-40-04-01 |
| ECLASS 10.0 | 27-40-04-01 | ECLASS 11.0 | 27-28-11-02 |
| ECLASS 12.0 | 27-28-11-02 | ECLASS 13.0 | 27-28-11-02 |

## Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

## Downloads

|                  |  |
|------------------|--|
| Engineering Data | <a href="#">CAD data – STEP</a>          |
| Engineering Data | <a href="#">Zuken E3.S</a>               |
| Catalogues       | <a href="#">Catalogues in PDF-format</a> |

**ELS 6/30 MM GE**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

