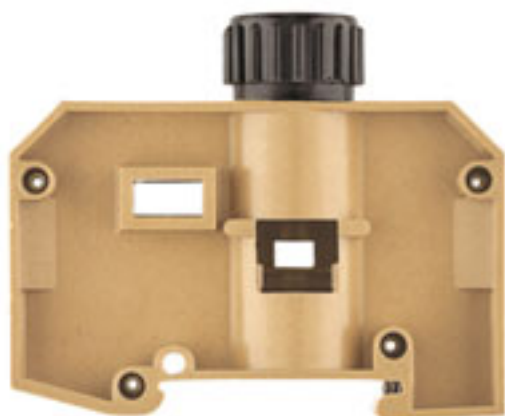


SAKS 4/35 USA**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Product image****General ordering data**

| | |
|------------|---|
| Version | Fuse terminal, Screw connection, medium yellow, 10 mm ² , 16 A, 400 V, Number of connections: 2, Number of levels: 1, TS 35, V-0, 5VA, KrG, 10 x 38 mm |
| Order No. | 0178220000 |
| Type | SAKS 4/35 USA |
| GTIN (EAN) | 4008190095987 |
| Qty. | 20 pc(s). |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

| | | | |
|--------------------------|------------|----------------|------------|
| Depth | 65 mm | Depth (inches) | 2.559 inch |
| Depth including DIN rail | 66 mm | Height | 75 mm |
| Height (inches) | 2.953 inch | Width | 24 mm |
| Width (inches) | 0.945 inch | Net weight | 79.35 g |

Temperatures

| | | | |
|----------------------------------|----------------|----------------------------------|--------|
| Storage temperature | -25 °C...55 °C | Continuous operating temp., min. | -60 °C |
| Continuous operating temp., max. | 130 °C | | |

Material data

| | | | |
|---------------------------|----------|--------|---------------|
| Material | KrG | Colour | medium yellow |
| UL 94 flammability rating | V-0, 5VA | | |

System specifications

| | | | |
|-------------------------------------|---|-------------------------------|----|
| Version | Screw connection, Fuse cartridge, for screwable cross-connection, One end without connector | End cover plate required | No |
| Number of potentials | 1 | Number of levels | 1 |
| Number of clamping points per level | 2 | Number of potentials per tier | 1 |
| Levels cross-connected internally | No | PE connection | No |
| Rail | TS 35 | N-function | No |
| PE function | No | PEN function | No |

Additional technical data

| | | | |
|-----------------------------|---------|---------------------|-----------------|
| Explosion-tested version | No | Installation advice | Direct mounting |
| Number of similar terminals | 1 | Open sides | closed |
| Type of mounting | Snap-on | | |

CSA rating data

| | | | |
|-------------------------------|-----------|-------------------------------|-------|
| Certificate No. (CSA) | 12400-188 | Current size B (CSA) | 30 A |
| Current size C (CSA) | 30 A | Current size D (CSA) | 5 A |
| Voltage size B (CSA) | 600 V | Voltage size C (CSA) | 600 V |
| Voltage size D (CSA) | 600 V | Wire cross section max. (CSA) | 8 AWG |
| Wire cross section min. (CSA) | 22 AWG | | |

Conductors for clamping (additional connection)

| | | | |
|---|--------------------|--|------------------|
| Conductor cross-section, flexible plus plastic collar DIN 46228/1, further connection, max. | 10 mm ² | Connection type, additional connection | Screw connection |
|---|--------------------|--|------------------|

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Conductors for clamping (rated connection)

| | | | |
|---|---------------------|---|---------------------|
| Blade size | 1.0 x 5.5 mm | Clamping range, max. | 16 mm ² |
| Clamping range, min. | 0.5 mm ² | Clamping screw | M 4 |
| Connection cross-section, stranded, max. | 10 mm ² | Connection cross-section, stranded, min. | 1.5 mm ² |
| Connection direction | on side | Gauge to IEC 60947-1 | B6 |
| Number of connections | 2 | Stripping length | 14 mm |
| Tightening torque, max. | 2.4 Nm | Tightening torque, min. | 1.2 Nm |
| Torque level with DMS electric screwdriver | 4 | Type of connection | Screw connection |
| Type of connection 2 | Screw connection | Wire connection cross section AWG, max. | AWG 8 |
| Wire connection cross section AWG, min. | AWG 20 | Wire connection cross section, finely stranded, max. | 10 mm ² |
| Wire connection cross section, finely stranded, min. | 0.5 mm ² | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, max. | 10 mm ² |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, min. | 0.5 mm ² | Wire connection cross-section, solid core, max. | 16 mm ² |
| Wire connection cross-section, solid core, min. | 0.5 mm ² | | |

Display element

| | |
|-------------------------------|-------|
| Type of voltage for indicator | AC/DC |
|-------------------------------|-------|

Fuse terminals

| | | | |
|--------------------------------|------------------|-------------------------|-------------|
| Cartridge fuse | 10 x 38 mm | Display | Without LED |
| Fuse holder (cartridge holder) | for screw fixing | Operating voltage, max. | 400 V |
| Type of voltage for indicator | AC/DC | | |

General

| | | | |
|---|-----------------|---|--------|
| Installation advice | Direct mounting | Rail | TS 35 |
| Wire connection cross section AWG, max. | AWG 8 | Wire connection cross section AWG, min. | AWG 20 |

Rating data

| | | | |
|---------------------------------|--------------------|--|---------|
| Rated cross-section | 10 mm ² | Rated voltage | 400 V |
| Rated DC voltage | 400 V | Rated current | 16 A |
| Current at maximum wires | 30 A | Volume resistance according to IEC 60947-7-x | 0.56 mΩ |
| Rated impulse withstand voltage | 6 kV | Power loss in accordance with IEC 60947-7-x | 1.82 W |
| Pollution severity | 3 | | |

UL rating data

| | | | |
|---|--------|---|-------|
| Certificate No. (UR) | E60693 | Conductor size Factory wiring max. (UR) | 8 AWG |
| Conductor size Factory wiring min. (UR) | 26 AWG | Conductor size Field wiring max. (UR) | 8 AWG |
| Conductor size Field wiring min. (UR) | 22 AWG | Current size C (UR) | 30 A |
| Voltage size C (UR) | 600 V | | |

SAKS 4/35 USA**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Classifications**

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC000899 | ETIM 7.0 | EC000899 |
| ETIM 8.0 | EC000899 | ETIM 9.0 | EC000899 |
| ECLASS 9.0 | 27-14-11-16 | ECLASS 9.1 | 27-14-11-16 |
| ECLASS 10.0 | 27-14-11-16 | ECLASS 11.0 | 27-14-11-16 |
| ECLASS 12.0 | 27-14-11-16 | ECLASS 13.0 | 27-25-01-13 |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| REACH SVHC | / |
| RoHS Compliance Status | Compliant without exemption |

Important note

| | |
|---------------------|--|
| Product information | The voltage depends on the selected fuse element or the selected indicator light |
|---------------------|--|

Approvals

Approvals



| | |
|-----------------------|------------|
| ROHS | Conform |
| UL File Number Search | UL Website |
| Certificate No. (UR) | E60693 |

Downloads

| | |
|---|---|
| Approval/Certificate/Document of Conformity | Declaration of Conformity |
| User Documentation | StorageConditionsTerminalBlocks |
| Catalogues | Catalogues in PDF-format |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/6 MC SDR | Version |
| Order No. | 1609830000 | Dekafix, Terminal marker, 5 x 6 mm, Pitch in mm (P): 6.00 |
| GTIN (EAN) | 4008190456603 | Weidmueller, To customer specification |
| Qty. | 200 pc(s). | |

Test plugs



Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

General ordering data

| | | |
|------------|----------------------------|---------------------------------------|
| Type | PS 4 F.STB 4 | Version |
| Order No. | 0299600000 | Test adapter (terminal), 230 V |
| GTIN (EAN) | 4008190074043 | |
| Qty. | 20 pc(s). | |
| Type | PS 2.3 RT | Version |
| Order No. | 0180400000 | Test adapter (terminal), 230 V, 20 mA |
| GTIN (EAN) | 4008190060121 | |
| Qty. | 20 pc(s). | |
| Type | PS 2.0 OR | Version |
| Order No. | 0293800000 | Test adapter (terminal), 230 V, 20 mA |
| GTIN (EAN) | 4008190042356 | |
| Qty. | 20 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|--|
| Type | ZS 2.3/4 | Version |
| Order No. | 0249600000 | Plug (terminal), Plug-in connection, red, V-2, Polyamide 66, Number of |
| GTIN (EAN) | 4008190022785 | poles: 4, Width: 6.5 mm, Height: 6.5 mm |
| Qty. | 20 pc(s). | |
| Type | FZS 2/4 RT/80 SAKT4 | Version |
| Order No. | 1276300000 | Plug (terminal), Plug-in connection, red, Number of poles: 1, Width: 9 |
| GTIN (EAN) | 4008190026080 | mm, Height: 9 mm |
| Qty. | 20 pc(s). | |

TS 32



TS 32

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | WEW 32/1 | Version |
| Order No. | 1067600000 | End bracket, dark beige, TS 32, V-2, PA 66 GF 30, Width: 12 mm, 100 |
| GTIN (EAN) | 4008190099657 | °C |
| Qty. | 50 pc(s). | |
| Type | EWK 2 | Version |
| Order No. | 0199360000 | End bracket, beige, TS 32, V-0, Wemid, Width: 15 mm, 100 °C |
| GTIN (EAN) | 4008190023546 | |
| Qty. | 50 pc(s). | |
| Type | EWK 1 | Version |
| Order No. | 0206160000 | End bracket, beige, TS 32, V-0, Wemid, Width: 9 mm, 100 °C |
| GTIN (EAN) | 4008190080020 | |
| Qty. | 50 pc(s). | |
| Type | EWK 1 ALT | Version |
| Order No. | 0495160000 | End bracket, beige, TS 32, V-2, Polyamide 66, Width: 8 mm, 100 °C |
| GTIN (EAN) | 4008190160777 | |
| Qty. | 50 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Cover profiles



Cover profiles provide protection against external impact on functional areas of the terminal blocks or in combination with our support brackets for the entire terminal strip. They provide protection against electric shock caused by accidental contact with live parts due to operation or faults.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | ADP 2/HP2 1M | Version |
| Order No. | 0485300000 | SAK Series, Cover profile, Transparent, 1000 mm |
| GTIN (EAN) | 4008190051716 | |
| Qty. | 1 m | |

Q / SAK



Screwable cross-connections are easy to mount and de mount. Thanks to the big contact surface, even high currents can be transmitted with maximum contact reliability.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | Q 2 SAK10 | Version |
| Order No. | 0457100000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 2, Pitch in mm (P): 9.90, Insulated: No, Width: 16.9 mm |
| GTIN (EAN) | 4008190103545 | |
| Qty. | 50 pc(s). | |
| Type | Q 10 SAK10 | Version |
| Order No. | 0457400000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 10, Pitch in mm (P): 9.90, Insulated: No, Width: 96.1 mm |
| GTIN (EAN) | 4008190016166 | |
| Qty. | 20 pc(s). | |
| Type | Q 3 SAK10 | Version |
| Order No. | 0457200000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 3, Pitch in mm (P): 9.90, Insulated: No, Width: 26.8 mm |
| GTIN (EAN) | 4008190135379 | |
| Qty. | 50 pc(s). | |
| Type | Q 4 SAK10 | Version |
| Order No. | 0457300000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 4, Pitch in mm (P): 9.90, Insulated: No, Width: 36.7 mm |
| GTIN (EAN) | 4008190129750 | |
| Qty. | 50 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/5 MC SDR | Version |
| Order No. | 1609810000 | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190456597 | Weidmueller, To customer specification |
| Qty. | 200 pc(s). | |

W-Series



A partition plate is used for the optical separation of circuits or used for electrical isolation from neighbouring cross-connectors. In contrast to the end plate, the contour can be larger than the adjacent terminal blocks. However, it should not be smaller, as otherwise the required clearance and creepage distances within the application can no longer be maintained.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | WTW EN | Version |
| Order No. | 1058800000 | Partition plate (terminal), dark beige, Height: 86 mm, Width: 3 mm, |
| GTIN (EAN) | 4008190140175 | V-O, Wemid |
| Qty. | 20 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Gauge rings

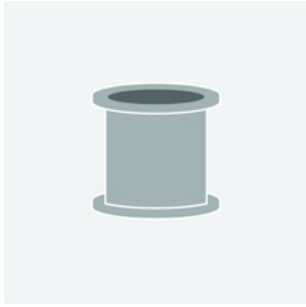


Gauge rings are used to protect against the using of incorrectly selected fuse sizes. They are simply inserted into the respective fuse base and prevent the using of bigger fuses.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | P 14/6 D01 GN SAKS4 | Version |
| Order No. | 0328600000 | Fuse gauge ring (terminal), Height: 11 mm, Depth: 10.5 mm, |
| GTIN (EAN) | 4008190004248 | Aluminium, green |
| Qty. | 50 pc(s). | |
| Type | P 14/10 D01 RT SAKS4 | Version |
| Order No. | 0328700000 | Fuse gauge ring (terminal), Height: 11 mm, Depth: 10.5 mm, |
| GTIN (EAN) | 4008190010294 | Aluminium, red |
| Qty. | 50 pc(s). | |
| Type | P 14/4 D01 BR SAKS4 | Version |
| Order No. | 0138100000 | Fuse gauge ring (terminal), Height: 11 mm, Depth: 10.5 mm, |
| GTIN (EAN) | 4008190077365 | Aluminium, brown |
| Qty. | 50 pc(s). | |
| Type | P 14/2 D01 RS SAKS4 | Version |
| Order No. | 0138000000 | Fuse gauge ring (terminal), Height: 11 mm, Depth: 10.5 mm, |
| GTIN (EAN) | 4008190114664 | Aluminium, pink |
| Qty. | 50 pc(s). | |

Slotted screwdriver

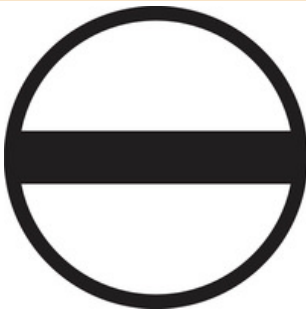

Slotted screwdriver with rounded blade SD DIN 5265, ISO 2380/2, output to DIN 5264, ISO 2380/1. ChromTop tip, SoftFinish grip

General ordering data

| | | |
|------------|----------------------------|--------------------------|
| Type | SDS 1.0X5.5X150 | Version |
| Order No. | 9008350000 | Screwdriver, Screwdriver |
| GTIN (EAN) | 4032248056316 | |
| Qty. | 1 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

5x20

5x20

For protection against overcurrent, we offer cartridge fuse with dimensions 5x20 mm in sizes from 100 mA to 6.3 A.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | G 20/0.25A/F | Version |
| Order No. | 0430500000 | Miniature fuse, quick-acting, 0.25 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190153991 | |
| Qty. | 10 pc(s). | |
| Type | G 20/3.15A/F | Version |
| Order No. | 0431100000 | Miniature fuse, quick-acting, 3.15 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190012977 | |
| Qty. | 10 pc(s). | |
| Type | G 20/0.20A/F | Version |
| Order No. | 0430400000 | Miniature fuse, quick-acting, 0.2 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190152383 | |
| Qty. | 10 pc(s). | |
| Type | G 20/5.00A/F | Version |
| Order No. | 0431300000 | Miniature fuse, quick-acting, 5 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190185381 | |
| Qty. | 10 pc(s). | |
| Type | G 20/2.00A/F | Version |
| Order No. | 0430900000 | Miniature fuse, quick-acting, 2 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190123567 | |
| Qty. | 10 pc(s). | |
| Type | G 20/6.30A/F | Version |
| Order No. | 0431400000 | Miniature fuse, quick-acting, 6.3 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190086053 | |
| Qty. | 10 pc(s). | |
| Type | G 20/2.50A/F | Version |
| Order No. | 0431000000 | Miniature fuse, quick-acting, 2.5 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190085513 | |
| Qty. | 10 pc(s). | |
| Type | G 20/0.63A/F | Version |
| Order No. | 0439000000 | Miniature fuse, quick-acting, 0.63 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190131210 | |
| Qty. | 10 pc(s). | |
| Type | G 20/0.50A/F | Version |
| Order No. | 0430600000 | Miniature fuse, quick-acting, 0.5 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190046835 | |
| Qty. | 10 pc(s). | |
| Type | G 20/1.00A/F | Version |
| Order No. | 0430700000 | Miniature fuse, quick-acting, 1 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190093877 | |
| Qty. | 10 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold


Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | G 20/1.60A/F | Version |
| Order No. | 0430800000 | Miniature fuse, quick-acting, 1.6 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190031503 | |
| Qty. | 10 pc(s). | |
| Type | G 20/0.10A/F | Version |
| Order No. | 0430300000 | Miniature fuse, quick-acting, 0.1 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190077174 | |
| Qty. | 10 pc(s). | |
| Type | G 20/4.00A/F | Version |
| Order No. | 0431200000 | Miniature fuse, quick-acting, 4 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190022983 | |
| Qty. | 10 pc(s). | |

E 14

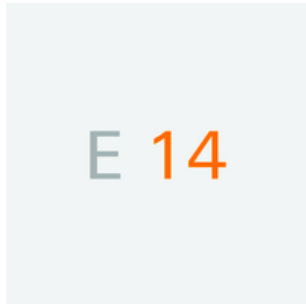

Weidmueller offers NEOZED fuses in E 14 design in sizes from 2 A to 16 A.

General ordering data

| | | |
|------------|----------------------------|-----------------------------------|
| Type | E 14/4A BR | Version |
| Order No. | 0137500000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190142629 | |
| Qty. | 10 pc(s). | |
| Type | E 14/16A GR | Version |
| Order No. | 0328500000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190152161 | |
| Qty. | 10 pc(s). | |
| Type | E 14/10A RT | Version |
| Order No. | 0328400000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190000288 | |
| Qty. | 10 pc(s). | |
| Type | E 14/6A GN | Version |
| Order No. | 0328300000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190002190 | |
| Qty. | 10 pc(s). | |
| Type | E 14/2A RS | Version |
| Order No. | 0137400000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190069094 | |
| Qty. | 10 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

QL mounting screws



Screwable cross-connections are easy to mount and de mount. Thanks to the big contact surface, even high currents can be transmitted with maximum contact reliability.

General ordering data

| | | |
|------------|----------------------------|---------------------|
| Type | SS M3 D 128-A 3 | Version |
| Order No. | 0164400000 | Lock washer, Copper |
| GTIN (EAN) | 4008190035914 | |
| Qty. | 50 pc(s). | |

Marker holder



The marker holder offer the possibility of additional mounting of standard markers with a pitch of 5 or 5.1 mm. The angled holders can be optionally snapped together and could be mounted in all standard marking channels of the Klippon® Connect modular terminal blocks. Fitting marker types could be found under the respective accessories of the designation marking holder.

General ordering data

| | | |
|------------|----------------------------|----------------------------|
| Type | BZT 1 ZA WS 10/5 | Version |
| Order No. | 1805520000 | Accessories, Marker holder |
| GTIN (EAN) | 4032248270248 | |
| Qty. | 100 pc(s). | |
| Type | BZT 1 WS 10/5 | Version |
| Order No. | 1805490000 | Accessories, Marker holder |
| GTIN (EAN) | 4032248270231 | |
| Qty. | 100 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Plus



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/8 PLUS MC NE WS | Version |
| Order No. | 1046350000 | Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00 |
| GTIN (EAN) | 4032248782055 | Weidmueller, white |
| Qty. | 800 pc(s). | |

Screws



Depending on the terminal block or also accessories, we offer different types of screws as additional items or also spare parts.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | BFSC M4X9T | Version |
| Order No. | 0103300000 | Mounting screw (Terminal), Steel, Height: 9 mm |
| GTIN (EAN) | 4008190023348 | |
| Qty. | 100 pc(s). | |
| Type | BFSC M3X25 | Version |
| Order No. | 0292500000 | Mounting screw (Terminal), Steel, Height: 25 mm |
| GTIN (EAN) | 4008190177027 | |
| Qty. | 100 pc(s). | |
| Type | KISC M3X6 SAKS1 | Version |
| Order No. | 0346200000 | Clamping yoke, Mounting screw, Steel |
| GTIN (EAN) | 4008190175658 | |
| Qty. | 100 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|--|
| Type | BFSC M4X30 | Version |
| Order No. | 0267100000 | Mounting screw (Terminal), Steel, Height: 30 mm |
| GTIN (EAN) | 4008190187897 | |
| Qty. | 50 pc(s). | |
| Type | BFSC M3X22 PA/RT | Version |
| Order No. | 0128900000 | Mounting screw (Terminal), Polyamide 66, Height: 22 mm |
| GTIN (EAN) | 4008190084158 | |
| Qty. | 100 pc(s). | |
| Type | BFSC M4X20 | Version |
| Order No. | 0362800000 | Mounting screw (Terminal), Steel, Height: 20 mm |
| GTIN (EAN) | 4008190114053 | |
| Qty. | 100 pc(s). | |

QL / SAKH 10

Screwable cross-connections are easy to mount and de mount. Thanks to the big contact surface, even high currents can be transmitted with maximum contact reliability.



General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 2 SAKH10 | Version |
| Order No. | 0131400000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of poles: 2, Pitch in mm (P): 14.00, Insulated: No, Width: 16.9 mm |
| GTIN (EAN) | 4008190114237 | |
| Qty. | 50 pc(s). | |
| Type | QL 3 SAKH10 | Version |
| Order No. | 0131500000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of poles: 3, Pitch in mm (P): 14.00, Insulated: No, Width: 26.8 mm |
| GTIN (EAN) | 4008190056490 | |
| Qty. | 50 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

SAK-Series

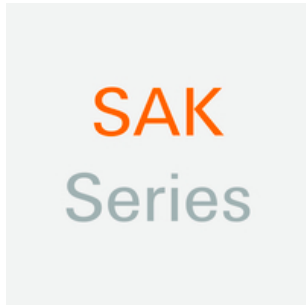


Warning covers with a flash symbol provide more safety for man and machine. They are used where external voltage must be indicated within the application.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | AD 4 SAK10 | Version |
| Order No. | 0178600000 | Terminal cover, yellow, PVC, Height: 39.6 mm, Width: 25 mm, Depth: |
| GTIN (EAN) | 4008190068288 | 1 mm, HB |
| Qty. | 50 pc(s). | |

Copper

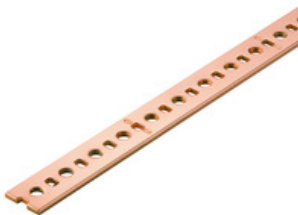

Of all the metals used, copper has the best electrical conductivity, which results in the highest short-circuit resistance. This makes the copper busbar the most widely used variant.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | NSCH 1M | Version |
| Order No. | 0280200000 | Busbar (terminal), Natural, Height: 15 mm, Depth: 2 mm, Copper |
| GTIN (EAN) | 4008190012953 | |
| Qty. | 10 m | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Copper



Of all the metals used, copper has the best electrical conductivity, which results in the highest short-circuit resistance. This makes the copper busbar the most widely used variant.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | SSCH 6X6X1000 CU/SN | Version |
| Order No. | 0571300000 | Busbar (terminal), silver, Height: 1000 mm, Depth: 6 mm, Copper |
| GTIN (EAN) | 4008190015039 | |
| Qty. | 1 m | |
| Type | SSCH 10X3X1000 CU/SN | Version |
| Order No. | 0348900000 | Busbar (terminal), silver, Height: 1000 mm, Depth: 3 mm, Copper |
| GTIN (EAN) | 4008190024802 | |
| Qty. | 1 m | |
| Type | SSCH 7.3X1.2X1000 | Version |
| Order No. | 1071200000 | Busbar (terminal), silver, Height: 1000 mm, Depth: 1.2 mm, Copper |
| GTIN (EAN) | 4008190279172 | |
| Qty. | 1 m | |
| Type | SSCH 15X6X1000 CU/SN | Version |
| Order No. | 0357400000 | Busbar (terminal), silver, Height: 1000 mm, Depth: 6 mm, Copper |
| GTIN (EAN) | 4008190169572 | |
| Qty. | 1 m | |

QL / SAKA

Screwable cross-connections are easy to mount and de mount. Thanks to the big contact surface, even high currents can be transmitted with maximum contact reliability.



General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 10 SAKB 10 | Version |
| Order No. | 0338400000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of poles: 10, Pitch in mm (P): 6.00, Insulated: No, Width: 97 mm |
| GTIN (EAN) | 4008190139452 | |
| Qty. | 20 pc(s). | |
| Type | QL 2 SAKA 10 | Version |
| Order No. | 0135500000 | Cross-connector (terminal), when screwed in, grey, 32 A, Number of poles: 2, Pitch in mm (P): 12.00, Insulated: No, Width: 19.9 mm |
| GTIN (EAN) | 4008190099404 | |
| Qty. | 50 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|--|
| Type | QL 3 SAKA10 | Version |
| Order No. | 0135600000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190032081 | poles: 3, Pitch in mm (P): 12.00, Insulated: No, Width: 31.8 mm |
| Qty. | 50 pc(s). | |
| Type | QL 4 SAKA10 | Version |
| Order No. | 0135700000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190118822 | poles: 4, Pitch in mm (P): 12.00, Insulated: No, Width: 43.7 mm |
| Qty. | 50 pc(s). | |
| Type | QL 10 SAKA10 | Version |
| Order No. | 0338500000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of |
| GTIN (EAN) | 4008190063313 | poles: 10, Pitch in mm (P): 6.00, Insulated: No, Width: 115.1 mm |
| Qty. | 20 pc(s). | |

Fuse holder



The fuse holder SIHA quickly turns a disconnect terminal into a fuse terminal: simply remove the disconnect lever and attach the fuse unit.

General ordering data

| | | |
|------------|----------------------------|----------------------------|
| Type | SK G20/SAKS1 | Version |
| Order No. | 0282100000 | Screw cover cap (terminal) |
| GTIN (EAN) | 4008190004606 | |
| Qty. | 20 pc(s). | |
| Type | SK E14 SAKS4 | Version |
| Order No. | 0339410000 | Screw cover cap (terminal) |
| GTIN (EAN) | 4008190032104 | |
| Qty. | 20 pc(s). | |
| Type | SK SAKS1/G25 | Version |
| Order No. | 0282000000 | Screw cover cap (terminal) |
| GTIN (EAN) | 4008190078492 | |
| Qty. | 20 pc(s). | |
| Type | SK E16/SAKS2 | Version |
| Order No. | 0284110000 | Screw cover cap (terminal) |
| GTIN (EAN) | 4008190006204 | |
| Qty. | 25 pc(s). | |
| Type | SK E18 SAKS5 | Version |
| Order No. | 0359310000 | Screw cover cap (terminal) |
| GTIN (EAN) | 4008190002121 | |
| Qty. | 20 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

6.3x32

6.3x32

For protection against overcurrent, we offer cartridge fuse with dimensions 6.3x32 mm in sizes from 500 mA to 12.5 A.

General ordering data

| | | |
|------------|----------------------------|------------|
| Type | VH 25.4/6.3/4.3 | Version |
| Order No. | 0446200000 | Dummy fuse |
| GTIN (EAN) | 4008190519759 | |
| Qty. | 10 pc(s). | |

5x25

5x25

For protection against overcurrent, we offer cartridge fuse with dimensions 5x25 mm in sizes from 250 mA to 6.3 A.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | G 25/0.80A/M GR | Version |
| Order No. | 0646400000 | Miniature fuse, medium time-lag, 0.8 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190060794 | |
| Qty. | 10 pc(s). | |
| Type | G 25/1.00A/M RT | Version |
| Order No. | 0265800000 | Miniature fuse, medium time-lag, 1 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190141660 | |
| Qty. | 10 pc(s). | |
| Type | G 25/0.50A/M WS | Version |
| Order No. | 0510300000 | Miniature fuse, medium time-lag, 0.5 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190018368 | |
| Qty. | 10 pc(s). | |
| Type | G 25/0.25A/M GE | Version |
| Order No. | 0546900000 | Miniature fuse, medium time-lag, 0.25 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190097370 | |
| Qty. | 10 pc(s). | |
| Type | G 25/2.00A/F BL | Version |
| Order No. | 0192700000 | Miniature fuse, quick-acting, 2 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190176402 | |
| Qty. | 10 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | G 25/4.00A/F BR | Version |
| Order No. | 0192800000 | Miniature fuse, quick-acting, 4 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190115319 | |
| Qty. | 10 pc(s). | |
| Type | G 25/6.30A/F GN | Version |
| Order No. | 0192900000 | Miniature fuse, quick-acting, 6.3 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190135461 | |
| Qty. | 10 pc(s). | |
| Type | G 25/10.0A/M RT | Version |
| Order No. | 0193100000 | Miniature fuse, medium time-lag, 10 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190023799 | |
| Qty. | 10 pc(s). | |

Uninsulated



Uninsulated bus bar tap-off terminals offer a space-saving option for connecting conductors on a bus bar.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | ZB 35/M6X16 | Version |
| Order No. | 0266500000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 14 mm, M 6, |
| GTIN (EAN) | 4008190102814 | Steel |
| Qty. | 20 pc(s). | |
| Type | ZBE 6 | Version |
| Order No. | 0459500000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 8 mm, M 4, |
| GTIN (EAN) | 4008190032692 | Steel |
| Qty. | 50 pc(s). | |
| Type | ZB 4 | Version |
| Order No. | 0316500000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 5.3 mm, M 3, |
| GTIN (EAN) | 4008190061999 | Steel |
| Qty. | 50 pc(s). | |
| Type | ZB 4/6 | Version |
| Order No. | 0556700000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 5.3 mm, M 3, |
| GTIN (EAN) | 4008190188412 | Steel |
| Qty. | 50 pc(s). | |
| Type | ZB 16 ZKSC | Version |
| Order No. | 0316600000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 10 mm, M 4, |
| GTIN (EAN) | 4008190145989 | Steel |
| Qty. | 50 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

DEK 5/8

**WS/ DEK**

MultiMark terminal markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.

Your benefits with MultiMark

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

General ordering data

| | | |
|------------|----------------------------|--|
| Type | DEK 5/8 MM WS | Version |
| Order No. | 2007130000 | Dekafix, Terminal marker, 5 x 8 mm, Weidmueller, white |
| GTIN (EAN) | 4050118392012 | |
| Qty. | 500 pc(s). | |

SAKS 4/35 USA**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Blank**

The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/8 MC NE WS | Version |
| Order No. | 1856740000 | Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00 |
| GTIN (EAN) | 4032248400850 | Weidmueller, white |
| Qty. | 800 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

DEK 5/6



WS/ DEK

MultiMark terminal markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.

Your benefits with MultiMark

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

General ordering data

| | | |
|------------|----------------------------|--|
| Type | DEK 5/6 MM WS | Version |
| Order No. | 2007120000 | Dekafix, Terminal marker, 5 x 6 mm, Weidmueller, white |
| GTIN (EAN) | 4050118392104 | |
| Qty. | 600 pc(s). | |

SAK-Series



End plates are fitted to the open side of the last modular terminal before the end bracket. The use of an end plate ensures the function of the modular terminal and the specified rated voltage. It guarantees protection against contact with live parts and makes the final terminal finger-proof.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | AP SAK4-10 I | Version |
| Order No. | 0117910000 | End plate (terminals), Light Grey, Height: 40 mm, Width: 1.5 mm, V-2, |
| GTIN (EAN) | 4008190183707 | PA 66 |
| Qty. | 20 pc(s). | |
| Type | AP SAKA KRG | Version |
| Order No. | 0134220000 | End plate (terminals), dark beige, yellow, Height: 82 mm, Width: 3 |
| GTIN (EAN) | 4008190167943 | mm, V-0, KrG |
| Qty. | 20 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | AP SAK4-10 BL | Version |
| Order No. | 0117980000 | End plate (terminals), blue, Height: 40 mm, Width: 1.5 mm, V-2, PA 66 |
| GTIN (EAN) | 4008190171087 | |
| Qty. | 20 pc(s). | |
| Type | AP SAK4-10 KRG | Version |
| Order No. | 0117920000 | End plate (terminals), dark beige, yellow, Height: 40 mm, Width: 1.5 mm, V-0, KrG |
| GTIN (EAN) | 4008190135904 | |
| Qty. | 20 pc(s). | |
| Type | AP SAK4-10 | Version |
| Order No. | 0117960000 | End plate (terminals), beige, Height: 40 mm, Width: 1.5 mm, V-2, PA 66 |
| GTIN (EAN) | 4008190081485 | |
| Qty. | 20 pc(s). | |
| Type | AP RSF1 KRG | Version |
| Order No. | 0270420000 | End plate (terminals), medium yellow, Height: 50 mm, Width: 3 mm, V-0, KrG |
| GTIN (EAN) | 4008190099107 | |
| Qty. | 10 pc(s). | |
| Type | AP KSKM | Version |
| Order No. | 9509630000 | SAK Series, End plate, 1.5 mm, beige, Direct mounting |
| GTIN (EAN) | 4008190456771 | |
| Qty. | 20 pc(s). | |
| Type | AP SAK4-10 DB | Version |
| Order No. | 0105100000 | End plate (terminals), dark beige, Height: 40 mm, Width: 1.5 mm, V-0, Wemid |
| GTIN (EAN) | 4008190394875 | |
| Qty. | 20 pc(s). | |
| Type | AP SAKS1+3 KRG | Version |
| Order No. | 0191320000 | End plate (terminals), dark beige, yellow, Height: 54 mm, Width: 3 mm, V-0, KrG |
| GTIN (EAN) | 4008190031688 | |
| Qty. | 20 pc(s). | |
| Type | AP SAKB/C/T KRG | Version |
| Order No. | 0146720000 | End plate (terminals), dark beige, yellow, Height: 65 mm, Width: 3 mm, V-0, KrG |
| GTIN (EAN) | 4008190027995 | |
| Qty. | 20 pc(s). | |
| Type | AP SAK4-10 RT | Version |
| Order No. | 0117900000 | End plate (terminals), red, Height: 40 mm, Width: 1.5 mm, V-2, PA 66 |
| GTIN (EAN) | 4008190125059 | |
| Qty. | 20 pc(s). | |
| Type | AP SAK35/TW SAK16 BL | Version |
| Order No. | 0303680000 | End plate (terminals), blue, Height: 58 mm, Width: 1.5 mm, V-2, PA 66 |
| GTIN (EAN) | 4008190025199 | |
| Qty. | 10 pc(s). | |
| Type | AP SAK35/TW SAK16 | Version |
| Order No. | 0303660000 | End plate (terminals), beige, Height: 58 mm, Width: 1.5 mm, V-2, PA 66 |
| GTIN (EAN) | 4008190110765 | |
| Qty. | 10 pc(s). | |
| Type | AP SAKS1+3 KRG/DB | Version |
| Order No. | 0191300000 | End plate (terminals), dark beige, Height: 54 mm, Width: 3 mm, V-0, KrG |
| GTIN (EAN) | 4008190099763 | |
| Qty. | 20 pc(s). | |
| Type | AP SAK4-10 KRG/BL | Version |
| Order No. | 0117970000 | End plate (terminals), blue, Height: 40 mm, Width: 1.5 mm, V-0, KrG |
| GTIN (EAN) | 4008190049607 | |
| Qty. | 20 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

QL / SAK 10



Screwable cross-connections are easy to mount and de mount. Thanks to the big contact surface, even high currents can be transmitted with maximum contact reliability.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 2 SAKB10 | Version |
| Order No. | 0114100000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190056605 | poles: 2, Pitch in mm (P): 10.00, Insulated: No, Width: 17 mm |
| Qty. | 100 pc(s). | |

SAK-Series



Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | EW 35 | Version |
| Order No. | 0383560000 | End bracket, beige, TS 35, V-2, Wemid, Width: 8.5 mm, 100 °C |
| GTIN (EAN) | 4008190181314 | |
| Qty. | 50 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Steel



Steel bus bars, together with stainless steel, have the highest strength among metallic busbars and are used in applications where short-circuit resistance plays only a secondary role.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | ESCH 1 M | Version |
| Order No. | 0280300000 | Busbar (terminal), silver, Height: 12 mm, Depth: 2 mm, Steel |
| GTIN (EAN) | 4008190143053 | |
| Qty. | 10 m | |

Insulation caps



With our accessories for the bus bar taps, you can quickly and easily insulate the tap terminals and visualize the potential through the color coding.

General ordering data

| | | |
|------------|----------------------------|-------------------------------------|
| Type | IK 6 GG ZBE6K | Version |
| Order No. | 0526060000 | Cover hood (terminal), Steel |
| GTIN (EAN) | 4008190128647 | |
| Qty. | 50 pc(s). | |
| Type | IK 16/ZB 16 GG | Version |
| Order No. | 0502960000 | Cover hood (terminal), Polyamide 66 |
| GTIN (EAN) | 4008190113438 | |
| Qty. | 50 pc(s). | |
| Type | IK 16/ZB 16 BL | Version |
| Order No. | 0502980000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190159696 | |
| Qty. | 50 pc(s). | |
| Type | IK 4 GG ZB4 | Version |
| Order No. | 0475460000 | Cover hood (terminal), Polyamide 66 |
| GTIN (EAN) | 4008190065348 | |
| Qty. | 50 pc(s). | |
| Type | IK 35/ZB35 BL | Version |
| Order No. | 0502780000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190141455 | |
| Qty. | 50 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|------------------------------|
| Type | IK 4 BL ZB4 | Version |
| Order No. | 0475480000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190145668 | |
| Qty. | 50 pc(s). | |

Connection sleeves



General ordering data

| | | |
|------------|----------------------------|---|
| Type | VL 2 RSF 1+2 | Version |
| Order No. | 0528400000 | Cross-connector (terminal), when screwed in, grey, 32 A, Number of |
| GTIN (EAN) | 4008190059095 | poles: 2, Pitch in mm (P): 11.00, Insulated: No, Width: 19 mm |
| Qty. | 10 pc(s). | |
| Type | VL 2 SAK16/SAKA | Version |
| Order No. | 0135800000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of |
| GTIN (EAN) | 4008190132088 | poles: 2, Pitch in mm (P): 12.00, Insulated: No, Width: 8 mm |
| Qty. | 50 pc(s). | |
| Type | VL 2 SAK6N/SAKT | Version |
| Order No. | 0194700000 | Cross-connector (terminal), when screwed in, grey, 32 A, Number of |
| GTIN (EAN) | 4008190148027 | poles: 2, Pitch in mm (P): 8.00, Insulated: No, Width: 7 mm |
| Qty. | 50 pc(s). | |
| Type | VH 23/6/4.2 SAKA10 | Version |
| Order No. | 0348700000 | Connecting sleeve (terminal), when screwed in, Width: 6 mm, Height: |
| GTIN (EAN) | 4008190185923 | 6 mm, Depth: 23 mm, Number of poles: 1, Cu Zn |
| Qty. | 50 pc(s). | |
| Type | VH 13.6/6.3/4.3 | Version |
| Order No. | 0299700000 | Connecting sleeve (terminal), when screwed in, Width: 7 mm, Height: |
| GTIN (EAN) | 4008190018313 | 7 mm, Depth: 13.6 mm, Cu Zn |
| Qty. | 50 pc(s). | |
| Type | VH 17.5/5/3.4 | Version |
| Order No. | 0285200000 | Connecting sleeve (terminal), when screwed in, Width: 5 mm, Height: |
| GTIN (EAN) | 4008190054717 | 5 mm, Depth: 17.5 mm, Copper |
| Qty. | 50 pc(s). | |
| Type | VH 19/5/3.4 | Version |
| Order No. | 0285100000 | Connecting sleeve (terminal), when screwed in, Width: 5 mm, Height: |
| GTIN (EAN) | 4008190189297 | 5 mm, Depth: 17.5 mm, Number of poles: 1, Cu Zn |
| Qty. | 50 pc(s). | |
| Type | VL 2 SAK6/10/SAKB | Version |
| Order No. | 0135900000 | Cross-connector (terminal), when screwed in, grey, 32 A, Number of |
| GTIN (EAN) | 4008190036409 | poles: 2, Pitch in mm (P): 6.50, Insulated: No |
| Qty. | 50 pc(s). | |

Creation date July 25, 2024 5:17:11 PM CEST

Catalogue status 13.07.2024 / We reserve the right to make technical changes.

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | VH 12/4.9/3.3 | Version |
| Order No. | 0249000000 | Connecting sleeve (terminal), when screwed in, Width: 4.9 mm, |
| GTIN (EAN) | 4008190129507 | Height: 4.9 mm, Depth: 12 mm, Copper |
| Qty. | 100 pc(s). | |
| Type | VH 20/5/3.4 | Version |
| Order No. | 0446100000 | Dummy fuse |
| GTIN (EAN) | 4008190519742 | |
| Qty. | 10 pc(s). | |

Miscellaneous



We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

General ordering data

| | | |
|------------|----------------------------|---------------------|
| Type | SS M4 D 128-A 4 | Version |
| Order No. | 0136400000 | Lock washer, Copper |
| GTIN (EAN) | 4008190118143 | |
| Qty. | 100 pc(s). | |

SAK-Series



A partition plate is used for the optical separation of circuits or used for electrical isolation from neighbouring cross-connectors. In contrast to the end plate, the contour can be larger than the adjacent terminal blocks. However, it should not be smaller, as otherwise the required clearance and creepage distances within the application can no longer be maintained.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | TSCH 6 DKI S4 | Version |
| Order No. | 0190260000 | Small partition (terminal), PA 66, beige, Continuous operating temp., |
| GTIN (EAN) | 4008190051075 | max.: 100 °C |
| Qty. | 100 pc(s). | |
| Type | TSCH 4 AKZ4 | Version |
| Order No. | 0363360000 | Small partition (terminal), PA 66, beige, Continuous operating temp., |
| GTIN (EAN) | 4008190136680 | max.: 100 °C |
| Qty. | 100 pc(s). | |
| Type | TSCH 2 | Version |
| Order No. | 0353660000 | Small partition (terminal), PA 66, beige, Continuous operating temp., |
| GTIN (EAN) | 4008190128432 | max.: 100 °C |
| Qty. | 100 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | TW AST1/PA HP/DBR/0.5 | Version |
| Order No. | 0474700000 | Partition plate (terminal), dark brown, Height: 65 mm, Width: 0.5 mm, |
| GTIN (EAN) | 4008190078508 | V-2 |
| Qty. | 20 pc(s). | |
| Type | TSCH 3 SAKD2.5 N | Version |
| Order No. | 0366860000 | Small partition (terminal), PA 66, beige, Continuous operating temp., |
| GTIN (EAN) | 4008190010928 | max.: 100 °C |
| Qty. | 100 pc(s). | |
| Type | TW DK4 HP/DBR/2 | Version |
| Order No. | 3833500000 | Partition plate (terminal), dark brown, Height: 65 mm, Width: 2 mm, |
| GTIN (EAN) | 4008190009052 | V-2, PA 66 |
| Qty. | 20 pc(s). | |
| Type | TW 4 SAK4-10 | Version |
| Order No. | 0130160000 | Partition plate (terminal), beige, Height: 50 mm, Width: 1.5 mm, V-2, |
| GTIN (EAN) | 4008190096335 | PA 66 |
| Qty. | 20 pc(s). | |
| Type | TW 4 SAK4-10 BL | Version |
| Order No. | 0130180000 | Partition plate (terminal), blue, Height: 50 mm, Width: 1.5 mm, V-2, PA |
| GTIN (EAN) | 4008190114138 | 66 |
| Qty. | 20 pc(s). | |
| Type | TW SAKS2 HP/DBR/2 | Version |
| Order No. | 0607000000 | Partition plate (terminal), dark brown, Height: 80 mm, Width: 2 mm, |
| GTIN (EAN) | 4008190002732 | V-2, PA 66 |
| Qty. | 20 pc(s). | |
| Type | TSCH 1 | Version |
| Order No. | 0319160000 | Small partition (terminal), PA 66, beige, Continuous operating temp., |
| GTIN (EAN) | 4008190097219 | max.: 100 °C |
| Qty. | 100 pc(s). | |

Mounting rail support

General ordering data

| | | |
|------------|----------------------------|--|
| Type | SH 2 | Version |
| Order No. | 0494920000 | Busbar support, medium yellow, 130 °C, Width: 40 mm, V-0, KrG, |
| GTIN (EAN) | 4008190007584 | when screwed in |
| Qty. | 10 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Fixing screws



Fixing screws fix the short current bridge within the application. If the short current bridge is slid between two adjacent terminal blocks into the short circuit position, it can be fixed by means of a fastening screw. This ensures a permanent connection or short circuit.

General ordering data

| | | |
|------------|----------------------------|------------------------------------|
| Type | KISC M3X20 SAK10 CU5 | Version |
| Order No. | 0377100000 | SAK Series, Mounting screw, Copper |
| GTIN (EAN) | 4008190060350 | |
| Qty. | 100 pc(s). | |

Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/6 MC NE WS | Version |
| Order No. | 1609820000 | Dekafix, Terminal marker, 5 x 6 mm, Pitch in mm (P): 6.00 |
| GTIN (EAN) | 4008190203436 | Weidmueller, white |
| Qty. | 1,000 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Insulated



Bus bar taps with insulation offer finger safety on the one hand. On the other hand, the colored insulation also indicates the respective potential, such as the neutral conductor or PE.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | ZB 16K GE/GN | Version |
| Order No. | 0502860000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 10 mm, M 4, |
| GTIN (EAN) | 4008190188795 | Steel |
| Qty. | 50 pc(s). | |
| Type | ZB 35K GE/GN M6X16 | Version |
| Order No. | 0502660000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 14 mm, M 6, |
| GTIN (EAN) | 4008190052294 | Steel |
| Qty. | 20 pc(s). | |
| Type | ZB 4K GE/GN | Version |
| Order No. | 0475360000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 6 mm, M 3, |
| GTIN (EAN) | 4008190188047 | Steel |
| Qty. | 50 pc(s). | |
| Type | ZB 16K SW | Version |
| Order No. | 0502810000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 10 mm, Steel |
| GTIN (EAN) | 4008190332563 | |
| Qty. | 50 pc(s). | |
| Type | ZB 4K BL | Version |
| Order No. | 0475380000 | Clamping yoke (bus-bar), Clamping yoke, silver, 4 mm ² , Width: 6 mm, |
| GTIN (EAN) | 4008190010942 | M 3, Steel |
| Qty. | 50 pc(s). | |
| Type | ZB 4/6K BL | Version |
| Order No. | 0565480000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 6 mm, M 3, |
| GTIN (EAN) | 4008190086831 | Steel |
| Qty. | 50 pc(s). | |
| Type | ZB 4K GG HENSEL | Version |
| Order No. | 1824560000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 6 mm, Steel |
| GTIN (EAN) | 4032248330973 | |
| Qty. | 50 pc(s). | |
| Type | ZB 35K BL M6X16 | Version |
| Order No. | 0502680000 | Clamping yoke (bus-bar), Clamping yoke, silver, 35 mm ² , Width: 14 |
| GTIN (EAN) | 4008190004385 | mm, M 6, Steel |
| Qty. | 20 pc(s). | |
| Type | ZB 16K BL | Version |
| Order No. | 0502880000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 10 mm, M 4, |
| GTIN (EAN) | 4008190014186 | Steel |
| Qty. | 50 pc(s). | |
| Type | ZBE 6K SW | Version |
| Order No. | 0525910000 | Clamping yoke (bus-bar), Clamping yoke, black, Width: 8 mm, M 4, |
| GTIN (EAN) | 4008190977054 | Steel |
| Qty. | 50 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|--|
| Type | ZBE 6K BL | Version |
| Order No. | 0525980000 | Clamping yoke (bus-bar), Clamping yoke, blue, 6 mm ² , Width: 8 mm, |
| GTIN (EAN) | 4008190060886 | M 4, Steel |
| Qty. | 50 pc(s). | |
| Type | ZBE 6K GE/GN | Version |
| Order No. | 0525960000 | Clamping yoke (bus-bar), Clamping yoke, yellow, green, Width: 8 mm, |
| GTIN (EAN) | 4008190145026 | M 4, Steel |
| Qty. | 50 pc(s). | |
| Type | ZB 4G SW | Version |
| Order No. | 0322110000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 7.4 mm, M 3, |
| GTIN (EAN) | 4008190189310 | Steel |
| Qty. | 50 pc(s). | |
| Type | ZB 4G BL | Version |
| Order No. | 0322180000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 7.4 mm, M 3, |
| GTIN (EAN) | 4008190050504 | Steel |
| Qty. | 50 pc(s). | |
| Type | ZB 4K SW | Version |
| Order No. | 0475310000 | Clamping yoke (bus-bar), Clamping yoke, black, Width: 7 mm, Steel |
| GTIN (EAN) | 4008190008406 | |
| Qty. | 50 pc(s). | |
| Type | ZB 35K SW M6X16 | Version |
| Order No. | 0502610000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 14 mm, M 6, |
| GTIN (EAN) | 4008190332587 | Steel |
| Qty. | 20 pc(s). | |
| Type | ZB 4/6K GE/GN | Version |
| Order No. | 0565460000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 6 mm, M 3, |
| GTIN (EAN) | 4008190032609 | Steel |
| Qty. | 50 pc(s). | |
| Type | ZB 4G GN/GE | Version |
| Order No. | 0322160000 | Clamping yoke (bus-bar), Clamping yoke, silver, Width: 7.4 mm, M 3, |
| GTIN (EAN) | 4008190014278 | Steel |
| Qty. | 50 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/6.5 MC SDR | Version |
| Order No. | 1609850000 | Dekafix, Terminal marker, 5 x 6.5 mm, Pitch in mm (P): 6.50 |
| GTIN (EAN) | 4008190456610 | Weidmueller, To customer specification |
| Qty. | 180 pc(s). | |

Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/5 MC NE WS | Version |
| Order No. | 1609801044 | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190397111 | Weidmueller, white |
| Qty. | 1,000 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Testsockets



Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | STB 18/RSF1 | Version |
| Order No. | 0286500000 | Socket (terminal), Plug-in depth: 15 mm, Depth: 23 mm |
| GTIN (EAN) | 4008190515591 | |
| Qty. | 20 pc(s). | |
| Type | STB 13.5/D6/4/M4 SAKA10 | Version |
| Order No. | 0135200000 | SAK Series, Socket |
| GTIN (EAN) | 4008190172862 | |
| Qty. | 50 pc(s). | |

Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/6.5 MC NE WS | Version |
| Order No. | 1609840000 | Dekafix, Terminal marker, 5 x 6.5 mm, Pitch in mm (P): 6.50 |
| GTIN (EAN) | 4008190203429 | Weidmueller, white |
| Qty. | 900 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

QL / SAKS



Screwable cross-connections are easy to mount and de mount. Thanks to the big contact surface, even high currents can be transmitted with maximum contact reliability.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 10 SAKS2 | Version |
| Order No. | 0338900000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190105723 | poles: 10, Pitch in mm (P): 10.00, Insulated: No, Width: 261.4 mm |
| Qty. | 20 pc(s). | |
| Type | QL 3 SAKS1 | Version |
| Order No. | 0191500000 | Cross-connector (terminal), when screwed in, grey, 47 A, Number of |
| GTIN (EAN) | 4008190036881 | poles: 3, Pitch in mm (P): 13.00, Insulated: No, Width: 31.9 mm |
| Qty. | 50 pc(s). | |
| Type | QL 3 SAKS4 | Version |
| Order No. | 0328100000 | Cross-connector (terminal), when screwed in, grey, 47 A, Number of |
| GTIN (EAN) | 4008190097639 | poles: 3, Pitch in mm (P): 24.00, Insulated: No, Width: 58 mm |
| Qty. | 20 pc(s). | |
| Type | QL 10 SAKS1 | Version |
| Order No. | 0338800000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190127039 | poles: 10, Pitch in mm (P): 13.00, Insulated: No, Width: 122.1 mm |
| Qty. | 20 pc(s). | |
| Type | QL 4 SAKS2 | Version |
| Order No. | 0208000000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190069100 | poles: 4, Pitch in mm (P): 27.60, Insulated: No, Width: 95.8 mm |
| Qty. | 20 pc(s). | |
| Type | QL 2 SAKS1 | Version |
| Order No. | 0191400000 | Cross-connector (terminal), when screwed in, grey, 47 A, Number of |
| GTIN (EAN) | 4008190123130 | poles: 2, Pitch in mm (P): 13.00, Insulated: No, Width: 18.9 mm |
| Qty. | 50 pc(s). | |
| Type | QL 2 SAKS2 | Version |
| Order No. | 0207800000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190144364 | poles: 2, Pitch in mm (P): 27.60, Insulated: No, Width: 40.6 mm |
| Qty. | 20 pc(s). | |
| Type | QL 4 SAKS1 | Version |
| Order No. | 0191600000 | Cross-connector (terminal), when screwed in, grey, 47 A, Number of |
| GTIN (EAN) | 4008190105518 | poles: 4, Pitch in mm (P): 13.00, Insulated: No, Width: 44.7 mm |
| Qty. | 20 pc(s). | |
| Type | QL 2 SAKS4 | Version |
| Order No. | 0328000000 | Cross-connector (terminal), when screwed in, grey, 47 A, Number of |
| GTIN (EAN) | 4008190071165 | poles: 2, Pitch in mm (P): 24.00, Insulated: No, Width: 34 mm |
| Qty. | 20 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold


Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|--|
| Type | QL 10 SAKS4 | Version |
| Order No. | 0339000000 | Cross-connector (terminal), when screwed in, grey, 47 A, Number of |
| GTIN (EAN) | 4008190025335 | poles: 10, Pitch in mm (P): 10.00, Insulated: No, Width: 226 mm |
| Qty. | 20 pc(s). | |

E 16

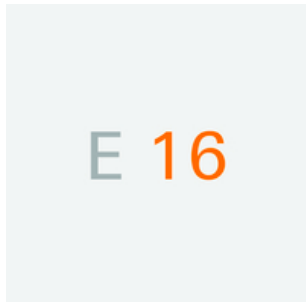

Weidmueller offers NEOZED fuses in E 16 design in sizes from 10 A to 25 A.

General ordering data

| | | |
|------------|----------------------------|-----------------------------------|
| Type | E 16/16A GR TNDZ | Version |
| Order No. | 0208600000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190015121 | |
| Qty. | 25 pc(s). | |
| Type | E 16/20A BL TNDZ | Version |
| Order No. | 0208700000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190044886 | |
| Qty. | 25 pc(s). | |
| Type | E 16/25A GE TNDZ | Version |
| Order No. | 0208800000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190037314 | |
| Qty. | 25 pc(s). | |
| Type | E 16/10A RT TNDZ | Version |
| Order No. | 0208500000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190067120 | |
| Qty. | 25 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Brass



Brass bus bars, as a copper alloy, has positive properties in terms of electrical conductivity and at the same time has a higher strength than copper against mechanical stress.

General ordering data

| | | |
|------------|-----------------------------|--|
| Type | SA 3.00X10.00X1000 CUZN ... | Version |
| Order No. | 0259800000 | Busbar (terminal), silver, Height: 1000 mm, Depth: 3 mm, Brass |
| GTIN (EAN) | 4008190049300 | |
| Qty. | 1 m | |

Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/8 PLUS MC SDR | Version |
| Order No. | 1046370000 | Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00 |
| GTIN (EAN) | 4032248782079 | Weidmueller, To customer specification |
| Qty. | 160 pc(s). | |

| | | |
|------------|----------------------------|---|
| Type | DEK 5/8 MC SDR | Version |
| Order No. | 1856750000 | Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00 |
| GTIN (EAN) | 4032248400867 | Weidmueller, To customer specification |
| Qty. | 160 pc(s). | |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

SchT group marker carrier



The SchT 5 S group tag carriers are clipped directly onto the TS 32 mounting rail (G-rail) or the TS 35 mounting rail (top-hat rail). It is therefore possible to label the terminal strip irrespective of the terminal and the type of terminal. SchT 5 and SchT 5 S are fitted with ESO 5, STR 5 protective strips.

The SchT 7 is a hinged group tag carrier for inlay tags which enables easy access to the clamping screw. The SchT 7 is fitted with ESO 7, STR 7 protective strips or DEK 5.

Inlay tags and protective strips can be found under "Accessories".

General ordering data

| Type | Version |
|------------|---|
| SCHT 7 | |
| Order No. | 0517960000 |
| GTIN (EAN) | 4008190001742 |
| Qty. | 20 pc(s). |
| | SCHT, Terminal marker, 39.3 x 8 mm, Pitch in mm (P): 7.00 |
| | Weidmueller, white |

QL / RSF1+2

Screwable cross-connections are easy to mount and de mount. Thanks to the big contact surface, even high currents can be transmitted with maximum contact reliability.



General ordering data

| Type | Version |
|--------------|--|
| QL 3 RSF1+2 | |
| Order No. | 0267500000 |
| GTIN (EAN) | 4008190116835 |
| Qty. | 50 pc(s). |
| | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 3, Pitch in mm (P): 11.00, Insulated: No, Width: 29 mm |
| Type | Version |
| QL 10 RSF1+2 | |
| Order No. | 0341700000 |
| GTIN (EAN) | 4008190003173 |
| Qty. | 20 pc(s). |
| | Cross-connector (terminal), when screwed in, grey, Number of poles: 10, Pitch in mm (P): 8.00, Insulated: No, Width: 106 mm |
| Type | Version |
| QL 4 RSF1+2 | |
| Order No. | 0267600000 |
| GTIN (EAN) | 4008190174859 |
| Qty. | 50 pc(s). |
| | Cross-connector (terminal), when screwed in, grey, 41 A, Number of poles: 4, Pitch in mm (P): 11.00, Insulated: No, Width: 40 mm |
| Type | Version |
| QL 2 RSF1+2 | |
| Order No. | 0267400000 |
| GTIN (EAN) | 4008190139988 |
| Qty. | 50 pc(s). |
| | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 2, Pitch in mm (P): 11.00, Insulated: No, Width: 18 mm |

SAKS 4/35 USA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

End plate



Current and voltage transformer wiring

Our test disconnect terminal blocks featuring spring and screw connection technology allow you to create all the important converter circuits for measuring current, voltage and power in a safe and sophisticated way.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | TW SAKB/C/T | Version |
| Order No. | 0242920000 | Partition plate (terminal), beige, Height: 75 mm, Width: 3 mm, V-2, PA |
| GTIN (EAN) | 4008190069933 | 66 |
| Qty. | 20 pc(s). | |

Steel



Steel DIN rails are the most widespread on the market. Among metal DIN rails, they have the lowest shortcircuit protection, similar to stainless steel.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | TS 32X15/LL 2M/ST/ZN | Version |
| Order No. | 0514400000 | Terminal rail, Accessories, Steel, galvanic zinc plated and passivated, |
| GTIN (EAN) | 4008190086152 | Width: 2000 mm, Height: 33 mm, Depth: 15 mm, Slit width: 5.20 |
| Qty. | 2 m | mm, Slit length: 25.00 mm |