


RSX LOETST. GSF 5/5**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

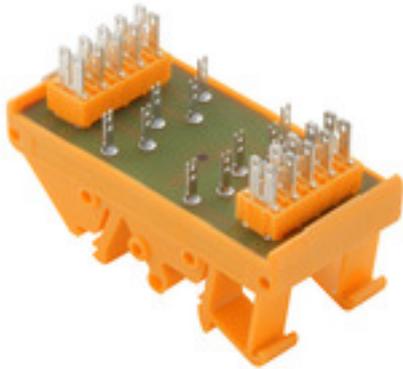

Axial components such as resistors, diodes and capacitors, can be soldered into the RSX component modules. Depending on the version, up to eight components can be soldered into our RSX modules.

General ordering data

Version	Assembly modul, Number of signals: 5
Order No.	0329860000
Type	RSX LOETST. GSF 5/5
GTIN (EAN)	4008 190179373
Qty.	5 pc(s).

RSX LOETST. GSF 5/5

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height of lowest version	53 mm	Width	70 mm
Width (inches)	2.756 inch	Length	35 mm
Length (inches)	1.378 inch	Net weight	36 g

Temperatures

Storage temperature	-40...60 °C	Operating temperature	-40...60
---------------------	-------------	-----------------------	----------

Classifications

ETIM 6.0	EC002780	ETIM 7.0	EC002780
ETIM 8.0	EC002780	ETIM 9.0	EC002780
ECLASS 9.0	27-14-11-52	ECLASS 9.1	27-14-11-52
ECLASS 10.0	27-14-11-52	ECLASS 11.0	27-14-11-52
ECLASS 12.0	27-14-11-52	ECLASS 13.0	27-14-11-52

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	d577b8f5-26ef-4f66-a4a2-3b0818823974

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

Approval/Certificate/Document of Conformity	Declaration of Conformity
Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format


Data sheet

RSX LOETST. GSF 5/5

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

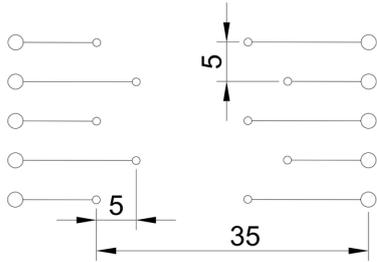

RSX LOETST. GSF 5/5

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Steel



Steel DIN rails are the most widespread on the market. Among metal DIN rails, they have the lowest shortcircuit protection, similar to stainless steel.

General ordering data

Type	TS 32X15 2M/ST/ZN	Version
Order No.	0122800000	Terminal rail, without slot, Accessories, 33 x 15 x 2000 mm, Steel,
GTIN (EAN)	4008190066307	galvanic zinc plated and passivated
Qty.	2 m	

Aluminum



Aluminum has the second best electrical conductivity after copper. One advantage is low weight, anMiscellaneous is outstanding corrosion protection.

General ordering data

Type	TS 35X7.5 2M/AL/BK	Version
Order No.	0330800000	Terminal rail, without slot, Accessories, 35 x 7.5 x 2000 mm,
GTIN (EAN)	4008190100650	Aluminium, untreated
Qty.	2 m	
Type	TS 35X15/2.3 2M/AL/BK	Version
Order No.	1848290000	Terminal rail, without slot, Accessories, 35 x 15 x 2000 mm,
GTIN (EAN)	4032248385614	Aluminium, untreated
Qty.	2 m	


RSX LOETST. GSF 5/5

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Z-Series

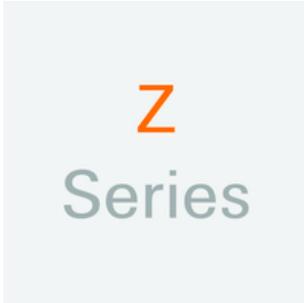

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

General ordering data

Type	ZEW 35	Version
Order No.	9540000000	End bracket, Wemid, dark beige, Rail: TS 35, Snap-on
GTIN (EAN)	4008190956264	
Qty.	20 pc(s).	
Type	ZEW 35/2	Version
Order No.	8630740000	End bracket, Wemid, dark beige, Rail: TS 35, Snap-on
GTIN (EAN)	4032248348916	
Qty.	20 pc(s).	

SAK-Series



Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

General ordering data

Type	EW 35	Version
Order No.	0383560000	End bracket, Wemid, beige, Rail: TS 35, when screwed in
GTIN (EAN)	4008190181314	
Qty.	50 pc(s).	
Type	EW 35/SCHA/M3	Version
Order No.	0258660000	End bracket, Wemid, beige, Rail: TS 35, when screwed in
GTIN (EAN)	4008190033477	
Qty.	20 pc(s).	
Type	EW 35 GR 7032	Version
Order No.	0383530000	End bracket, Wemid, grey, Rail: TS 35, when screwed in
GTIN (EAN)	4008190027322	
Qty.	50 pc(s).	

RSX LOETST. GSF 5/5

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

W-Series



Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

General ordering data

Type	WEW 35/1	Version
Order No.	1059000000	End bracket, Wemid, dark beige, Rail: TS 35, when screwed in
GTIN (EAN)	4008190172282	
Qty.	50 pc(s).	
Type	WEW 35/2	Version
Order No.	1061200000	End bracket, Wemid, dark beige, Rail: TS 35, when screwed in
GTIN (EAN)	4008190030230	
Qty.	50 pc(s).	

Plastic



Plastic DIN rails have insulating properties and are very light. They can be used where clearance and creepage distances to the support bracket cannot be achieved with standard DIN rails.

General ordering data

Type	TSK 35X15 2M PVC/GR	Version
Order No.	0514300000	Terminal rail, without slot, Accessories, 35 x 15 x 2000 mm, PVC,
GTIN (EAN)	4008190052263	untreated
Qty.	2 m	

RSX LOETST. GSF 5/5

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Steel



Steel DIN rails are the most widespread on the market. Among metal DIN rails, they have the lowest shortcircuit protection, similar to stainless steel.

General ordering data

Type	TS 35X15/LL 2M/ST/ZN	Version
Order No.	0236500000	Terminal rail, with slot, Accessories, 35 x 15 x 2000 mm, Slit width:
GTIN (EAN)	4008190183967	5.20 mm, Slit length: 25.00 mm, Steel, galvanic zinc plated and
Qty.	2 m	passivated
Type	TS 35X7.5 2M/ST/SZ	Version
Order No.	9300090000	Terminal rail, without slot, Accessories, 35 x 7.5 x 2000 mm, Steel,
GTIN (EAN)	4032248296264	galvanic zinc plated and passivated
Qty.	2 m	
Type	TS 35X15/LL 2M/ST/SZ	Version
Order No.	7907490000	Terminal rail, with slot, Accessories, 35 x 15 x 2000 mm, Slit width:
GTIN (EAN)	4032248296262	5.20 mm, Slit length: 25.00 mm, Steel, galvanic zinc plated and
Qty.	2 m	passivated
Type	TS 35X7.5/LL 2M/ST/SZ	Version
Order No.	7915060000	Terminal rail, with slot, Accessories, 35 x 7.5 x 2000 mm, Slit width:
GTIN (EAN)	4032248296279	5.20 mm, Slit length: 25.00 mm, Steel, galvanic zinc plated and
Qty.	2 m	passivated
Type	TS 35X15/LL 1M/ST/ZN	Version
Order No.	0236510000	Terminal rail, with slot, Accessories, 35 x 15 x 1000 mm, Slit width:
GTIN (EAN)	4008190017699	5.20 mm, Slit length: 25.00 mm, Steel, galvanic zinc plated and
Qty.	1 m	passivated
Type	TS 35X15/2.3 2M/ST/ZN	Version
Order No.	0498000000	Terminal rail, without slot, Accessories, 35 x 15 x 2000 mm, Steel,
GTIN (EAN)	4008190042493	galvanic zinc plated and passivated
Qty.	2 m	
Type	TS 35X7.5/LL 1M/ST/ZN	Version
Order No.	0514510000	Terminal rail, with slot, Accessories, 35 x 7.5 x 1000 mm, Slit width:
GTIN (EAN)	4008190116620	5.20 mm, Slit length: 25.00 mm, Steel, galvanic zinc plated and
Qty.	1 m	passivated
Type	TS 35X7.5 2M/ST/ZN	Version
Order No.	0383400000	Terminal rail, without slot, Accessories, 35 x 7.5 x 2000 mm, Steel,
GTIN (EAN)	4008190088026	galvanic zinc plated and passivated
Qty.	2 m	
Type	TS 35X7.5/LL 2M/ST/ZN	Version
Order No.	0514500000	Terminal rail, with slot, Accessories, 35 x 7.5 x 2000 mm, Slit width:
GTIN (EAN)	4008190046019	5.20 mm, Slit length: 25.00 mm, Steel, galvanic zinc plated and
Qty.	2 m	passivated
Type	TS 35X15 2M/ST/ZN	Version
Order No.	0236400000	Terminal rail, without slot, Accessories, 35 x 15 x 2000 mm, Steel,
GTIN (EAN)	4008190114558	galvanic zinc plated and passivated
Qty.	2 m	

RSX LOETST. GSF 5/5

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	TS 35X7.5 1M/ST/ZN	Version
Order No.	0383410000	Terminal rail, without slot, Accessories, 35 x 7.5 x 1000 mm, Steel,
GTIN (EAN)	4008190115623	galvanized, chromium-plated
Qty.	1 m	

TS 32

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

General ordering data

Type	EWK 2	Version
Order No.	0199360000	End bracket, Wemid, beige, Rail: TS 32, when screwed in
GTIN (EAN)	4008190023546	
Qty.	50 pc(s).	

Stainless steel

Stainless steel is a collective term for all types of steel (alloys) with a high degree of purity and corrosion resistance.

General ordering data

Type	TS 35X7.5 2M/CRN	Version
Order No.	1747350000	Terminal rail, without slot, Accessories, 35 x 7.5 x 2000 mm,
GTIN (EAN)	4032248003372	Stainless steel, rust-proof, Stainless steel 1.4301, untreated
Qty.	2 m	

RSX LOETST. GSF 5/5

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Copper



Copper has the best electrical conductivity of all metals used. The copper rail has the highest short-circuit protection.

General ordering data

Type	TS 35X15/2.3 2M/CU/BK	Version
Order No.	0270100000	Terminal rail, without slot, Accessories, 35 x 15 x 2000 mm, Copper,
GTIN (EAN)	4008190105136	untreated
Qty.	2 m	