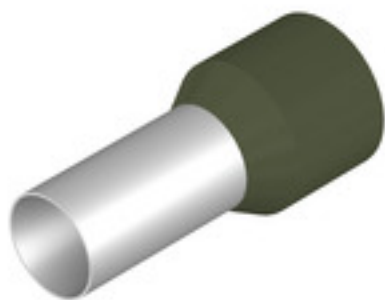


**H50,0/36 OLIV****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

**General ordering data**

Version	Wire-end ferrule, Standard, 26 mm, 20 mm, Olive green
Order No.	<a href="#">0444200000</a>
Type	H50,0/36 OLIV
GTIN (EAN)	4008190110284
Qty.	50 pc(s).
Packaging	loose

**H50,0/36 OLIV****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Technical data****Dimensions and weights**

Net weight	2.8 g
------------	-------

**Technical data**

Description of article	Wire end ferrule with plastic collar, olive green	Version	Standard
------------------------	---	---------	----------

**Wire-end ferrules**

Collar diameter (D2)	15 mm	Colour code	Weidmüller
Conductor cross-section	50 mm <sup>2</sup>	Contact surface diameter (D1)	10.3 mm
Contact surface length (L2)	20 mm	L1 in mm	36 mm
Metal sleeve thickness (S1)	0.3 mm	Plastic collar thickness (S2)	0.5 mm
Stripping length	26 mm	Wire connection cross section AWG, max.	AWG 1

**Classifications**

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ETIM 9.0	EC000005
ECLASS 9.0	27-40-02-01	ECLASS 9.1	27-40-02-01
ECLASS 10.0	27-40-02-01	ECLASS 11.0	27-40-02-01
ECLASS 12.0	27-40-02-01	ECLASS 13.0	27-40-02-01

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E499744

**Downloads**

Engineering Data	<a href="#">CAD data – STEP</a>
Engineering Data	<a href="#">Zuken E3.S</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	

## H50,0/36 OLIV

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Drawings

## Drawing

