

**IE-BS-V01P-RJ45-FJ-A****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Bayonet plug-in connector sets according to IEC  
61076-3-106 ver.1 (Ethernet/IP), RJ45 plastic insert incl.  
RJ45 insert

**General ordering data**

Version	Flange RJ45, IP67, Variant 1 metal, IDC, EIA/TIA 586 A, Cat.6 <sub>A</sub> / Class E <sub>A</sub> (ISO/IEC 11801 2010)
Order No.	<a href="#">1012380000</a>
Type	IE-BS-V01P-RJ45-FJ-A
GTIN (EAN)	4032248720033
Qty.	10 pc(s).

**IE-BS-V01P-RJ45-FJ-A****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Technical data****Dimensions and weights**

Net weight	3.5 g
------------	-------

**Temperatures**

Operating temperature	-40 °C...70 °C
-----------------------	----------------

**General data**

Connection 1	RJ45	Connection 2	IDC
Description of article	Variant 1 metal, IDC, EIA/TIA 586 A	Wiring	TIA-568A
Seal material	NBR	Housing main material	PA UL 94 V0
Insulation cross-section, max.	1.6 mm	Category	Cat.6 <sub>A</sub> / Class E <sub>A</sub> (ISO/IEC 11801 2010)
Contact surface	Gold over nickel	Connection diameter, solid	0.4...0.64 mm
Conductor connection cross-section, solid (AWG)	AWG 24...AWG 22	Connection diameter, flexible	0.48...0.76 mm
Conductor connection cross-section, flexible (AWG)	AWG 26...AWG 22	Shielding	360°; all-round enclosure
Protection degree	IP67	Plugging cycles	750

**Electrical properties**

Dielectric strength, contact / contact PoE / PoE+	≥ 1000 V AC/DC conforming to IEEE 802.3bt	Dielectric strength, contact / shield	≥ 1500 V AC/DC
---	---	---------------------------------------	----------------

**General standards**

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-106 Var. 1, IEC 60603-7-51
-------------------------	---------	--------------------	--

**Classifications**

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ETIM 9.0	EC001121
ECLASS 9.0	27-44-03-90	ECLASS 9.1	27-44-03-90
ECLASS 10.0	27-44-03-90	ECLASS 11.0	27-44-03-90
ECLASS 12.0	27-44-03-90	ECLASS 13.0	27-44-03-90
ECLASS 14.0	27-44-03-90		

**Environmental Product Compliance**

REACH SVHC	6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	11b17e97-f803-4c09-9278-b20f22f15f81
RoHS Compliance Status	Compliant without exemption

**IE-BS-V01P-RJ45-FJ-A****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Approvals**

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E316369

**Downloads**

Approval/Certificate/Document of Conformity	<a href="#">DUXR.E316369</a>
Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Designation key / Type key</a> <a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">MB FREECONTACT EN</a> <a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>


## IE-BS-V01P-RJ45-FJ-A

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)


## Drawings

### Installation cut-out

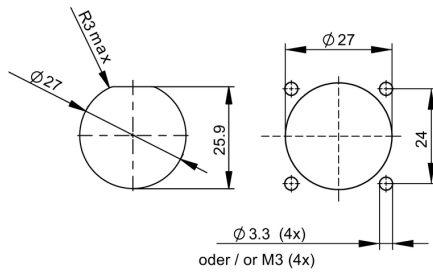

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

### Detailed drawing

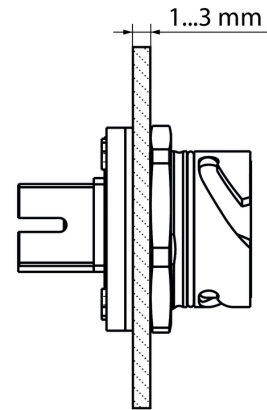

Wall thickness when using the central screw connection

**IE-BS-V01P-RJ45-FJ-A****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Dust caps**

For protecting your devices against dust and dirt.

**General ordering data**

Type	IE-BP-V01P	Version
Order No.	<a href="#">1965700000</a>	Flange-mounted housing, protective cap
GTIN (EAN)	4032248653928	
Qty.	10 pc(s).	