

IE-PH-V01P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Bayonet plug-in connectors according to IEC
61076-3-106 ver.1 (Ethernet/IP), plastic, empty housing

General ordering data

Version	Empty enclosure, Plug housing, IP67
Order No.	1012440000
Type	IE-PH-V01P
GTIN (EAN)	4032248720095
Qty.	10 pc(s).

IE-PH-V01P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Depth	77.5 mm	Depth (inches)	3.051 inch
Height	30 mm	Height (inches)	1.181 inch
Width	30	Width (inches)	1.181 inch
Net weight	2.4 g		

Temperatures

Operating temperature	-40 °C...70
-----------------------	-------------

General data

Colour		Configuration	Plug housing with labelling/marketing holder: 9*11 mm; suitable for holding RJ45 and fibre-optic inserts
	Miscellaneous		
Housing main material	PA UL 94 V0	Plugging cycles	750
Protection degree	IP67		

General standards

Connector standard	IEC 61076-3-106 Var. 1
--------------------	------------------------

Classifications

ETIM 6.0	EC001031	ETIM 7.0	EC001031
ETIM 8.0	EC001031	ETIM 9.0	EC001031
ECLASS 9.0	27-18-27-02	ECLASS 9.1	27-18-27-02
ECLASS 10.0	27-18-27-02	ECLASS 11.0	27-18-27-02
ECLASS 12.0	27-18-27-02	ECLASS 13.0	27-19-01-04
ECLASS 14.0	27-19-01-04		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	11b17e97-f803-4c09-9278-b20f22f15f81

Approvals

ROHS	Conform
------	---------

IE-PH-V01P

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Approval/Certificate/Document of Con-
formity

[DUXR.E316369](#)

Engineering Data

[CAD data – STEP](#)

Product Change Notification

[20210412 Technical change for cap nut V1 and V4](#)

[20210412 Technische Änderung zu Hutmutter V1 und V4](#)

User Documentation

[MAN IE GUIDE DE](#)

[MAN IE GUIDE EN](#)

[Designation key / Type key](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures

[MB FREECONTACT EN](#)

[FL FIELDWIRING EN](#)

[PI PROFINET CABLING EN](#)

[PI PROFINET CABLING EN](#)


IE-PH-V01P

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

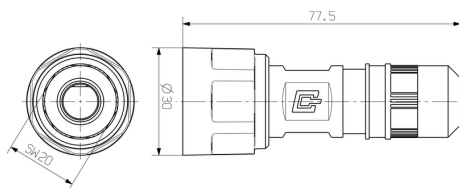

IE-PH-V01P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****RJ45**RJ45 inserts for plug-in connectors ver.1 / 4 / 5 / 14,
HDC and junction boxes IE-OM...; IE-OP...; IE-CC...**General ordering data**

Type	IE-PI-RJ45-FH	Version
Order No.	1962730000	Plug insert RJ45 IDC, Plug insert RJ45, no tools required, TIA-568A,
GTIN (EAN)	4032248654017	EIA/TIA T568 B, PROFINET
Qty.	10 pc(s).	
Type	IE-PI-RJ45-TH	Version
Order No.	1962720000	Plug insert RJ45 IDC, Plug insert RJ45, crimp
GTIN (EAN)	4032248644834	
Qty.	10 pc(s).	

LWL-LC

FO LC inserts for plug-in connectors ver.1 / 4 / 14

General ordering data

Type	IE-PI-2LC-MM	Version
Order No.	1962780000	LC insert, Plug insert 2 LC, multimode
GTIN (EAN)	4032248644865	
Qty.	10 pc(s).	
Type	IE-PI-2LC-SM	Version
Order No.	1962790000	LC insert, Plug insert 2 LC, singlemode
GTIN (EAN)	4032248644872	
Qty.	10 pc(s).	

IE-PH-V01P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****LWL-SC**

FO SC inserts for plug-in connectors ver.1 / 4 / 14

**General ordering data**

Type	IE-PI-SCRJ-SM	Version
Order No.	1067390000	SC insert, Plug SCRJ, singlemode
GTIN (EAN)	4032248820863	
Qty.	10 pc(s).	
Type	IE-PI-2SC-MM	Version
Order No.	1962750000	SC insert, Plug insert 2 SC, multimode
GTIN (EAN)	4032248644841	
Qty.	10 pc(s).	
Type	IE-PI-2SC-SM	Version
Order No.	1962760000	SC insert, Plug insert 2 SC, singlemode
GTIN (EAN)	4032248654000	
Qty.	10 pc(s).	
Type	IE-PI-2SC-POF	Version
Order No.	1962770000	SC insert, Plug insert 2 SC, multimode
GTIN (EAN)	4032248644858	
Qty.	10 pc(s).	
Type	IE-PI-SCRJ-POF	Version
Order No.	1067410000	SC insert, Plug SCRJ, POF
GTIN (EAN)	4032248820870	
Qty.	10 pc(s).	

IE-PH-V01P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Blank**

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ESG 9/11 K MC NE WS	Version
Order No.	1857440000	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive
GTIN (EAN)	4032248402731	
Qty.	200 pc(s).	

Dust caps

For protecting your devices against dust and dirt.

General ordering data

Type	IE-PP-V01P	Version
Order No.	1965690000	Plug housing protective cap
GTIN (EAN)	4032248653911	
Qty.	10 pc(s).	

IE-PH-V01P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Hybrid**

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14

**General ordering data**

Type	IE-PI-HYB-10P	Version
Order No.	1068990000	Insert, for plug insert, Hybrid
GTIN (EAN)	4032248823963	
Qty.	1 pc(s).	
Type	IE-PIC-HYB-S-O,5-300	Version
Order No.	1096180000	Crimp contact, for plug insert, Hybrid
GTIN (EAN)	4032248869152	
Qty.	300 pc(s).	

Empty housings

HDC plug-in connector according to IEC 61076-3-106 ver.5 in metal, empty housing

**General ordering data**

Type	IE-PH-V05M	Version
Order No.	1962540000	Empty enclosure, Plug housing, Variant 5 to IEC 61076-3-106, IP67
GTIN (EAN)	4032248644674	
Qty.	10 pc(s).	