

IE-OP-V04P-1S**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



Junction box, design for PushPull plug-in connectors ver.4
according to IEC 61076-3-106, plastic

General ordering data

Version	Wall-mounted junction box, IP67, Variant 4 to IEC 61076-3-106
Order No.	1045780000
Type	IE-OP-V04P-1S
GTIN (EAN)	4032248779963
Qty.	10 pc(s).

IE-OP-V04P-1S**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Depth	106.9 mm	Depth (inches)	4.209 inch
Height	61.6 mm	Height (inches)	2.425 inch
Width	41.8 mm	Width (inches)	1.646 inch
Net weight	6.5 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Colour	black	Housing main material	PA
Plugging cycles	750	Protection degree	IP67
Type of mounting	Floor-mounted, for exposed connections, Wall mounting	UL 94 flammability rating	V-0

General standards

Connector standard	IEC 61076-3-106 Var. 4
--------------------	------------------------

Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-03-92
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-OP-V04P-1S

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

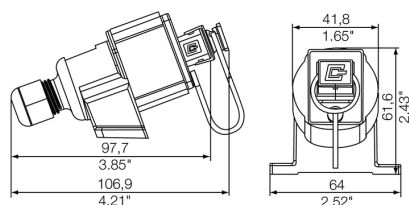

IE-OP-V04P-1S

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

RJ45

RJ45 inserts for plug-in connectors ver.1 / 4 / 5 / 14,
HDC and junction boxes IE-OM...; IE-OP...; IE-CC...



General ordering data

Type	IE-BI-RJ45-FJ-P	Version
Order No.	1963830000	RJ45 insert socket, Connector for base, PROFINET
GTIN (EAN)	4032248646159	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-A	Version
Order No.	1962850000	RJ45 insert socket, Connector for base, TIA-568A
GTIN (EAN)	4032248645053	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-B	Version
Order No.	1963840000	RJ45 insert socket, Connector for base, TIA-568B
GTIN (EAN)	4032248651894	
Qty.	10 pc(s).	

Sets - RJ45

PushPull plug-in connector set according to IEC
61076-3-106 ver.4 (IEC24702), plastic with RJ45 insert



General ordering data

Type	IE-PS-V04P-RJ45-FH	Version
Order No.	1963160000	RJ45 plug, no tools required, Version 4, Cat.6 _A / Class E _A (ISO/IEC 11801 2010)
GTIN (EAN)	4032248651665	
Qty.	10 pc(s).	