

IE-CC-V04P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

PushPull plug-in connector according to IEC
61076-3-106 ver.4 (IEC24702), plastic, empty housing

General ordering data

| | |
|------------|--|
| Version | Coupling, IP67, Variant 4 to IEC 61076-3-106 |
| Order No. | 1045960000 |
| Type | IE-CC-V04P |
| GTIN (EAN) | 4032248781072 |
| Qty. | 10 pc(s). |

IE-CC-V04P

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

| | | | |
|------------|----------|-----------------|------------|
| Depth | 109.3 mm | Depth (inches) | 4.303 inch |
| Height | 41.8 mm | Height (inches) | 1.646 inch |
| Width | 41.8 mm | Width (inches) | 1.646 inch |
| Net weight | 5.8 g | | |

Temperatures

| | |
|-----------------------|----------------|
| Operating temperature | -40 °C...70 °C |
|-----------------------|----------------|

General data

| | | | |
|------------------|---|---------------------------|-------------|
| Colour | black | Housing main material | PA UL 94 V0 |
| Plugging cycles | 750 | Protection degree | IP67 |
| Type of mounting | Floor-mounted, for exposed connections, Wall mounting | UL 94 flammability rating | V-0 |

General standards

| | |
|--------------------|------------------------|
| Connector standard | IEC 61076-3-106 Var. 4 |
|--------------------|------------------------|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC000437 | ETIM 7.0 | EC000437 |
| ETIM 8.0 | EC000437 | ETIM 9.0 | EC000437 |
| ECLASS 9.0 | 27-44-02-02 | ECLASS 9.1 | 27-44-03-92 |
| ECLASS 10.0 | 27-44-02-02 | ECLASS 11.0 | 27-44-02-02 |
| ECLASS 12.0 | 27-44-02-02 | ECLASS 13.0 | 27-44-02-02 |

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads

| | |
|--------------------|--|
| Engineering Data | CAD data – STEP |
| User Documentation | MAN IE GUIDE DE MAN IE GUIDE EN |
| Catalogues | Catalogues in PDF-format |
| Brochures | MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN |


IE-CC-V04P

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

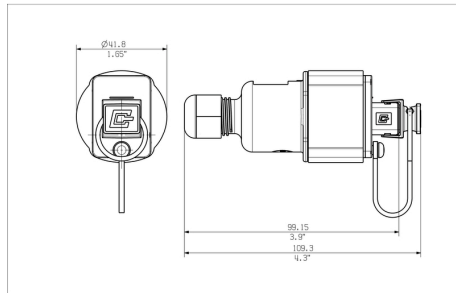

IE-CC-V04P

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | ESG 9/11 K MC NE WS | Version |
| Order No. | 1857440000 | ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive |
| GTIN (EAN) | 4032248402731 | |
| Qty. | 200 pc(s). | |

RJ45



RJ45 inserts for plug-in connectors ver.1 / 4 / 5 / 14, HDC and junction boxes IE-OM...; IE-OP...; IE-CC...

General ordering data

| | | |
|------------|----------------------------|--|
| Type | IE-BI-RJ45-FJ-P | Version |
| Order No. | 1963830000 | RJ45 insert socket, Connector for base, PROFINET |
| GTIN (EAN) | 4032248646159 | |
| Qty. | 10 pc(s). | |
| Type | IE-BI-RJ45-FJ-A | Version |
| Order No. | 1962850000 | RJ45 insert socket, Connector for base, TIA-568A |
| GTIN (EAN) | 4032248645053 | |
| Qty. | 10 pc(s). | |
| Type | IE-BI-RJ45-FJ-B | Version |
| Order No. | 1963840000 | RJ45 insert socket, Connector for base, TIA-568B |
| GTIN (EAN) | 4032248651894 | |
| Qty. | 10 pc(s). | |