

**IE-OP-V01P-1S****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Junction box, design for bayonet plug-in connectors ver.1  
according to IEC 61076-3-106, plastic

**General ordering data**

Version	Wall-mounted junction box, IP67, Variant 1 to IEC 61076-3-106
Order No.	<a href="#">1061830000</a>
Type	IE-OP-V01P-1S
GTIN (EAN)	4032248811182
Qty.	10 pc(s).

**IE-OP-V01P-1S****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Depth	114 mm	Depth (inches)	4.488 inch
Height	65.2 mm	Height (inches)	2.567 inch
Width	41.8 mm	Width (inches)	1.646 inch
Net weight	74 g		

**Temperatures**

Operating temperature	-40 °C...70 °C
-----------------------	----------------

**General data**

Colour	black	Housing main material	PA UL 94 V0
Plugging cycles	750	Protection degree	IP67
Type of mounting	Floor-mounted, for exposed connections, Wall mounting	UL 94 flammability rating	V-0

**General standards**

Connector standard	IEC 61076-3-106 Var. 1
--------------------	------------------------

**Classifications**

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-03-92
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">MB FREECONTACT EN</a> <a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>


## IE-OP-V01P-1S

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

### Dimensioned drawing

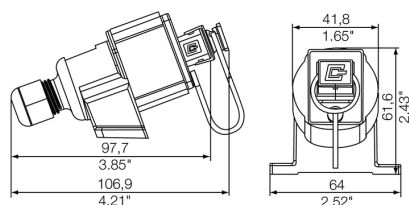

## IE-OP-V01P-1S

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Sets - RJ45



Bayonet plug-in connector sets according to IEC 61076-3-106 ver.1 (EtherNet/IP), RJ45 plastic insert incl. RJ45 insert

## General ordering data

Type	IE-PS-V01P-RJ45-FH	Version
Order No.	<a href="#">1012490000</a>	RJ45 plug, no tools required, Variant 1 plastic, Cat.6 <sub>A</sub> / Class E <sub>A</sub> (ISO/
GTIN (EAN)	4032248720132	IEC 11801 2010)
Qty.	10 pc(s).	

## RJ45



RJ45 inserts for plug-in connectors ver.1 / 4 / 5 / 14, HDC and junction boxes IE-OM...; IE-OP...; IE-CC...

## General ordering data

Type	IE-BI-RJ45-FJ-B	Version
Order No.	<a href="#">1963840000</a>	RJ45 insert socket, Connector for base, TIA-568B
GTIN (EAN)	4032248651894	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-P	Version
Order No.	<a href="#">1963830000</a>	RJ45 insert socket, Connector for base, PROFINET
GTIN (EAN)	4032248646159	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-A	Version
Order No.	<a href="#">1962850000</a>	RJ45 insert socket, Connector for base, TIA-568A
GTIN (EAN)	4032248645053	
Qty.	10 pc(s).	