

**IE-BSC-V14M-SCRJ-SM-C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

PushPull plug-in connector set according to IEC  
61076-3-117 ver.14 (PROFINET), metal incl. SC insert

**General ordering data**

Version	Flange FO, IP67, Variant 14 central cable gland, SCRJ Duplex coupling, Singlemode
Order No.	<a href="#">1062600000</a>
Type	IE-BSC-V14M-SCRJ-SM-C
GTIN (EAN)	4032248813315
Qty.	10 pc(s).

## IE-BSC-V14M-SCRJ-SM-C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	36.15 mm	Depth (inches)	1.423 inch
Height	39.6 mm	Height (inches)	1.559 inch
Width	39.6 mm	Width (inches)	1.559 inch
Net weight	55.81 g		

## Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

## General data

Colour	Miscellaneous	Connection 1	SCRJ
Connection 2		Description of article	Variant 14 central cable gland, SCRJ Duplex coupling
	SCRJ		
Fibre type	Singlemode	Housing main material	Zinc diecast
Insertion loss	≤ 0.5 dB	Plugging cycles	500
Protection degree	IP67	Return loss (attenuation)	≥ 40 dB

## General standards

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-117 Var. 14, IEC 61754-24
-------------------------	---------	--------------------	---------------------------------------

## Classifications

ETIM 6.0	EC001122	ETIM 7.0	EC001122
ETIM 8.0	EC001122	ETIM 9.0	EC001122
ECLASS 9.0	19-17-01-22	ECLASS 9.1	19-17-01-22
ECLASS 10.0	19-17-01-22	ECLASS 11.0	19-17-01-22
ECLASS 12.0	19-17-01-22	ECLASS 13.0	19-17-01-22

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	4f3aae94-c2bc-4010-b63b-5b114ba6bd55

## Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E316369

## IE-BSC-V14M-SCRJ-SM-C

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Technical data

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">PROFINET Manufacturer's Declaration</a>
Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Designation key / Type key</a> <a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>


## IE-BSC-V14M-SCRJ-SM-C

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Drawings

## Installation cut-out

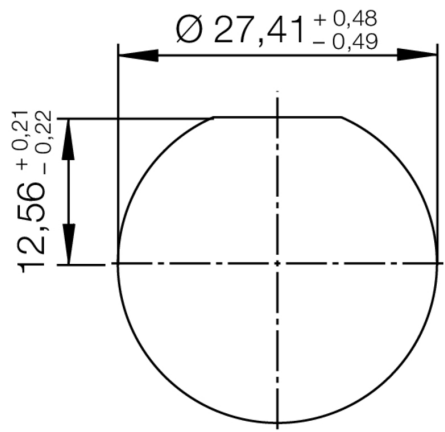

**IE-BSC-V14M-SCRJ-SM-C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Dust caps**

For protecting your devices against dust and dirt.

**General ordering data**

Type	IE-BP-V14P	Version
Order No.	<a href="#">1058310000</a>	Flange-mounted housing, protective cap
GTIN (EAN)	4032248799404	
Qty.	10 pc(s).	