

IE-PI-SCRJ-POF**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

FO SC inserts for plug-in connectors ver.1 / 4 / 14

General ordering data

Version	SC insert, Plug SCRJ, POF
Order No.	1067410000
Type	IE-PI-SCRJ-POF
GTIN (EAN)	4032248820870
Qty.	10 pc(s).

Creation date August 29, 2024 7:05:00 AM CEST

Catalogue status 17.08.2024 / We reserve the right to make technical changes.

IE-PI-SCRJ-POF

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	56 mm	Depth (inches)	2.205 inch
Height	10.5 mm	Height (inches)	0.413 inch
Width	13.2 mm	Width (inches)	0.52 inch
Net weight	18.7 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Colour		Configuration	Connector and flange insert for variant 1, 4 and 14 housings
	Miscellaneous		
Connection 1	SCRJ	Connection 2	Crimp
Description of article	Plug SCRJ, POF	Ferrule material	Arcap
Fibre type	POF	Housing main material	Zinc diecast, PA
Insertion loss	≤ 1.0 dB	Plugging cycles	1000
Protection degree	IP67 with housing		

General standards

Certificate No. (UL)	E477798	Connector standard	IEC 61754-24
----------------------	---------	--------------------	--------------

Classifications

ETIM 6.0	EC001122	ETIM 7.0	EC001122
ETIM 8.0	EC001122	ETIM 9.0	EC001122
ECLASS 9.0	19-17-01-22	ECLASS 9.1	19-17-01-22
ECLASS 10.0	19-17-01-22	ECLASS 11.0	19-17-01-22
ECLASS 12.0	19-17-01-22	ECLASS 13.0	19-17-01-22
ECLASS 14.0	19-17-01-22		

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	67cf1078-beca-4687-860b-dc475a6ec24a
RoHS Compliance Status	Compliant

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (UL)	E477798

IE-PI-SCRJ-POF

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Approval/Certificate/Document of Conformity	PROFINET Manufacturer's Declaration
Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key Manual
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-PI-SCRJ-POF

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

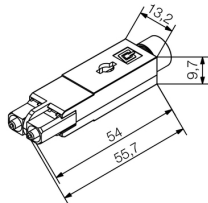

IE-PI-SCRJ-POF

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

...for fiber-optic connectors SC, ST & LC



GOF

- For fibre-optic SC/ST, IP 20 and IP 67 connectors
- For fibre-optic LC and IP 67 connectors

POF

- For polymer fibre-optic SC/ST, IP 20 and IP 67 connectors
- For fibre-optic, Profinet and Mobil cable SC/ST and IP 67 connectors

General ordering data

Type	IE-CT-SC-GOF-P	Version
Order No.	9205350000	Pressing tool
GTIN (EAN)	4032248725489	
Qty.	1 pc(s).	
Type	IE-CT-SC-GOF	Version
Order No.	9205320000	Pressing tool
GTIN (EAN)	4032248725458	
Qty.	1 pc(s).	

LWL-SC

FO SC inserts for plug-in connectors ver.1 / 4 / 14



General ordering data

Type	IE-SCRJ-IP67-POF-100	Version
Order No.	1278430000	FO connector, Replacement crimp barrel, IP67 with housing
GTIN (EAN)	4050118069136	
Qty.	100 pc(s).	

IE-PI-SCRJ-POF**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****...for fibre-optic cable with polymer optic fibres (POF)**

Crimping and stripping tools for processing the fibre-optic-cable contacts of polymer optical fibres (POF)

General ordering data

Type	HTX-IE-POF	Version
Order No.	1208870000	Pressing tool
GTIN (EAN)	4032248990269	
Qty.	1 pc(s).	

Crimp Sets

Crimp sets

General ordering data

Type	TOOL SET IE-POF	Version
Order No.	1208930000	Crimping tool: HTX-IE-POF, Stripping tool: Multi-Stripax IE-POF
GTIN (EAN)	4032248990283	
Qty.	1 pc(s).	