

IE-PIC-HYB-S-0,75-300**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14

General ordering data

| | |
|------------|--|
| Version | Crimp contact, for plug insert, Hybrid |
| Order No. | 1068950000 |
| Type | IE-PIC-HYB-S-0,75-300 |
| GTIN (EAN) | 4032248823109 |
| Qty. | 300 pc(s). |

IE-PIC-HYB-S-0,75-300**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

| | |
|------------|--------|
| Net weight | 0.27 g |
|------------|--------|

General data

| | | | |
|--|----------------------|--|----------------------|
| Wire connection cross section, finely stranded, max. | 0.75 mm ² | Wire connection cross section, finely stranded, min. | 0.75 mm ² |
|--|----------------------|--|----------------------|

Electrical properties

| | |
|---------------|------|
| Rated voltage | 24 V |
|---------------|------|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC001121 | ETIM 7.0 | EC001121 |
| ETIM 8.0 | EC001121 | ETIM 9.0 | EC001121 |
| ECLASS 9.0 | 27-44-03-90 | ECLASS 9.1 | 27-44-09-90 |
| ECLASS 10.0 | 27-44-03-90 | ECLASS 11.0 | 27-44-03-90 |
| ECLASS 12.0 | 27-44-03-90 | ECLASS 13.0 | 27-44-03-90 |
| ECLASS 14.0 | 27-44-03-90 | | |

Environmental Product Compliance

| | |
|------------------------|----------------|
| REACH SVHC | Lead 7439-92-1 |
| RoHS Compliance Status | Compliant |

Important note

| | |
|---------------------|--|
| Product information | Hybrid, 10-pole. Inserts for plug-in connectors Variant 14 |
|---------------------|--|

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads

| | |
|--------------------|---|
| User Documentation | MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key |
| Catalogues | Catalogues in PDF-format |
| Brochures | FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN |


IE-PIC-HYB-S-0,75-300

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

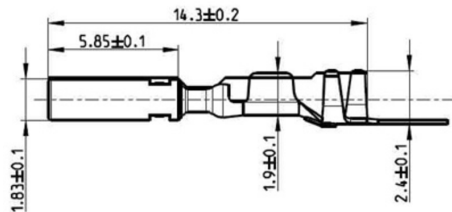

IE-PIC-HYB-S-0,75-300**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Crimping tools****Crimping tools for Weidmüller contacts for RSV and DSTV-HD systems**

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation
- With end stop for exact positioning of the contacts

General ordering data

| | | |
|------------|----------------------------|---|
| Type | HTF HYB | Version |
| Order No. | 1119580000 | Pressing tool, Crimping tool for contacts, 0.08mm ² , 1mm ² , |
| GTIN (EAN) | 4032248900626 | FoderBcrimp |
| Qty. | 1 pc(s). | |