

IE-PS-V05M-A-RJ45-FH**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

HDC plug-in connector set according to IEC 61076-3-106
ver.5 in metal, with RJ45 insert

General ordering data

Version	RJ45 plug, no tools required, Cat.6 _A / Class E _A (ISO/IEC 11801 2010)
Order No.	1077300000
Type	IE-PS-V05M-A-RJ45-FH
GTIN (EAN)	4032248834914
Qty.	10 pc(s).

IE-PS-V05M-A-RJ45-FH

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	79 g
------------	------

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Connection 1	RJ45	Connection 2	IDC
Colour	black	Housing main material	diecast aluminium
Insulation cross-section, min.	0.85 mm	Insulation cross-section, max.	1.6 mm
Category	Cat.6A / Class E _A (ISO/IEC 11801 2010)	Contact surface	Gold over nickel
Connection diameter, solid	0.4...0.64 mm	Connection diameter, flexible	0.48...0.76 mm
MICE classification M	M ₃	MICE classification I	I ₃
MICE classification C	C ₁	MICE classification E	E ₃
Sheath diameter, min.	5 mm	Sheath diameter, max.	10 mm
Shielding	360°; shield contact	Protection degree	IP67
Plugging cycles	750	Ability to reconnect	≥ 10 cycles (for the same or larger cross-section)

Electrical properties

Dielectric strength, contact / contact	≥ 1000 V AC/DC	Dielectric strength, contact / shield	≥ 1500 V AC/DC
--	----------------	---------------------------------------	----------------

General standards

Application-specific communication cable facilities	PROFINET installation instructions	Connector standard	IEC 61076-3-106 Var. 5, IEC 60603-7-51
---	------------------------------------	--------------------	--

Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ETIM 9.0	EC001121
ECLASS 9.0	27-44-03-90	ECLASS 9.1	27-44-03-90
ECLASS 10.0	27-44-03-90	ECLASS 11.0	27-44-03-90
ECLASS 12.0	27-44-03-90	ECLASS 13.0	27-44-03-90
ECLASS 14.0	27-44-03-90		

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	4f3aae94-c2bc-4010-b63b-5b114ba6bd55
RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6bl, 6c

Approvals

ROHS	Conform
------	---------

IE-PS-V05M-A-RJ45-FH

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Downloads

Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN FL FIELDWIRING EN PI PROFINET CABLING EN


IE-PS-V05M-A-RJ45-FH

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

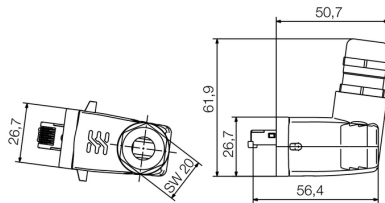

IE-PS-V05M-A-RJ45-FH**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Dust caps**

For protecting your devices against dust and dirt.

General ordering data

Type	IE-PP-V05M	Version
Order No.	1968920000	Flange-mounted housing, protective cap
GTIN (EAN)	4032248692668	
Qty.	1 pc(s).	