

**HDC IP68 06B TSS 1M20****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**IP68**

The new RockStar® enclosures are resistant to seawater and offer a high degree of shock resistance, meet IP 68 and IP 69K, and have been developed for use under extreme environmental conditions and designed for the high vibration requirements acc. to DIN EN 61373 cat. 2 (bogie). As such, this housing family is ideally suited for fault- and maintenance-free operation of heavy-duty connectors in transport and traffic engineering as well as in power engineering and in applications with extreme requirements. During development, measures were also implemented to make the enclosures extremely EMC-resistant.

**General ordering data**

|            |  |
|------------|--|
| Version    | HDC enclosures, Size: 3, Protection degree: IP68 (in plugged condition), IP66 (in plugged condition), IP69K, Plug housing, Clamping yoke connection, Standard, Size of cable entries: M 20 |
| Order No.  | <a href="#">1082510000</a>   |
| Type       | HDC IP68 06B TSS 1M20  |
| GTIN (EAN) | 4032248845774  |
| Qty.       | 1 pc(s).   |

Creation date July 25, 2024 9:46:57 AM CEST

Catalogue status 13.07.2024 / We reserve the right to make technical changes.

## HDC IP68 06B TSS 1M20

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

|            |          |                 |            |
|------------|----------|-----------------|------------|
| Height     | 100.5 mm | Height (inches) | 3.957 inch |
| Width      | 58 mm    | Width (inches)  | 2.283 inch |
| Net weight | 467 g    |                 |            |

## Temperatures

|                   |                   |
|-------------------|-------------------|
| Limit temperature | -50 °C ... 125 °C |
|-------------------|-------------------|

## Dimensions

|             |           |
|-------------|-----------|
| Cable entry | w. thread |
|-------------|-----------|

## General data

|                             |                             |                       |   |
|-----------------------------|-----------------------------|-----------------------|---|
| EMC housings                | Yes                         | Housing main material | diecast aluminium   |
| Material of locking element |                             | Protection degree     | IP68 (in plugged condition), IP66 (in plugged condition), IP69K |
|                             | Stainless steel, rust-proof |                       |   |
| Surface finish              | Powder coating              | Tightening torque     | 6.5 Nm  |

## Version

|                              |                          |                                |                    |
|------------------------------|--------------------------|--------------------------------|--------------------|
| BG                           | 3                        | Cable entry                    | w. thread          |
| Clamp version                | Clamping yoke connection | Colour (RAL)                   | RAL 9011, RAL 9005 |
| Design                       | Standard                 | Design of housing              | Plug housing       |
| Design of locking system     | Clamping yoke connection | Internal thread                | M 20               |
| Number of cable entry on top | 0                        | Number of cable entry sideways | 1                  |
| Size                         | 3                        | Size of cable entries          | M 20               |
| Suitable for ModuPlug®       | Yes                      | Tightening torque              | 6.5 Nm             |
| Top part/bottom part/lid     | upper part               | Type                           | Plug               |

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC000437    | ETIM 7.0    | EC000437    |
| ETIM 8.0    | EC000437    | ETIM 9.0    | EC000437    |
| ECLASS 9.0  | 27-44-02-02 | ECLASS 9.1  | 27-44-02-02 |
| ECLASS 10.0 | 27-44-02-02 | ECLASS 11.0 | 27-44-02-02 |
| ECLASS 12.0 | 27-44-02-02 | ECLASS 13.0 | 27-44-02-02 |

|                     |                         |
|---------------------|-------------------------|
| Substance           | Acetone                 |
| Chemical resistance | Resistant               |
| Substance           | Diesel oil              |
| Chemical resistance | Unstable                |
| Substance           | Ethyl alcohol           |
| Chemical resistance | Resistant               |
| Substance           | Transmission oil        |
| Chemical resistance | Conditionally resistant |
| Substance           | Hydraulic oil           |
| Chemical resistance | Conditionally resistant |
| Substance           | Petroleum benzine       |

**HDC IP68 06B TSS 1M20****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Technical data**

|                     |                         |
|---------------------|-------------------------|
| Chemical resistance | Unstable                |
| Substance           | Sweat                   |
| Chemical resistance | Conditionally resistant |
| Substance           | Premium gasoline        |
| Chemical resistance | Unstable                |
| Substance           | Water                   |
| Chemical resistance | Resistant               |
| Substance           | UV                      |
| Chemical resistance | Resistant               |
| Substance           | Ozone                   |
| Chemical resistance | Resistant               |

**Environmental Product Compliance**

REACH SVHC

/

Chemical resistance

de.myview.objectmodel.impl.BlockImpl@61daf09f de.myview.objectmodel.impl.BlockImpl@5291771c  
 de.myview.objectmodel.impl.BlockImpl@7cf53e4c de.myview.objectmodel.impl.BlockImpl@4e7f78a6  
 de.myview.objectmodel.impl.BlockImpl@781727fe de.myview.objectmodel.impl.BlockImpl@21679677  
 de.myview.objectmodel.impl.BlockImpl@74b5cb49 de.myview.objectmodel.impl.BlockImpl@41ba2731  
 de.myview.objectmodel.impl.BlockImpl@53d02f de.myview.objectmodel.impl.BlockImpl@1d9a3a7c  
 de.myview.objectmodel.impl.BlockImpl@472f4505

RoHS Compliance Status

Compliant without exemption

**Approvals**

Approvals



ROHS

Conform

**Downloads**

Approval/Certificate/Document of Conformity

[Manufacturer's declaration](#)

Engineering Data

[CAD data – STEP](#)

Product Change Notification

[20220214 Technical change to HDC housings](#)  
[20220214 Technische Änderung bei HDC-Gehäusen](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures


[FL FIELDWIRING EN](#)  
[FL FIELDWIRING EN](#)

## HDC IP68 06B TSS 1M20

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

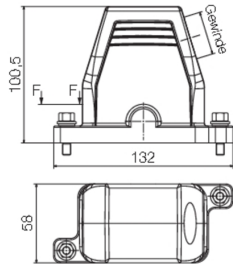

**HDC IP68 06B TSS 1M20**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Accessories****Socket wrench sets**

Allen key made from fully hardened, high-alloy chromium-vanadium- steel, acc. to DIN ISO 2936 L (DIN 911), high-quality refined surface.

**General ordering data**

|            |                            |               |
|------------|----------------------------|---------------|
| Type       | SK WSD-S 1,5-10,0          | Version       |
| Order No.  | <a href="#">9008850000</a> | Mounting tool |
| GTIN (EAN) | 4032248266609              |               |
| Qty.       | 1 pc(s).                   |               |

**Screws**

We offer a variety of accessories, including screws, that fit to the heavy-duty connectors.

**General ordering data**

|            |                            |  |
|------------|----------------------------|--|
| Type       | HDC IP68 SCREW SET         | Version  |
| Order No.  | <a href="#">2555340000</a> | Heavy-duty connectors, Accessories, Set of fixings |
| GTIN (EAN) | 4050118571332              |  |
| Qty.       | 10 pc(s).                  |  |