

**IE-PIC-HYB-S-0,5-300****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14

**General ordering data**

|            |  |
|------------|--|
| Version    | Crimp contact, for plug insert, Hybrid |
| Order No.  | <a href="#">1096180000</a>             |
| Type       | IE-PIC-HYB-S-0,5-300                   |
| GTIN (EAN) | 4032248869152                          |
| Qty.       | 300 pc(s).                             |

**IE-PIC-HYB-S-0,5-300****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

|            |        |
|------------|--------|
| Net weight | 0.27 g |
|------------|--------|

**General data**

|  |                     |  |                     |
|--|---------------------|--|---------------------|
| Wire connection cross section, finely stranded, max. | 0.5 mm <sup>2</sup> | Wire connection cross section, finely stranded, min. | 0.2 mm <sup>2</sup> |
| Wire cross-section, finely stranded, max. (AWG)      | AWG 20              | Wire cross-section, finely stranded, min. (AWG)      | AWG 24              |

**Electrical properties**

|               |      |
|---------------|------|
| Rated voltage | 24 V |
|---------------|------|

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC001121    | ETIM 7.0    | EC001121    |
| ETIM 8.0    | EC001121    | ETIM 9.0    | EC001121    |
| ECLASS 9.0  | 27-44-03-90 | ECLASS 9.1  | 27-44-09-90 |
| ECLASS 10.0 | 27-44-03-90 | ECLASS 11.0 | 27-44-03-90 |
| ECLASS 12.0 | 27-44-03-90 | ECLASS 13.0 | 27-44-03-90 |

**Environmental Product Compliance**

|            |                                      |
|------------|--------------------------------------|
| REACH SVHC | Lead 7439-92-1                       |
| SCIP       | 67cf1078-beca-4687-860b-dc475a6ec24a |

**Important note**

|                     |  |
|---------------------|--|
| Product information | Hybrid, 10-pole. Inserts for plug-in connectors Variant 14 |
|---------------------|--|

**Approvals**

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

**Downloads**

|   |  |
|---|--|
| Approval/Certificate/Document of Conformity | <a href="#">PROFINET Manufacturer's Declaration</a>  |
| User Documentation                          | <a href="#">MAN IE GUIDE DE</a><br><a href="#">MAN IE GUIDE EN</a><br><a href="#">Designation key / Type key</a>   |
| Catalogues                                  | <a href="#">Catalogues in PDF-format</a>   |
| Brochures                                   | <a href="#">FL FIELDWIRING EN</a><br><a href="#">PI PROFINET CABLING EN</a><br><a href="#">FL FIELDWIRING EN</a><br><a href="#">PI PROFINET CABLING EN</a> |


## IE-PIC-HYB-S-0,5-300

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Drawings

## Dimensioned drawing

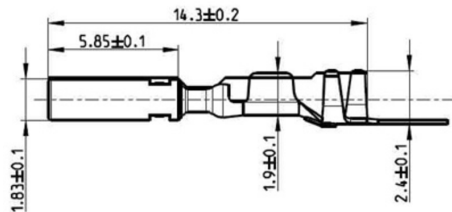

**IE-PIC-HYB-S-0,5-300****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Crimping tools****Crimping tools for Weidmüller contacts for RSV and DSTV-HD systems**

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation
- With end stop for exact positioning of the contacts

**General ordering data**

|            |                            |   |
|------------|----------------------------|---|
| Type       | HTF HYB                    | Version   |
| Order No.  | <a href="#">1119580000</a> | Pressing tool, Crimping tool for contacts, 0.08mm <sup>2</sup> , 1mm <sup>2</sup> , |
| GTIN (EAN) | 4032248900626              | FoderBcrimp   |
| Qty.       | 1 pc(s).                   |   |