

**IE-PS-V14M-2SC-POF****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

PushPull plug-in connector set according to IEC  
61076-3-117 ver.14 (PROFINET), metal incl. SC insert

**General ordering data**

Version	FO connector, Version 14, SC-RJ POF, IP67
Order No.	<a href="#">1191550000</a>
Type	IE-PS-V14M-2SC-POF
GTIN (EAN)	4032248974436
Qty.	10 pc(s).

## IE-PS-V14M-2SC-POF

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	79.9 mm	Depth (inches)	3.146 inch
Height	26.8 mm	Height (inches)	1.055 inch
Width	22.7 mm	Width (inches)	0.894 inch
Net weight	54.24 g		

## Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

## General data

Colour	silver	Connection 1	SCRJ
Connection 2	Rapid connection system: crimping, cutting	Description of article	Version 14, SC-RJ POF
Fibre type	POF	Housing main material	Zinc diecast
Housing material, insert	PA, Zinc diecast	Insertion loss	≤ 1.0 dB
Plugging cycles	750	Protection degree	IP67
Sheath diameter, max.	10 mm	Sheath diameter, min.	5 mm

## General standards

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-117 Var. 14, IEC 61754-24
-------------------------	---------	--------------------	--

## Classifications

ETIM 6.0	EC001122	ETIM 7.0	EC001122
ETIM 8.0	EC001122	ETIM 9.0	EC001122
ECLASS 9.0	19-17-01-22	ECLASS 9.1	19-17-01-22
ECLASS 10.0	19-17-01-22	ECLASS 11.0	19-17-01-22
ECLASS 12.0	19-17-01-22	ECLASS 13.0	19-17-01-22

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	4f3aae94-c2bc-4010-b63b-5b114ba6bd55
RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c

## Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E316369

## IE-PS-V14M-2SC-POF

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

### Downloads

Approval/Certificate/Document of Conformity	<a href="#">PROFINET Manufacturer's Declaration</a>
Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Designation key / Type key</a> <a href="#">Manual</a> <a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>


## IE-PS-V14M-2SC-POF

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

### Dimensioned drawing

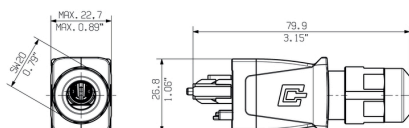

**IE-PS-V14M-2SC-POF****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Crimp Sets**

Crimp sets

**General ordering data**

Type	TOOL SET IE-POF	Version
Order No.	<a href="#">1208930000</a>	Crimping tool: HTX-IE-POF, Stripping tool: Multi-Stripax IE-POF
GTIN (EAN)	4032248990283	
Qty.	1 pc(s).	

**LWL-SC**

FO SC inserts for plug-in connectors ver.1 / 4 / 14

**General ordering data**

Type	IE-SCRJ-IP67-POF-100	Version
Order No.	<a href="#">1278430000</a>	FO connector, Replacement crimp barrel, IP67 with housing
GTIN (EAN)	4050118069136	
Qty.	100 pc(s).	

## IE-PS-V14M-2SC-POF

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

Type	ESG 9/11 K MC NE WS	Version
Order No.	<a href="#">1857440000</a>	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive
GTIN (EAN)	4032248402731	
Qty.	200 pc(s).	

## Dust caps



For protecting your devices against dust and dirt.

## General ordering data

Type	IE-PP-V14P	Version
Order No.	<a href="#">1058280000</a>	Plug housing protective cap
GTIN (EAN)	4032248799374	
Qty.	10 pc(s).	