

## HDC 24B ADLU

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

### General ordering data

Version	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Bulkhead housing, End-locking clamp, lower side, Standard, with cover
Order No.	<a href="#">1214300000</a>
Type	HDC 24B ADLU
GTIN (EAN)	4008190083090
Qty.	1 pc(s).

## HDC 24B ADLU

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Height	47 mm	Height (inches)	1.85 inch
Width	99 mm	Width (inches)	3.898 inch
Mounting dimension - height	32 mm	Mounting dimension - width	130 mm
Net weight	286 g		

## Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

## Dimensions

Height of base B1	5 mm	Height of housing B	29 mm
Hole pitch length A2	130 mm	Total length housing	120 mm
Width base C1	47 mm	Width housing C	43 mm

## General data

EMC housings	No	Housing main material	diecast aluminium
Material of locking element	Stainless steel, rust-proof	Protection class note	Protection class with secured cover: IP 65
Protection degree	IP65 (in plugged condition)	Surface finish	Powder coating

## Version

BG	8	Clamp version	End-locking clamp
Colour (RAL)	RAL 7035	Cover	with cover
Design	Standard	Design of cover	with cover
Design of housing	Bulkhead housing	Design of locking system	End-locking clamp, lower side
Sealing	NBR	Size	8
Suitable for ModuPlug®	Yes	Top part/bottom part/lid	lower part
Type	Bulkhead (feed-through)		

## Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-02-02
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Substance	Acetone
Chemical resistance	Conditionally resistant
Substance	Drilling oil
Chemical resistance	Resistant
Substance	Diesel
Chemical resistance	Resistant
Substance	Ethyl alcohol
Chemical resistance	Resistant
Substance	Transmission oil

Creation date July 4, 2024 4:18:39 PM CEST

**HDC 24B ADLU**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

Chemical resistance	Resistant
Substance	Hydraulic oil
Chemical resistance	Resistant
Substance	Coolant
Chemical resistance	Resistant
Substance	Petroleum benzine
Chemical resistance	Resistant
Substance	Sweat
Chemical resistance	Resistant
Substance	Premium gasoline
Chemical resistance	Conditionally resistant
Substance	Water
Chemical resistance	Resistant
Substance	UV
Chemical resistance	Unstable
Substance	Ozone
Chemical resistance	Unstable

**Environmental Product Compliance**

REACH SVHC	Lead 7439-92-1 Potassium perfluorobutane sulfonate 29420-49-3
SCIP	e98b2b24-ba23-41bf-8d19-0dda3647412f
Chemical resistance	de.myview.objectmodel.impl.BlockImpl@626221f4 de.myview.objectmodel.impl.BlockImpl@1ff0e931 de.myview.objectmodel.impl.BlockImpl@773c1263 de.myview.objectmodel.impl.BlockImpl@591ffaeb de.myview.objectmodel.impl.BlockImpl@2a011dbd de.myview.objectmodel.impl.BlockImpl@3220c0ad de.myview.objectmodel.impl.BlockImpl@25987380 de.myview.objectmodel.impl.BlockImpl@3f60d7a de.myview.objectmodel.impl.BlockImpl@2138144c de.myview.objectmodel.impl.BlockImpl@15a99d6e de.myview.objectmodel.impl.BlockImpl@73cbf828 de.myview.objectmodel.impl.BlockImpl@40e5a6f6 de.myview.objectmodel.impl.BlockImpl@219e40d2

**Important note**

Product information	When mounting the housings, make sure that the flat gasket is correctly seated.
---------------------	---

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E92202

**HDC 24B ADLU**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Technical data****Downloads**

---

Approval/Certificate/Document of Conformity	<a href="#">Manufacturer's declaration</a>
Engineering Data	<a href="#">CAD data – STEP</a>
Engineering Data	<a href="#">Zuken E3.S</a>
Product Change Notification	<a href="#">20220214 Technical change to HDC housings</a> <a href="#">20220214 Technische Änderung bei HDC-Gehäusen</a>
Technical Documentation	<a href="#">1214300000_HDC_24B_ADLU_STP_Blatt_1.pdf</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a> <a href="#">FL FIELDWIRING EN</a>

---


**Data sheet**

**HDC 24B ADLU**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

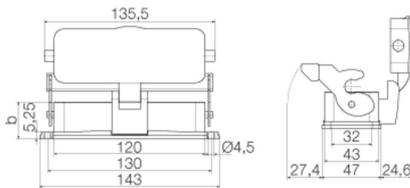

## HDC 24B ADLU

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

## Accessories

## Hood, Cable Entry sideways



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 64D TSLU 1PG21G	Version
Order No.	<a href="#">1662470000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4008190418991	lower side, high, Size of cable entries: PG 21
Qty.	1 pc(s).	
Type	HDC 64D TSLU 1M32G	Version
Order No.	<a href="#">1786810000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4032248204052	lower side, high, Size of cable entries: M 32
Qty.	1 pc(s).	
Type	HDC 24B TSLU 1PG29G	Version
Order No.	<a href="#">1662410000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4008190418939	lower side, Standard, Size of cable entries: PG 29
Qty.	1 pc(s).	
Type	HDC 24B TSLU 1M25G	Version
Order No.	<a href="#">1787800000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4032248205240	lower side, Standard, Size of cable entries: M 25
Qty.	1 pc(s).	
Type	HDC 24B TSLU 1PG21G	Version
Order No.	<a href="#">1662390000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4008190418915	lower side, Standard, Size of cable entries: PG 21
Qty.	1 pc(s).	
Type	HDC 64D TSLU 1PG29G	Version
Order No.	<a href="#">1662490000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4008190419011	lower side, high, Size of cable entries: PG 29
Qty.	1 pc(s).	
Type	HDC 24B TSLU 1M32G	Version
Order No.	<a href="#">1787790000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4032248205233	lower side, Standard, Size of cable entries: M 32
Qty.	1 pc(s).	
Type	HDC 64D TSLU 1M40G	Version
Order No.	<a href="#">1804610000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4032248267538	lower side, high, Size of cable entries: M 40
Qty.	1 pc(s).	

Creation date July 4, 2024 4:18:39 PM CEST

Catalogue status 29.06.2024 / We reserve the right to make technical changes.

**HDC 24B ADLU**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**
**XXL plug housing, cable entry sideways**


The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings. The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact. The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening. The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned. Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

Type	HDC 64D TSLU 1M50G	Version
Order No.	<a href="#">1111150000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp, lower side, Standard, Size of cable entries: M 50
GTIN (EAN)	4032248100118	
Qty.	1 pc(s).	

**Hood, Cable Entry at top**


The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings. The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact. The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening. The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned. Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

Type	HDC 64D TOLU 1PG29G	Version
Order No.	<a href="#">1662630000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4008190419158	
Qty.	1 pc(s).	
Type	HDC 24B TOLU 1M25G	Version
Order No.	<a href="#">1787860000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248205301	
Qty.	1 pc(s).	

## HDC 24B ADLU

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

Type	HDC 24B TOLU 1M32G	Version
Order No.	<a href="#">1787850000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, Standard, Size of cable entries: M 32
GTIN (EAN)	4032248205295	
Qty.	1 pc(s).	
Type	HDC 64D TOLU 1M40G	Version
Order No.	<a href="#">1983470000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, high, Size of cable entries: M 40
GTIN (EAN)	4032248687916	
Qty.	1 pc(s).	
Type	HDC 64D TOLU 1M32G	Version
Order No.	<a href="#">1786860000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248204106	
Qty.	1 pc(s).	
Type	HDC 24B TOLU 1PG2 1G	Version
Order No.	<a href="#">1662540000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4008190419066	
Qty.	1 pc(s).	
Type	HDC 64D TOLU 1M25G	Version
Order No.	<a href="#">1786870000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, high, Size of cable entries: M 25
GTIN (EAN)	4032248204113	
Qty.	1 pc(s).	
Type	HDC 64D TOLU 1PG2 1G	Version
Order No.	<a href="#">1662610000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, high, Size of cable entries: PG 21
GTIN (EAN)	4008190419134	
Qty.	1 pc(s).	
Type	HDC 24B TOLU 1PG29G	Version
Order No.	<a href="#">1662550000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, Standard, Size of cable entries: PG 29
GTIN (EAN)	4008190419073	
Qty.	1 pc(s).	

**HDC 24B ADLU**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**XXL plug housing, cable entry on top**



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

Type	HDC 64D TOLU 1M50G	Version
Order No.	<a href="#">1111170000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp,
GTIN (EAN)	4032248100125	lower side, Standard, Size of cable entries: M 50
Qty.	1 pc(s).	