

**IE-BS-V01M-SCRJ-MM****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Bayonet plug-in connector sets according to IEC  
61076-3-106 ver.1 (Ethernet/IP), RJ45 metal insert incl.  
SC insert

**General ordering data**

Version	Flange FO, IP67, Multimode, POF
Order No.	<a href="#">1221010000</a>
Type	IE-BS-V01M-SCRJ-MM
GTIN (EAN)	4050118003949
Qty.	10 pc(s).

## IE-BS-V01M-SCRJ-MM

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	37 mm	Depth (inches)	1.457 inch
Height	32 mm	Height (inches)	1.26 inch
Width	32 mm	Width (inches)	1.26 inch
Net weight	5.8 g		

## Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

## General data

Colour	Miscellaneous	Connection 1	SCRJ
Connection 2	SCRJ	Fibre type	Multimode, POF
Housing main material	Zinc diecast	Insertion loss	≤ 0.4 dB
Plugging cycles	500	Protection degree	IP67
Return loss (attenuation)	≥ 30 dB		

## General standards

Connector standard	IEC 61076-3-106 Var. 1, IEC 61754-24
--------------------	---

## Classifications

ETIM 6.0	EC000752	ETIM 7.0	EC000752
ETIM 8.0	EC000752	ETIM 9.0	EC000752
ECLASS 9.1	19-17-01-16	ECLASS 10.0	19-17-01-16
ECLASS 11.0	19-17-01-16	ECLASS 12.0	19-17-01-16
ECLASS 13.0	19-17-01-16		

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	e5bbf197-73b5-420b-90c0-0173b7b3b6b7
RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c

## Approvals

ROHS	Conform
------	---------

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">PROFINET Manufacturer's Declaration</a>
Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Designation key / Type key</a> <a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">MB FREECONTACT EN</a> <a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>

Creation date August 29, 2024 2:59:49 AM CEST

Catalogue status 17.08.2024 / We reserve the right to make technical changes.


## IE-BS-V01M-SCRJ-MM

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)


## Drawings

### Installation cut-out

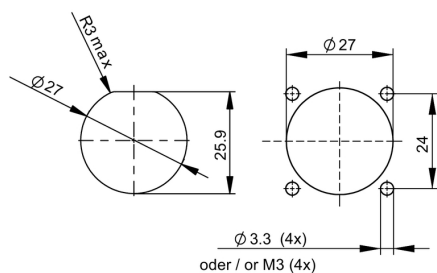

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

### Detailed drawing

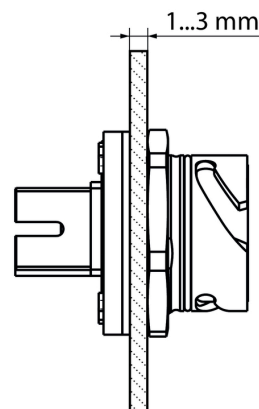

Wall thickness when using the central screw connection

**IE-BS-V01M-SCRJ-MM****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Dust caps**

For protecting your devices against dust and dirt.

**General ordering data**

Type	IE-BP-V01P	Version
Order No.	<a href="#">1965700000</a>	Flange-mounted housing, protective cap
GTIN (EAN)	4032248653928	
Qty.	10 pc(s).	