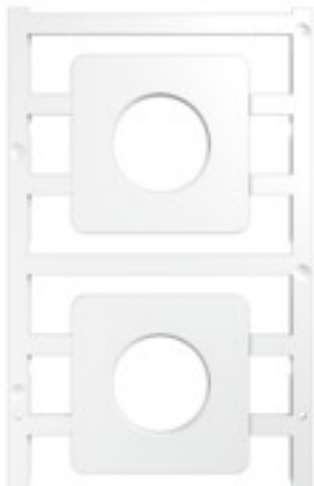


**SM 45/45-24 MC SDR****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Similar to illustration



SM is a MultiCard marker for labelling control and signalling devices. The tags are clipped into the carriers or attached by means of the adhesive film already fitted to them. Customised tags can be created with the PrintJet CONNECT or Plotter marking systems.

- Users can quickly produce tags to suit their needs
- No need to stock expensive standard tags
- Highly resistant printing quality when using the PrintJet as a substitute for engraving
- For extreme demands, we recommend the ETO SM protective film
- Holders can be used for the 22-mm or 30-mm-diameter push-buttons from Siemens, ABB, Moeller and Télémécanique

**For custom printing:** Please send us a file of our labelling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

**General ordering data**

Version	SwitchMark, Device markers, 42 x 42 mm, for cam switches, Eaton Moeller, To customer specification
Order No.	<a href="#">1248570000</a>
Type	SM 45/45-24 MC SDR
GTIN (EAN)	4050118038941
Qty.	4 pc(s).
compatible printer	<a href="#">2715590000</a> <a href="#">2438520000</a> <a href="#">2438510000</a>

**SM 45/45-24 MC SDR****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Depth	1.2 mm	Depth (inches)	0.047 inch
Height	42 mm	Height (inches)	1.654 inch
Width	42 mm	Width (inches)	1.654 inch
Diameter	24 mm	Net weight	5.75 g

**Temperatures**

Operating temperature range	-40...100 °C
-----------------------------	--------------

**General data**

Application/manufacture	for cam switches, Eaton Moeller		
Colour	To customer specification		
Halogen	No		
Material	Polyamide 66		
Number of markers per combination	1 MultiCard = Device markers		
Number of markers per packaging unit	Form of supply	MultiCard	
Operating temperature range	-40...100 °C		
Operating temperature range, max.	100 °C		
Operating temperature range, min.	-40 °C		
Printed characters	Based on customer requirements (Please send M-Print PRO file)		
UL 94 flammability rating	V-2		
Width	42 mm		

**Device markers**

Diameter	24 mm	Halogen	No
----------	-------	---------	----

**Classifications**

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Catalogues	<a href="#">Catalogues in PDF-format</a>
------------	--

### SM 45/45-24 MC SDR

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

### Example of use

