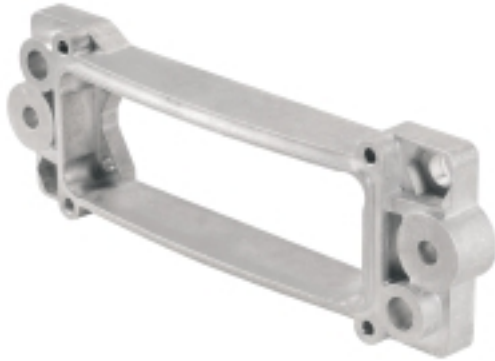


HDC IP68 24B HP FRAME**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The RockStar[®] HighPower housings are manufactured from high-strength die-cast aluminium and offer perfect protection against harsh environmental conditions thanks to continual optimisation. The multi-part housing gives users the opportunity to examine work processes down to the last step in the workflow.

General ordering data

Version	HDC enclosures, Size: 8, Protection degree: IP68, IP69K, IP68 (in plugged condition), , Clamping yoke connection, Standard
Order No.	1282820000
Type	HDC IP68 24B HP FRAME
GTIN (EAN)	4050118073010
Qty.	1 pc(s).

HDC IP68 24B HP FRAME**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Depth	217 mm	Depth (inches)	8.543 inch
Height	21 mm	Height (inches)	0.827 inch
Width	72 mm	Width (inches)	2.835 inch
Net weight	305 g		

Temperatures

Limit temperature	-50 °C ... 125 °C
-------------------	-------------------

General data

Colour	Silver grey, black (similar to RAL 9005)	Series	HighPower
Type	Counter-frame		

Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-02-02
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Environmental Product Compliance

REACH SVHC	/
------------	---

Approvals

ROHS	Conform
------	---------

Downloads

Approval/Certificate/Document of Conformity	Manufacturer's declaration
Engineering Data	CAD data – STEP
User Documentation	HDC_HP_MOAL_IP68_PLUS_ABGH
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN FL FIELDWIRING EN