

IE-CD-V14MSCRJ-MM-C-MA**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Coupling FreeCon design for Fibre-optic plug-in connectors PushPull Var.14 according to IEC 61076-3-117, metal

General ordering data

Version	Junction box, FreeCon, SCRJ, Plug-in connector, IP65
Order No.	1318150000
Type	IE-CD-V14MSCRJ-MM-C-MA
GTIN (EAN)	4050118123982
Qty.	1 pc(s).

IE-CD-V14MSCRJ-MM-C-MA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	43.9 mm	Depth (inches)	1.728 inch
Height	52 mm	Height (inches)	2.047 inch
Width	41 mm	Width (inches)	1.614 inch
Net weight	224.56 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Colour	silver	Housing main material	Aluminium profile, Cover: die-cast zinc, painted
Protection degree	IP65	Type of mounting	Screw mounting

General standards

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-117 Var. 14, IEC 61754-24
-------------------------	---------	--------------------	---------------------------------------

Optical properties of fibre-optic coupling

Insertion attenuation (fibre-optic coupling)	<0.2 dB
--	---------

Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-03-92
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Approvals

Approvals



UL File Number Search	UL Website
Certificate no. (cULus)	E316369

Downloads

Approval/Certificate/Document of Conformity	PROFINET Manufacturer's Declaration
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN

Creation date May 23, 2024 4:07:54 AM CEST

Catalogue status 18.05.2024 / We reserve the right to make technical changes.


IE-CD-V14MSCRJ-MM-C-MA

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com


Drawings

Dimensioned drawing

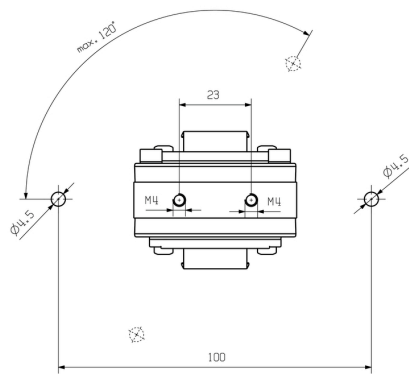


Bottom view

Dimensioned drawing

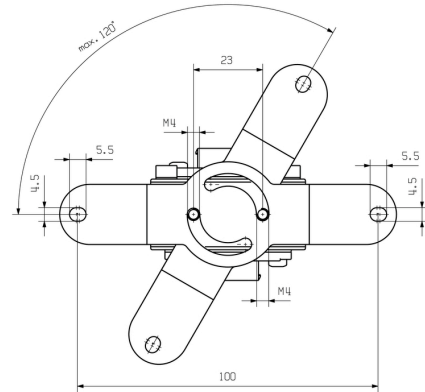


Bottom view with mounting foot

Dimensioned drawing

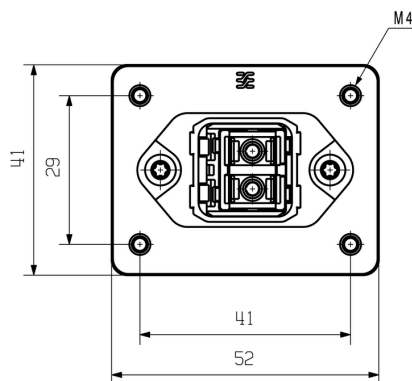

Front view

Dimensioned drawing

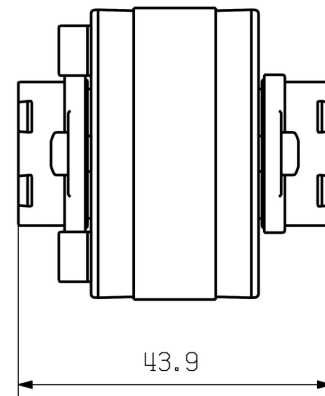

Side view

IE-CD-V14MSCRJ-MM-C-MA**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Dust caps**

For protecting your devices against dust and dirt.

General ordering data

Type	IE-BP-V14P	Version
Order No.	1058310000	Flange-mounted housing, protective cap
GTIN (EAN)	4032248799404	
Qty.	10 pc(s).	

SC-RJPushPull plug-in connector set according to IEC
61076-3-117 ver.14 (PROFINET), metal incl. SC insert**General ordering data**

Type	IE-PS-V14M-2SC-POF	Version
Order No.	1191550000	FO connector, Version 14, SC-RJ POF, IP67
GTIN (EAN)	4032248974436	
Qty.	10 pc(s).	