

**SAI-WDF-3P-M8****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**General ordering data**

Order No.	<a href="#">1392390000</a>
Type	SAI-WDF-3P-M8
GTIN (EAN)	4050118192766
Qty.	1 pc(s).

## SAI-WDF-3P-M8

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Net weight	21 g
------------	------

## Technical data customisable plug-in connectors

Coding	M8 = none	Contact material	CuZn
Contact surface	Gold-plated	Housing main material	CuZn
Number of poles	3	Protection degree	IP67
Rated current	4 A	Rated voltage	30 V
Temperature range of housing	-40 ... +85 °C		

## General technical specifications

Coding	M8 = none	Connection thread	M8 socket, M8 pin
Contact material	CuZn	Contact surface	Gold-plated
Housing main material	CuZn	Number of poles	3
Protection degree	IP67	Rated current	4 A
Rated voltage	30 V	Temperature range of housing	-40 ... +85 °C

## Classifications

ETIM 6.0	EC002925	ETIM 7.0	EC002925
ETIM 8.0	EC002925	ETIM 9.0	EC002925
ECLASS 9.0	27-44-01-06	ECLASS 9.1	27-44-01-06
ECLASS 10.0	27-44-01-06	ECLASS 11.0	27-44-01-06
ECLASS 12.0	27-44-01-06	ECLASS 13.0	27-44-01-06

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	ebf89fc8-a87f-4691-b87a-dfb9921774b4

## Approvals

Approvals



ROHS	Conform
------	---------

## Downloads

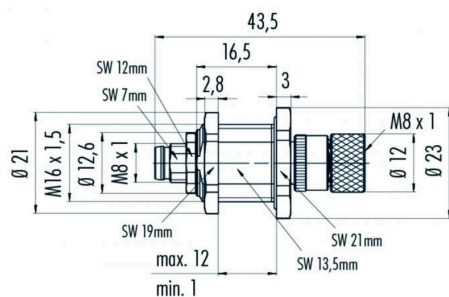
 
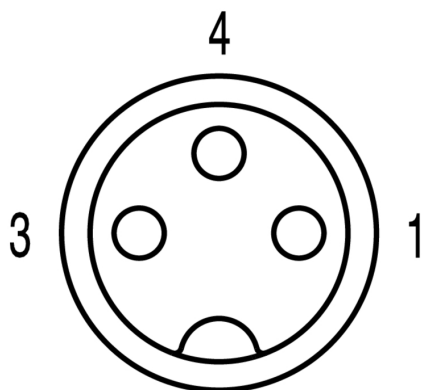
Engineering Data	<a href="#">CAD data – STEP</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a>

**SAI-WDF-3P-M8****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Drawings****Dimensioned drawing****Wiring diagram****Pole scheme****Pole scheme**