

**IE-CD-VAPM24V-C-MA****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

View from below

Y-distributor / connection coupling, FreeCon for plug-in  
PushPull Power connector to PROFINET specification,  
metal

**General ordering data**

|            |  |
|------------|--|
| Version    | Coupling, FreeCon, Supply, IP65, If thread-locking fluid is used |
| Order No.  | <a href="#">1397690000</a>                                       |
| Type       | IE-CD-VAPM24V-C-MA   |
| GTIN (EAN) | 4050118198669  |
| Qty.       | 1 pc(s).   |

**IE-CD-VAPM24V-C-MA****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

|            |          |
|------------|----------|
| Net weight | 425.36 g |
|------------|----------|

**Temperatures**

|                       |                |
|-----------------------|----------------|
| Operating temperature | -40 °C...70 °C |
|-----------------------|----------------|

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC001264    | ETIM 7.0    | EC001264    |
| ETIM 8.0    | EC001264    | ETIM 9.0    | EC001264    |
| ECLASS 9.0  | 19-17-01-23 | ECLASS 9.1  | 19-17-01-25 |
| ECLASS 10.0 | 19-17-01-23 | ECLASS 11.0 | 19-17-01-23 |
| ECLASS 12.0 | 19-17-01-23 | ECLASS 13.0 | 19-17-01-23 |

**Environmental Product Compliance**

|                        |                             |
|------------------------|-----------------------------|
| REACH SVHC             | /                           |
| RoHS Compliance Status | Compliant without exemption |

**Approvals**

Approvals



|                         |            |
|-------------------------|------------|
| ROHS                    | Conform    |
| UL File Number Search   | UL Website |
| Certificate no. (cULus) | E316369    |

**Downloads**

|   |  |
|---|--|
| Approval/Certificate/Document of Conformity | <a href="#">PROFINET Manufacturer's Declaration</a>  |
| Engineering Data                            | <a href="#">CAD data – STEP</a>  |
| User Documentation                          | <a href="#">MAN IE GUIDE DE</a><br><a href="#">MAN IE GUIDE EN</a>   |
| Catalogues                                  | <a href="#">Catalogues in PDF-format</a>   |
| Brochures                                   | <a href="#">MB FREECONTACT EN</a><br><a href="#">FL FIELDWIRING EN</a><br><a href="#">PI PROFINET CABLING EN</a><br><a href="#">PI PROFINET CABLING EN</a> |


## IE-CD-VAPM24V-C-MA

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany


[www.weidmueller.com](http://www.weidmueller.com)

## Drawings


### Dimensioned drawing

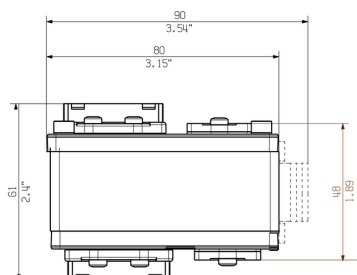

### Dimensioned drawing

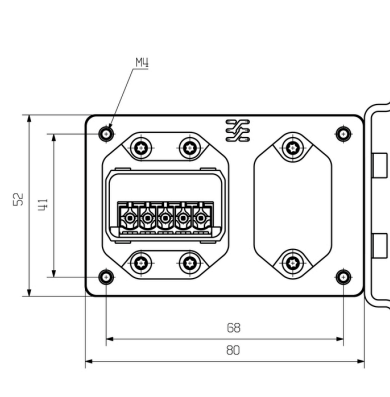

### Dimensioned drawing

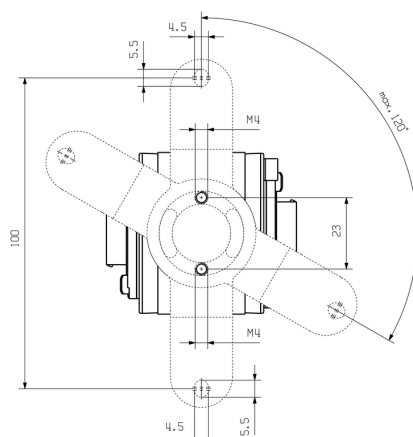

### Dimensioned drawing

