

**THM EL 100 WS 30M****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Customised identification: EL**

The endless variations of MultiMark markers make them an economical alternative to conventional tag rails or special labels. For any given width, the height can be precisely configured by the software to match the respective markers perfectly. A blade is used to cut the labels individually to the specified size. Perfect for producing large labels for function blocks or complete terminal blocks.

**General ordering data**

Version	THM, Device markers, 100 x , white
Order No.	<a href="#">1420010000</a>
Type	THM EL 100 WS 30M
GTIN (EAN)	4050118223477
Qty.	1 pc(s).
compatible printer	<a href="#">2599430000</a> <a href="#">2599440000</a>

## THM EL 100 WS 30M

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	0.08 mm	Depth (inches)	0.003 inch
Height	100 mm	Height (inches)	3.937 inch
Length	30,000 mm	Length (inches)	1,181.1 inch
Net weight	485 g		

## Temperatures

Operating temperature range	-40...150 °C
-----------------------------	--------------

## General data

Adhesive	Acrylate adhesive		
Approval acc. to UL 969	Yes		
Colour	white		
Halogen	No		
Length	30,000 mm		
Material	Polyester		
Material colour according to resistance code	9		
Number of markers per combination	1 Label reel = Device markers		
Number of markers per packaging unit	Form of supply	Label reel	
Number per roll	1		
Number per sheet	1		
Operating temperature range	-40...150 °C		
Operating temperature range, max.	150 °C		
Operating temperature range, min.	-40 °C		
Printing method	Thermal transfer		
UL 94 flammability rating	V-0		
Version	Endless, Self-adhesive		

## Device markers

Halogen	No
---------	----

## Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04
ECLASS 14.0	27-28-11-04		

## Environmental Product Compliance

REACH SVHC	/
RoHS Compliance Status	Compliant without exemption

## Approvals

ROHS	Conform
------	---------

### THM EL 100 WS 30M

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

### Downloads

Catalogues


[Catalogues in PDF-format](#)

**THM EL 100 WS 30M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

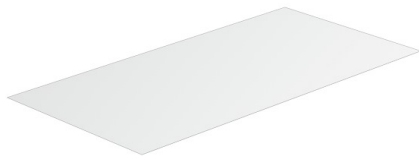

**THM EL 100 WS 30M****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	RIBBON MM 110/360 SW	Version
Order No.	<a href="#">2005070000</a>	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 pc(s).	

**THM EL 100 WS 30M**

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

