

IE-FCI-D9-FM**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Version	FrontCom, Signal insert D-Sub, 9-pole, Plug, Socket connector
Order No.	1450850000
Type	IE-FCI-D9-FM
GTIN (EAN)	4050118255713
Qty.	1 pc(s).

IE-FCI-D9-FM**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Height	17.9 mm	Height (inches)	0.705 inch
Width	12.5 mm	Width (inches)	0.492 inch
Length	30.8 mm	Length (inches)	1.213 inch
Net weight	11 g		

Temperatures

Operating temperature	-55 °C...105
-----------------------	--------------

Technical data

Contact resistance	≤ 20 mΩ	Contact surface	Gold-plated
Current-carrying capacity	3 A	Dielectric strength, contact / contact	1 kV _{eff} / 1 min.
Housing main material	SPCC	Housing surface	tin-plated
Insulation strength	1000 MΩ at 500 V DC	Material insulator	PBT glass fibre reinforced UL 94 V-0
Number of poles	9		

General data

Insert type	Signal insert D-Sub, 9-pole	Protection degree	IP20
-------------	-----------------------------	-------------------	------

Electrical properties

Contact resistance	≤ 20 mΩ	Dielectric strength, contact / contact	1 kV _{eff} / 1 min.
Insulation strength	1000 MΩ at 500 V DC		

General standards

Certificate No. (DNV)	TAA000022B	Certificate No. (UR)	E497345
-----------------------	------------	----------------------	---------

Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ETIM 9.0	EC001121
ECLASS 9.0	27-44-03-90	ECLASS 9.1	27-18-90-90
ECLASS 10.0	27-44-03-90	ECLASS 11.0	27-44-03-90
ECLASS 12.0	27-18-28-92	ECLASS 13.0	27-18-28-92

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	14f36bdb-8bcd-4f24-8fb3-9538ad1abec6
RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c

IE-FCI-D9-FM

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (UR)	E497345

Downloads

Approval/Certificate/Document of Conformity	GL_FrontCom
Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-FCI-D9-FM

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

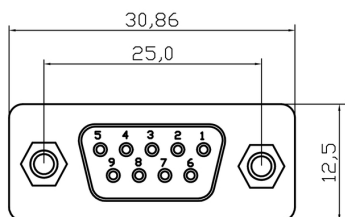

Dimensioned drawing

