

HSS 8.5-25.4 EL Y10M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

General ordering data

Version	Conductor and cable markers, 8.5 - 25.4 mm, yellow
Order No.	1489610000
Type	HSS 8.5-25.4 EL Y10M
GTIN (EAN)	4050118299335
Qty.	1 pc(s).
compatible printer	2599430000 2599440000

HSS 8.5-25.4 EL Y10M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	0.77 mm	Depth (inches)	0.03 inch
Width	40.5 mm	Width (inches)	1.594 inch
Length	10,000 mm	Length (inches)	393.7 inch
Net weight	388 g		

Temperatures

Operating temperature range	-55...135 °C
-----------------------------	--------------

General data

Colour	yellow	Halogen	Yes
Length	10,000 mm	Material	Polyolefine
Operating temperature range	-55...135 °C	Operating temperature range, max.	135 °C
Operating temperature range, min.	-55 °C	Printed characters	without
Recommended industries	Plant manufacture, Energy, Device manufacturer, Machinery	Type of printing	neutral
Width	40.5 mm		

Conductor and cable markers

Conductor O.D.	8.5 - 25.4 mm	Conductor O.D., max.	25.4 mm
Conductor O.D., min.	8.5 mm	Conductor cross-section, max.	120 mm ²
Conductor cross-section, min.	35 mm ²	Cross-section for connected wire	35 - 120 mm ²
Halogen	Yes	Rate of shrinkage	3:1
Recommended shrinking temperature	90 °C	Text field height	40.3 mm
Text field width	0 mm		

Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ETIM 9.0	EC001530
ECLASS 9.0	27-40-04-01	ECLASS 9.1	27-40-04-01
ECLASS 10.0	27-40-04-01	ECLASS 11.0	27-28-11-02
ECLASS 12.0	27-28-11-02	ECLASS 13.0	27-28-11-02

Environmental Product Compliance

REACH SVHC	/
------------	---

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E366310

Downloads

Catalogues	Catalogues in PDF-format
------------	--

Creation date June 26, 2024 3:25:07 AM CEST


Catalogue status 14.06.2024 / We reserve the right to make technical changes.

HSS 8.5-25.4 EL Y10M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

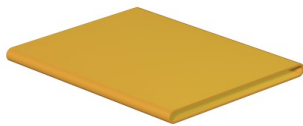

HSS 8.5-25.4 EL Y10M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON HSS HF EL 40/300 ...	Version
Order No.	1426210000	Ink ribbon
GTIN (EAN)	4050118228823	
Qty.	1 pc(s).	

THM MULTIMARK

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	THM MMP ROLLER 115
Order No.	1357420000
GTIN (EAN)	4050118160314
Qty.	1 pc(s).

Type	THM MMP ROLLER 30
Order No.	1357430000
GTIN (EAN)	4050118160253
Qty.	1 pc(s).