

HSS 1.6-4.8 EL W13M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

General ordering data

Version	Conductor and cable markers, 1.6 - 4.8 mm, white
Order No.	1489640000
Type	HSS 1.6-4.8 EL W13M
GTIN (EAN)	4050118299441
Qty.	1 pc(s).
compatible printer	2599430000 2599440000

HSS 1.6-4.8 EL W13M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	0.77 mm	Depth (inches)	0.03 inch
Width	7.6 mm	Width (inches)	0.299 inch
Length	13,000 mm	Length (inches)	511.81 inch
Net weight	106 g		

Temperatures

Operating temperature range	-55...135 °C
-----------------------------	--------------

General data

Colour	white	Halogen	Yes
Length	13,000 mm	Material	Polyolefine
Operating temperature range	-55...135 °C	Operating temperature range, max.	135 °C
Operating temperature range, min.	-55 °C	Printed characters	without
Recommended industries	Plant manufacture, Energy, Device manufacturer, Machinery	Type of printing	neutral
Width	7.6 mm		

Conductor and cable markers

Conductor O.D.	1.6 - 4.8 mm	Conductor O.D., max.	4.8 mm
Conductor O.D., min.	1.6 mm	Conductor cross-section, max.	4 mm ²
Conductor cross-section, min.	0.75 mm ²	Cross-section for connected wire	0.75 - 4 mm ²
Halogen	Yes	Rate of shrinkage	3:1
Recommended shrinking temperature	90 °C	Text field height	7.4 mm
Text field width	0 mm		

Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ETIM 9.0	EC001530
ECLASS 9.0	27-40-04-01	ECLASS 9.1	27-40-04-01
ECLASS 10.0	27-40-04-01	ECLASS 11.0	27-28-11-02
ECLASS 12.0	27-28-11-02	ECLASS 13.0	27-28-11-02
ECLASS 14.0	27-28-11-02		

Environmental Product Compliance

REACH SVHC	/
RoHS Compliance Status	Compliant without exemption

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E366310

HSS 1.6-4.8 EL W13M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Catalogues

[Catalogues in PDF-format](#)

HSS 1.6-4.8 EL W13M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings



HSS 1.6-4.8 EL W13M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

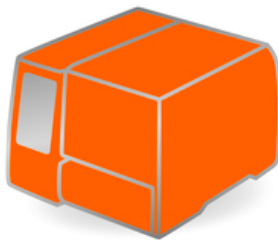
Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON HSS HF EL 40/300 ...	Version
Order No.	1426210000	Ink ribbon
GTIN (EAN)	4050118228823	
Qty.	1 pc(s).	

THM MULTIMARK

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	THM MMP ROLLER 115
Order No.	1357420000
GTIN (EAN)	4050118160314
Qty.	1 pc(s).

Type	THM MMP ROLLER 30
Order No.	1357430000
GTIN (EAN)	4050118160253
Qty.	1 pc(s).