

HSS 8.5-25.4 EL W30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

General ordering data

Version	Conductor and cable markers, 8.5 - 25.4 mm, white
Order No.	1505910000
Type	HSS 8.5-25.4 EL W30M
GTIN (EAN)	4050118314373
Qty.	1 pc(s).
compatible printer	2599430000 2599440000

HSS 8.5-25.4 EL W30M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	0.77 mm	Depth (inches)	0.03 inch
Width	40.5 mm	Width (inches)	1.594 inch
Length	30,000 mm	Length (inches)	1,181.1 inch
Net weight	310 g		

Temperatures

Operating temperature range	-55...135 °C
-----------------------------	--------------

General data

Colour	white	Halogen	Yes
Length	30,000 mm	Material	Polyolefine
Operating temperature range	-55...135 °C	Operating temperature range, max.	135 °C
Operating temperature range, min.	-55 °C	Printed characters	without
Recommended industries	Plant manufacture, Energy, Device manufacturer, Machinery	Type of printing	neutral
Width	40.5 mm		

Conductor and cable markers

Conductor O.D.	8.5 - 25.4 mm	Conductor O.D., max.	25.4 mm
Conductor O.D., min.	8.5 mm	Conductor cross-section, max.	120 mm ²
Conductor cross-section, min.	35 mm ²	Cross-section for connected wire	35 - 120 mm ²
Halogen	Yes	Rate of shrinkage	3:1
Recommended shrinking temperature	90 °C	Text field height	40.3 mm
Text field width	0 mm		

Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ETIM 9.0	EC001530
ECLASS 9.0	27-40-04-01	ECLASS 9.1	27-40-04-01
ECLASS 10.0	27-40-04-01	ECLASS 11.0	27-28-11-02
ECLASS 12.0	27-28-11-02	ECLASS 13.0	27-28-11-02
ECLASS 14.0	27-28-11-02		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Important note

Product information	External roll holder 1302920000 necessary
---------------------	---

HSS 8.5-25.4 EL W30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Approvals**

Approvals



ROHS Conform

UL File Number Search UL Website

Certificate No. (cURus) E366310

DownloadsCatalogues [Catalogues in PDF-format](#)

HSS 8.5-25.4 EL W30M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Drawings



HSS 8.5-25.4 EL W30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

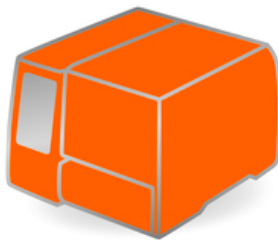
Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON HSS HF EL 40/300 ...	Version
Order No.	1426210000	Ink ribbon
GTIN (EAN)	4050118228823	
Qty.	1 pc(s).	

THM MULTIMARK

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MULTIMARK ROLLER 115
Order No.	1357420000
GTIN (EAN)	4050118160314
Qty.	1 pc(s).

Type	THM MMP EXT.RH
Order No.	1302920000
GTIN (EAN)	4050118102307
Qty.	1 pc(s).

Type	MULTIMARK ROLLER 30
Order No.	1357430000
GTIN (EAN)	4050118160253
Qty.	1 pc(s).