

THM EL 30 WS 30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Customised identification: EL**

The endless variations of MultiMark markers make them an economical alternative to conventional tag rails or special labels. For any given width, the height can be precisely configured by the software to match the respective markers perfectly. A blade is used to cut the labels individually to the specified size. Perfect for producing large labels for function blocks or complete terminal blocks.

General ordering data

Version	THM, Device markers, 30 x , white
Order No.	1517180000
Type	THM EL 30 WS 30M
GTIN (EAN)	4050118325010
Qty.	1 pc(s).
compatible printer	2599430000 2599440000

THM EL 30 WS 30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Depth	0.08 mm	Depth (inches)	0.003 inch
Height	30 mm	Height (inches)	1.181 inch
Length	30,000 mm	Length (inches)	1,181.1 inch
Net weight	152 g		

Temperatures

Operating temperature range	-40...150 °C
-----------------------------	--------------

General data

Adhesive	Acrylate adhesive	
Approval acc. to UL 969	Yes	
Colour	white	
Halogen	No	
Length	30,000 mm	
Material	Polyester	
Material colour according to resistance code	9	
Number of markers per combination	1 Label reel = Device markers	
Number of markers per packaging unit	Form of supply	Label reel
Number per roll	1	
Number per sheet	1	
Operating temperature range	-40...150 °C	
Operating temperature range, max.	150 °C	
Operating temperature range, min.	-40 °C	
Printing method	Thermal transfer	
UL 94 flammability rating	V-0	
Version	Endless, Self-adhesive	

Device markers

Halogen	No
---------	----

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04
ECLASS 14.0	27-28-11-04		

Environmental Product Compliance

REACH SVHC	/
RoHS Compliance Status	Compliant without exemption

Approvals

ROHS	Conform
------	---------

THM EL 30 WS 30M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Catalogues


[Catalogues in PDF-format](#)

THM EL 30 WS 30M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

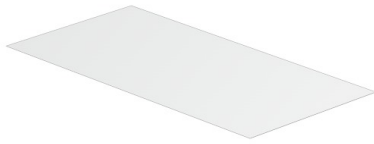

THM EL 30 WS 30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM 110/360 SW	Version
Order No.	2005070000	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 pc(s).	

THM EL 30 WS 30M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Drawings

