

**THM EL 50 SI 30M****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Customised identification: EL**

The endless variations of MultiMark markers make them an economical alternative to conventional tag rails or special labels. For any given width, the height can be precisely configured by the software to match the respective markers perfectly. A blade is used to cut the labels individually to the specified size. Perfect for producing large labels for function blocks or complete terminal blocks.

**General ordering data**

Version	THM, Device markers, 50 x , silver
Order No.	<a href="#">1517240000</a>
Type	THM EL 50 SI 30M
GTIN (EAN)	4050118325034
Qty.	1 pc(s).
compatible printer	<a href="#">2599430000</a> <a href="#">2599440000</a>

**THM EL 50 SI 30M****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Depth	0.08 mm	Depth (inches)	0.003 inch
Height	50 mm	Height (inches)	1.969 inch
Length	30,000 mm	Length (inches)	1,181.1 inch
Net weight	255 g		

**Temperatures**

Operating temperature range	-40...150 °C
-----------------------------	--------------

**General data**

Adhesive	Acrylate adhesive	
Approval acc. to UL 969	Yes	
Colour	silver	
Halogen	No	
Length	30,000 mm	
Material	Polyester	
Number of markers per combination	1 Label reel = Device markers	
Number of markers per packaging unit	Form of supply	Label reel
Number per roll	1	
Number per sheet	1	
Operating temperature range	-40...150 °C	
Operating temperature range, max.	150 °C	
Operating temperature range, min.	-40 °C	
Printing method	Thermal transfer	
UL 94 flammability rating	V-0	
Version	Endless, Self-adhesive	

**Device markers**

Halogen	No
---------	----

**Classifications**

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04
ECLASS 14.0	27-28-11-04		

**Environmental Product Compliance**

REACH SVHC	/
RoHS Compliance Status	Compliant without exemption

**Approvals**

ROHS	Conform
------	---------

**Downloads**


Catalogues	<a href="#">Catalogues in PDF-format</a>
------------	--

**THM EL 50 SI 30M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

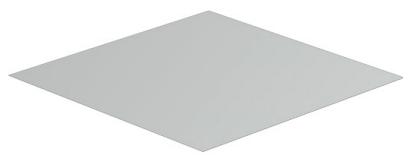

**THM EL 50 SI 30M****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	RIBBON MM 110/360 SW	Version
Order No.	<a href="#">2005070000</a>	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 pc(s).	

**THM EL 50 SI 30M**

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

