

DRMKIT 230VAC 4CO LD**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Product image**

Similar to illustration

- Mounted kit consisting relay, socket and retaining clip
- 100 % function tested
- 100 % check of the dielectric strenght between input - output
- 4 CO contacts
- With mechanical status indicator
- Optional Test button with coloured identification of coils (AC red / DC blue)
- Bright status LED (AC coil: red / DC coil: green)

General ordering data

| | |
|----------------|---|
| Version | D-SERIES DRM, Relay module, Number of contacts: 4, CO contact AgNi flash gold-plated, Rated control voltage: 230 V AC, Continuous current: 5 A, Screw connection, Test button available: No |
| Order No. | 1542450000 |
| Type | DRMKIT 230VAC 4CO LD |
| GTIN (EAN) | 4050118347258 |
| Qty. | 10 pc(s). |
| Relevant base | 7760056264 |
| Relevant relay | 7760056095 |

Creation date July 5, 2024 2:19:19 AM CEST

Catalogue status 29.06.2024 / We reserve the right to make technical changes.

DRMKIT 230VAC 4CO LD**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

| | | | |
|------------|---------|-----------------|------------|
| Depth | 66.8 mm | Depth (inches) | 2.63 inch |
| Height | 79.9 mm | Height (inches) | 3.146 inch |
| Width | 27.2 mm | Width (inches) | 1.071 inch |
| Net weight | 93.35 g | | |

Temperatures

| | | | |
|---------------------|----------------|-----------------------|----------------|
| Storage temperature | -40 °C...70 °C | Operating temperature | -40 °C...55 °C |
|---------------------|----------------|-----------------------|----------------|

Control side

| | | | |
|-----------------------|--------------------|------------------|--------------------------------|
| Rated control voltage | 230 V AC | Rated current AC | 6.1 mA (50 Hz), 5.2 mA (60 Hz) |
| Power rating | 1.0...1.2VA (60HZ) | Coil resistance | 15000 Ω ± 10 % |
| Coil tolerance | 10 % | Status indicator | red LED |

Load side

| | | | |
|---|---------------------------------------|---|---------------------------------------|
| Rated switching voltage | 250 V AC | Continuous current | 5 A |
| Max. switching frequency at rated load | 0.1 Hz | Max. switching voltage, AC | 250 V |
| Inrush current | 10 A / 50 ms | AC switching capacity (resistive), max. | 1250 VA |
| DC switching capacity (resistive), max. | 120 W @ 24 V | Switch-on delay | <20 ms |
| Switch-off delay | <20 ms | Contact type | 4 CO contact (AgNi flash gold-plated) |
| Mechanical service life | 20 x 10 ⁶ switching cycles | Min. switching power | 10 mA @ 12 V, 100 mA @ 5 V |

General data

| | | |
|--------------------------------------|--------------------------|------------------------|
| Rail | TS 35 | |
| Test button available | No | |
| Mechanical switch position indicator | Yes | |
| Colour | black | |
| UL94 flammability rating component | Component | Housing |
| | UL94 flammability rating | V-2 |
| | Component | Mounting foot |
| | UL94 flammability rating | HB |
| | Component | Retaining clip |
| | UL94 flammability rating | HB |
| | Component | Relay cover |
| | UL94 flammability rating | V-2 |
| | Component | Relay baseplate |
| | UL94 flammability rating | V-0 |
| | Component | Relay status indicator |
| | UL94 flammability rating | HB |
| | Component | Relay test button |
| | UL94 flammability rating | HB |

DRMKIT 230VAC 4CO LD**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Insulation coordination**

| | | | |
|---|-----------------------------|--|--------------------------------|
| Rated voltage | 250 V | Pollution severity | 2 |
| Surge voltage category | III | Insulating material group | C |
| Clearance and creepage distances for control side - load side | ≥ 5.5 mm | Dielectric strength for control side - load side | 1.8 kV _{eff} / 1 min. |
| Dielectric strength of neighbouring contacts | 1 kV _{eff} / 1 min | Dielectric strength of open contact | 1 kV _{eff} / 1 min |
| Impulse withstand voltage | 4.8 kV (1.2/50 µs) | Protection degree | IP20 |

Further details of approvals / standards

| | | | |
|-------------------------------|---------|------------------------------|---------|
| Certificate no. (cURus) relay | E312083 | Certificate no. (cURus) base | E312083 |
|-------------------------------|---------|------------------------------|---------|

Connection data

| | | | |
|---|---------------------|---|---------------------|
| Wire connection method | Screw connection | Stripping length, rated connection | 7 mm |
| Tightening torque, min. | 0.5 Nm | Tightening torque, max. | 0.7 Nm |
| Clamping range, min. | 0.5 mm ² | Clamping range, max. | 2.5 mm ² |
| Wire cross-section, solid, min. | 0.5 mm ² | Wire cross-section, solid, max. | 2.5 mm ² |
| Wire connection cross section, finely stranded, min. | 0.5 mm ² | Wire connection cross section, finely stranded, max. | 2.5 mm ² |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, min. | 0.5 mm ² | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, max. | 2.5 mm ² |
| Conductor cross-section, flexible, AEH (DIN 46228-1), min. | 0.5 mm ² | Conductor cross-section, flexible, AEH (DIN 46228-1), max. | 2.5 mm ² |
| Wire connection cross section, finely stranded, two clampable wires, min. | 0.5 mm ² | Wire cross-section, finely stranded, two clampable wires, max. | 1 mm ² |
| Blade size | size PH1 | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC001437 | ETIM 7.0 | EC001437 |
| ETIM 8.0 | EC001437 | ETIM 9.0 | EC001437 |
| ECLASS 9.0 | 27-37-16-01 | ECLASS 9.1 | 27-37-16-01 |
| ECLASS 10.0 | 27-37-16-01 | ECLASS 11.0 | 27-37-16-01 |
| ECLASS 12.0 | 27-37-16-01 | ECLASS 13.0 | 27-37-16-01 |

Environmental Product Compliance

| | |
|------------|---|
| REACH SVHC | / |
|------------|---|

Approvals

Approvals



| | |
|------|---------|
| ROHS | Conform |
|------|---------|

DRMKIT 230VAC 4CO LD

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Approval/Certificate/Document of Conformity

[EU Konformitätserklärung / EU Declaration of Conformity](#)

Engineering Data

[CAD data – STEP](#)

Engineering Data

[Zuken E3.S](#)

Catalogues

[Catalogues in PDF-format](#)


DRMKIT 230VAC 4CO LD

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany


www.weidmueller.com

Drawings


Wiring diagram

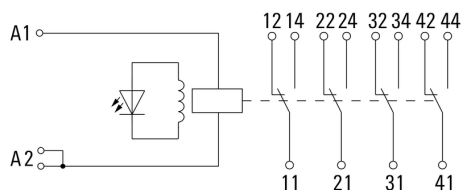


Graph

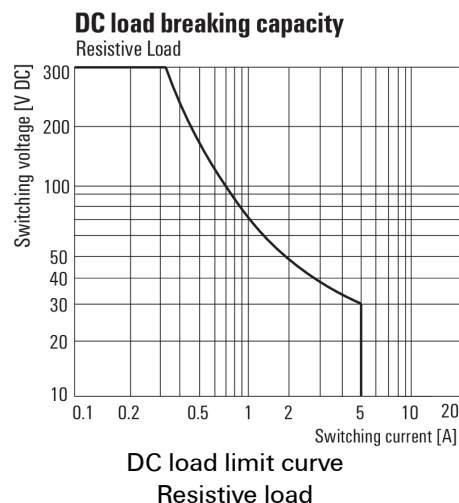


Graph

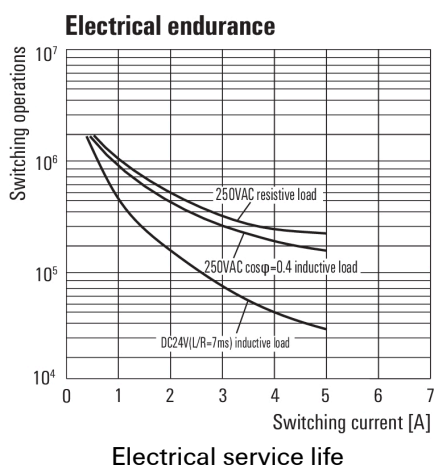


Graph

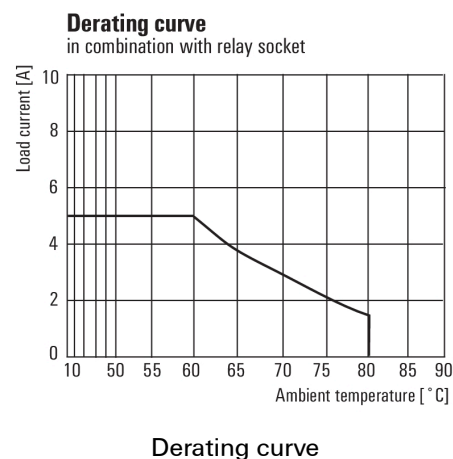

Graph

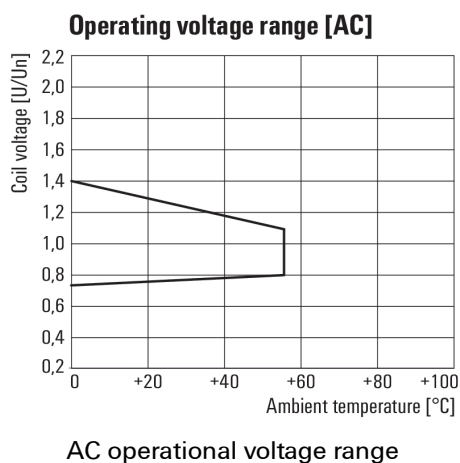

Dimensional drawing

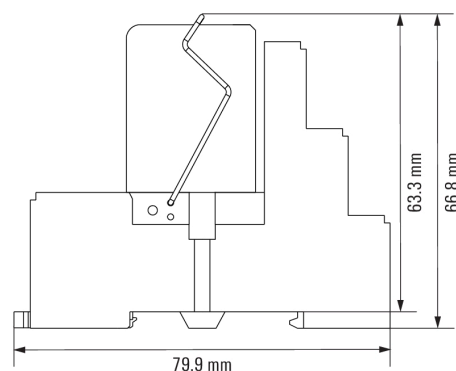

DRMKIT 230VAC 4CO LD**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****LED**

Pluggable protective modules for the D-SERIES relay sockets, with optional protective functions.

- With green LED

General ordering data

| | | |
|------------|----------------------------|--|
| Type | RIM 3 110/230VUC | Version |
| Order No. | 7940018455 | D-SERIES, LED module, Rated control voltage: 110...230 V UC, Plug-in |
| GTIN (EAN) | 4032248878185 | connection |
| Qty. | 10 pc(s). | |

ESG 6/15**Guaranteed long service life: ESG**

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

Your benefits with MultiMark

- "Different materials for various requirements"
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

General ordering data

| | | |
|------------|----------------------------|---------------------------------------|
| Type | ESG 6/15 MM WS | Version |
| Order No. | 2619940000 | ESG, Device markers, 6 x 15 mm, white |
| GTIN (EAN) | 4050118626148 | |
| Qty. | 3,000 pc(s). | |

DRMKIT 230VAC 4CO LD

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Custom printing



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | ESG 9/26 SCM ECO MC SDR | Version |
| Order No. | 1525800000 | ESG, Device markers x 26 mm, PA 66, Colour: To customer |
| GTIN (EAN) | 4050118331875 | specification |
| Qty. | 80 pc(s). | |

Crosshead screwdriver Phillips



Crosshead screwdriver, Phillips, SDK PH DIN 5262, ISO 8764/2-PH, output to ISO 8764-PH, ChromTop tip, SoftFinish grip

General ordering data

| | | |
|------------|----------------------------|---|
| Type | SDK PH1 X 80 | Version |
| Order No. | 2749410000 | Screwdriver, Blade width (B): 1 mm, 80 mm, Blade thickness (A): |
| GTIN (EAN) | 4050118895636 | |
| Qty. | 1 pc(s). | |

DRMKIT 230VAC 4CO LD**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Cross-connection for socket with screw connection**

Cross-connection for the sockets in the D-SERIES DRM.

**General ordering data**

| | | |
|------------|----------------------------|----------------------------------|
| Type | SCM-I QV S | Version |
| Order No. | 1132080000 | RIDERSERIES RCM, Cross-connector |
| GTIN (EAN) | 4032248912193 | |
| Qty. | 10 pc(s). | |

Retaining clips

Retaining clip for D-SERIES DRM relays

- Metal and plastic retaining clip

**General ordering data**

| | | |
|------------|----------------------------|------------------------------|
| Type | SCM CLIP P | Version |
| Order No. | 7760056367 | D-SERIES DRM, Retaining clip |
| GTIN (EAN) | 6944169773334 | |
| Qty. | 5 pc(s). | |

DRMKIT 230VAC 4CO LD

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories**ESG 6/17****Guaranteed long service life: ESG**

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

Your benefits with MultiMark

- "Different materials for various requirements"
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

General ordering data

| | | |
|------------|----------------------------|---------------------------------------|
| Type | ESG 6/17 MM WS | Version |
| Order No. | 2005100000 | ESG, Device markers, 6 x 17 mm, white |
| GTIN (EAN) | 4050118390728 | |
| Qty. | 3,000 pc(s). | |

Crosshead screwdriver, Phillips

VDE insulated screwdriver sets, for working on live parts up to 1000 V AC and 1500 V DC, DIN EN 60900. IEC 900. Each piece is "GS" safety tested. Blade made from fully hardened, high-alloy chromium-vanadium-molybdenum steel, gun-metal finish.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | SDIK SLIM PH1 X 80 | Version |
| Order No. | 2749650000 | Screwdriver, Blade width (B): 1 mm, 80 mm, Blade thickness (A): 1 |
| GTIN (EAN) | 4050118896398 | |
| Qty. | 1 pc(s). | |

DRMKIT 230VAC 4CO LD

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | ESG 9/26 SCM ECO MC NE ... | Version |
| Order No. | 1520990000 | ESG, Device markers x 26 mm, PA 66, Colour: yellow |
| GTIN (EAN) | 4050118327861 | |
| Qty. | 80 pc(s). | |
| Type | ESG 9/26 SCM ECO MC NE ... | Version |
| Order No. | 1521000000 | ESG, Device markers x 26 mm, PA 66, Colour: grey |
| GTIN (EAN) | 4050118327878 | |
| Qty. | 80 pc(s). | |
| Type | ESG 9/26 SCM ECO MC NE ... | Version |
| Order No. | 1520980000 | ESG, Device markers x 26 mm, PA 66, Colour: white |
| GTIN (EAN) | 4050118327939 | |
| Qty. | 80 pc(s). | |

Crosshead screwdriver Phillips



VDE insulated crosshead screwdriver, for Phillips screws, SDIK PH DIN 7438, ISO 8764/2-PH, output to ISO 8764-PH, SoftFinish grip

General ordering data

| | | |
|------------|----------------------------|---|
| Type | SDIK PH1 X 80 | Version |
| Order No. | 2749890000 | Screwdriver, Blade width (B): 1 mm, 80 mm, Blade thickness (A): 1 |
| GTIN (EAN) | 4050118897098 | |
| Qty. | 1 pc(s). | |

DRMKIT 230VAC 4CO LD**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Protection modules**

Pluggable protective modules for the D-SERIES relay sockets, with optional protective functions.

- With free-wheeling diode or RC filter

General ordering data

| | | |
|------------|----------------------------|---|
| Type | RIM 3 110/230VAC | Version |
| Order No. | 7760056014 | D-SERIES, RC filter, Rated control voltage: 110...230 V AC, Plug-in |
| GTIN (EAN) | 4032248878109 | connection |
| Qty. | 10 pc(s). | |
| Type | RIM 3 110/230VAC LED | Version |
| Order No. | 7760056045 | D-SERIES, RC filter, Rated control voltage: 110...230 V AC, Plug-in |
| GTIN (EAN) | 4032248878147 | connection |
| Qty. | 10 pc(s). | |


DRMKIT 230VAC 4CO LD

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Miscellaneous

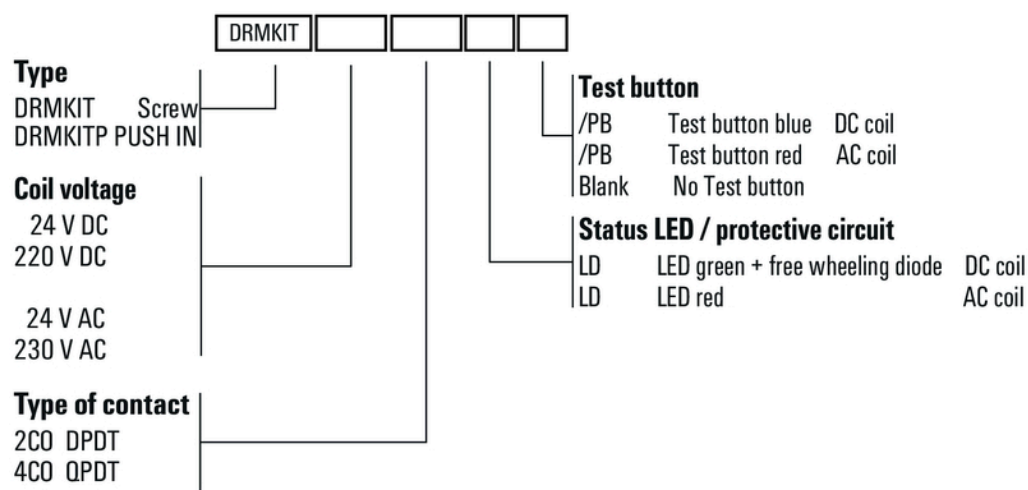

Type codes