

**HDC 24B AZO****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**IP65**

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

Version	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Bulkhead housing, Central locking at the top, Standard
Order No.	<a href="#">1611350000</a>
Type	HDC 24B AZO
GTIN (EAN)	4008190870805
Qty.	1 pc(s).

## HDC 24B AZO

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Height	29.3 mm	Height (inches)	1.154 inch
Width	58.5 mm	Width (inches)	2.303 inch
Mounting dimension - height	32 mm	Mounting dimension - width	130 mm
Net weight	108 g		

## Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

## Dimensions

Height of base B1	5.3 mm	Height of housing B	29 mm
Hole pitch length A2	130 mm	Total length housing	120 mm
Width base C1	47 mm	Width housing C	43 mm

## General data

EMC housings	No	Housing main material	diecast aluminium
Material of locking element	Stainless steel, rust-proof	Protection degree	IP65 (in plugged condition)
Surface finish	Powder coating		

## Version

BG	8	Clamp version	Central-locking clamp
Colour (RAL)	RAL 7035	Design	Standard
Design of housing	Bulkhead housing	Design of locking system	Central locking at the top
Sealing	NBR	Size	8
Suitable for ModuPlug®	Yes	Top part/bottom part/lid	lower part
Type	Bulkhead (feed-through)		

## Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-02-02
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02
ECLASS 14.0	27-44-02-02		

Substance	Acetone
Chemical resistance	Conditionally resistant
Substance	Drilling oil
Chemical resistance	Resistant
Substance	Diesel
Chemical resistance	Resistant
Substance	Ethyl alcohol
Chemical resistance	Resistant
Substance	Transmission oil
Chemical resistance	Resistant

## HDC 24B AZO

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

Substance	Hydraulic oil
Chemical resistance	Resistant
Substance	Coolant
Chemical resistance	Resistant
Substance	Petroleum benzine
Chemical resistance	Resistant
Substance	Sweat
Chemical resistance	Resistant
Substance	Premium gasoline
Chemical resistance	Conditionally resistant
Substance	Water
Chemical resistance	Resistant
Substance	UV
Chemical resistance	Unstable
Substance	Ozone
Chemical resistance	Unstable

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	d447edfa-0214-4f34-b5ba-82eae491b46a
Chemical resistance	de.myview.objectmodel.impl.BlockImpl@17ad94d de.myview.objectmodel.impl.BlockImpl@253525a7 de.myview.objectmodel.impl.BlockImpl@7a254c0 de.myview.objectmodel.impl.BlockImpl@36e8347d de.myview.objectmodel.impl.BlockImpl@610f235c de.myview.objectmodel.impl.BlockImpl@6d1b3ac7 de.myview.objectmodel.impl.BlockImpl@780a77f0 de.myview.objectmodel.impl.BlockImpl@fb6ff50 de.myview.objectmodel.impl.BlockImpl@173b2839 de.myview.objectmodel.impl.BlockImpl@23c2f51b de.myview.objectmodel.impl.BlockImpl@8dca364 de.myview.objectmodel.impl.BlockImpl@30289150 de.myview.objectmodel.impl.BlockImpl@7e1c1d8c
RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6bl

## Important note

Product information	When mounting the housings, make sure that the flat gasket is correctly seated.
---------------------	---

## Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E92202

## HDC 24B AZO

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

### Downloads

Approval/Certificate/Document of Con-  
formity

[Manufacturer's declaration](#)

Engineering Data

[CAD data – STEP](#)

Product Change Notification

[20220214 Technical change to HDC housings](#)

[20220214 Technische Änderung bei HDC-Gehäusen](#)

Technical Documentation

[1611350000 HDC\\_24B\\_AZO\\_STP\\_Blatt\\_1.pdf](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures

[FL FIELDWIRING EN](#)

[FL FIELDWIRING EN](#)

### HDC 24B AZO

**Weidmüller Interface GmbH & Co. KG**


Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

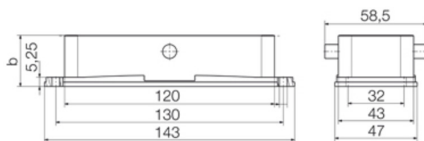

## HDC 24B AZO

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Housing, cable entry sideways



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 64D TSZO 1PG29G	Version
Order No.	<a href="#">1663390000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Central locking at the top, high, Size of cable entries: PG 29
GTIN (EAN)	4008190419912	
Qty.	1 pc(s).	
Type	HDC 64D TSZO 1M40G	Version
Order No.	<a href="#">1904690000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Central locking at the top, high, Size of cable entries: M 40
GTIN (EAN)	4032248585281	
Qty.	1 pc(s).	
Type	HDC 64D TSZO 1PG21G	Version
Order No.	<a href="#">1663370000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Central locking at the top, high, Size of cable entries: PG 21
GTIN (EAN)	4008190419899	
Qty.	1 pc(s).	