

HDC 64D TSBU 1PG29G**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**IP65**

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Version	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on lower side, high, Size of cable entries: PG 29
Order No.	1661320000
Type	HDC 64D TSBU 1PG29G
GTIN (EAN)	4008190417871
Qty.	1 pc(s).

HDC 64D TSBU 1PG29G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height	76 mm	Height (inches)	2.992 inch
Width	59 mm	Width (inches)	2.323 inch
Net weight	326 g		

Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

Dimensions

Cable entry	w. thread	Height of housing B	76 mm
Total length housing	120 mm	Width housing C	43 mm

General data

EMC housings	No	Housing main material	diecast aluminium
Material of locking element		Protection degree	IP65 (in plugged condition)
Surface finish	Stainless steel, rust-proof		
	Powder coating		

Version

BG	8	Cable entry	w. thread
Clamp version	Side-locking clamp	Colour (RAL)	RAL 7035
Design		Design of housing	Cable entry from side, Plug housing
	high		
Design of locking system	Side-locking clamp on lower side	Internal thread	PG 29
Number of cable entry on top	0	Number of cable entry sideways	1
Size	8	Size of cable entries	PG 29
Suitable for ModuPlug®	Yes	Top part/bottom part/lid	upper part
Type	Plug		

Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-02-02
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Substance	Acetone
Chemical resistance	Conditionally resistant
Substance	Drilling oil
Chemical resistance	Resistant
Substance	Diesel
Chemical resistance	Resistant
Substance	Ethyl alcohol
Chemical resistance	Resistant
Substance	Transmission oil
Chemical resistance	Resistant

Creation date July 25, 2024 12:47:05 AM CEST

HDC 64D TSBU 1PG29G**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data**

Substance	Hydraulic oil
Chemical resistance	Resistant
Substance	Coolant
Chemical resistance	Resistant
Substance	Petroleum benzine
Chemical resistance	Resistant
Substance	Sweat
Chemical resistance	Resistant
Substance	Premium gasoline
Chemical resistance	Conditionally resistant
Substance	Water
Chemical resistance	Resistant
Substance	UV
Chemical resistance	Unstable
Substance	Ozone
Chemical resistance	Unstable

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	d447edfa-0214-4f34-b5ba-82eae491b46a
Chemical resistance	de.myview.objectmodel.impl.BlockImpl@66992393 de.myview.objectmodel.impl.BlockImpl@515d5fee de.myview.objectmodel.impl.BlockImpl@1f7076d6 de.myview.objectmodel.impl.BlockImpl@7398236f de.myview.objectmodel.impl.BlockImpl@5c321334 de.myview.objectmodel.impl.BlockImpl@67ab9573 de.myview.objectmodel.impl.BlockImpl@7bf19996 de.myview.objectmodel.impl.BlockImpl@49c05edc de.myview.objectmodel.impl.BlockImpl@5a74f63 de.myview.objectmodel.impl.BlockImpl@3e9c52a9 de.myview.objectmodel.impl.BlockImpl@49d651c5 de.myview.objectmodel.impl.BlockImpl@2abc09d de.myview.objectmodel.impl.BlockImpl@3dc85bfc
RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6bl

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E92202

HDC 64D TSBU 1PG29G

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Downloads

Approval/Certificate/Document of Conformity

[Manufacturer's declaration](#)

Engineering Data

[CAD data – STEP](#)

Engineering Data

[Zuken E3.S](#)

Product Change Notification

[20220214 Technical change to HDC housings](#)

[20220214 Technische Änderung bei HDC-Gehäusen](#)

Technical Documentation

[1661320000_HDC_64D_TSBU_1PG29G_STP_Blatt_1.pdf](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures

[FL FIELDWIRING EN](#)


[FL FIELDWIRING EN](#)

HDC 64D TSBU 1PG29G

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

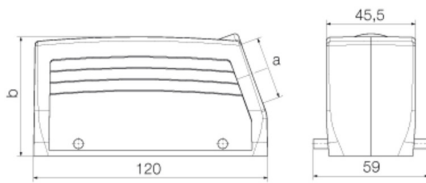

HDC 64D TSBU 1PG29G

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Cover



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 24B DMDQ 2QB	Version
Order No.	1665640000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cover for upper part of housing, Side-locking clamp on lower side, Standard
GTIN (EAN)	4008190422660	
Qty.	1 pc(s).	
Type	HDC 24B DMDQ 2QB N	Version
Order No.	2559760000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cover for upper part of housing, Side-locking clamp on lower side, Standard
GTIN (EAN)	4050118676754	
Qty.	1 pc(s).	

Bulkhead housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 24B ABU N	Version
Order No.	2488600000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Bulkhead housing, Side-locking clamp on lower side, Standard
GTIN (EAN)	4050118541533	
Qty.	1 pc(s).	

HDC 64D TSBU 1PG29G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	HDC 24B ABU	Version
Order No.	1212400000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Bulkhead housing, Side-locking clamp on lower side, Side-locking clamp not replaceable, Standard
GTIN (EAN)	4008190083939	
Qty.	1 pc(s).	

Coupling hood



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 24B KBU 1PG29G	Version
Order No.	1661730000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 29
GTIN (EAN)	4008190418281	
Qty.	1 pc(s).	
Type	HDC 64D KBU 1M32G	Version
Order No.	1786960000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248204205	
Qty.	1 pc(s).	
Type	HDC 64D KBU 1M32G N	Version
Order No.	2559910000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4050118677416	
Qty.	1 pc(s).	
Type	HDC 64D KBU 1PG29G	Version
Order No.	1661810000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4008190418359	
Qty.	1 pc(s).	
Type	HDC 24B KBU 1M25G	Version
Order No.	1787920000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248205363	
Qty.	1 pc(s).	
Type	HDC 24B KBU 1PG21G	Version
Order No.	1661720000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4008190418274	
Qty.	1 pc(s).	

HDC 64D TSBU 1PG29G

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Base housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 64D SBU 2M32G N	Version
Order No.	2550540000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4064675005087	
Qty.	1 pc(s).	
Type	HDC 24B SBU 2M25G	Version
Order No.	1787870000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248205318	
Qty.	1 pc(s).	
Type	HDC 24B SBU 2PG21G	Version
Order No.	1661520000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4008190418076	
Qty.	1 pc(s).	
Type	HDC 24B SBU 1M25G N	Version
Order No.	2560960000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4050118673227	
Qty.	1 pc(s).	
Type	HDC 24B SBU 1PG21G N	Version
Order No.	2560750000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4050118676747	
Qty.	1 pc(s).	
Type	HDC 64D SBU 1M25G	Version
Order No.	1904340000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 25
GTIN (EAN)	4032248585601	
Qty.	1 pc(s).	
Type	HDC 64D SBU 2PG21G	Version
Order No.	1661590000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: PG 21
GTIN (EAN)	4008190418144	
Qty.	1 pc(s).	
Type	HDC 64D SBU 2PG29G N	Version
Order No.	2560790000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4050118894103	
Qty.	1 pc(s).	

HDC 64D TSBU 1PG29G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	HDC 64D SBU 2M25G	Version
Order No.	1786890000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 25
GTIN (EAN)	4032248204137	
Qty.	1 pc(s).	
Type	HDC 24B SBU 1M25G	Version
Order No.	1901150000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248521258	
Qty.	1 pc(s).	
Type	HDC 64D SBU 1M32G	Version
Order No.	1904350000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248585298	
Qty.	1 pc(s).	
Type	HDC 24B SBU 1PG21G	Version
Order No.	1661510000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4008190418069	
Qty.	1 pc(s).	
Type	HDC 64D SBU 2M32G	Version
Order No.	1786880000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248204120	
Qty.	1 pc(s).	
Type	HDC 64D SBU 2PG29G	Version
Order No.	1661630000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4008190418182	
Qty.	1 pc(s).	
Type	HDC 24B SBU 2M25G N	Version
Order No.	2560970000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4050118676730	
Qty.	1 pc(s).	
Type	HDC 64D SBU 1M32G N	Version
Order No.	2561050000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4050118680195	
Qty.	1 pc(s).	
Type	HDC 64D SBU 2M25G N	Version
Order No.	2561060000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4050118680508	
Qty.	1 pc(s).	