

**HDC 06B DMDL 1LB****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

Version	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cover for upper part of housing, End-locking clamp, lower side, Standard
Order No.	<a href="#">1665210000</a>
Type	HDC 06B DMDL 1LB
GTIN (EAN)	4008190421915
Qty.	1 pc(s).

## HDC 06B DMDL 1LB

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	72 mm	Depth (inches)	2.835 inch
Height	18 mm	Height (inches)	0.709 inch
Width	43 mm	Width (inches)	1.693 inch
Net weight	92 g		

## Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

## Dimensions

Cable entry	For hoods	Height of housing B	18 mm
Total length housing	60 mm	Width housing C	43 mm

## General data

EMC housings	No	Housing main material	diecast aluminium
Material of locking element	Stainless steel, rust-proof	Protection degree	IP65 (in plugged condition)
Surface finish	Powder coating	Tightening torque	1.2 Nm

## Version

BG	3	Cable entry	For hoods
Clamp version	End-locking clamp	Colour (RAL)	RAL 7035
Design	Standard	Design of housing	Cover for upper part of housing
Design of locking system	End-locking clamp, lower side	Sealing	NBR
Size	3	Suitable for ModuPlug®	Yes
Tightening torque	1.2 Nm	Top part/bottom part/lid	Cover
Type	Cover		

## Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-02-02
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Substance	Acetone
Chemical resistance	Conditionally resistant
Substance	Drilling oil
Chemical resistance	Resistant
Substance	Diesel
Chemical resistance	Resistant
Substance	Ethyl alcohol
Chemical resistance	Resistant
Substance	Transmission oil
Chemical resistance	Resistant

Creation date June 3, 2024 5:00:08 PM CEST

Catalogue status 01.06.2024 / We reserve the right to make technical changes.

## HDC 06B DMDL 1LB

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

Substance	Hydraulic oil
Chemical resistance	Resistant
Substance	Coolant
Chemical resistance	Resistant
Substance	Petroleum benzine
Chemical resistance	Resistant
Substance	Sweat
Chemical resistance	Resistant
Substance	Premium gasoline
Chemical resistance	Conditionally resistant
Substance	Water
Chemical resistance	Resistant
Substance	UV
Chemical resistance	Unstable
Substance	Ozone
Chemical resistance	Unstable

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1 Potassium perfluorobutane sulfonate 29420-49-3
SCIP	e98b2b24-ba23-41bf-8d19-Odda3647412f
Chemical resistance	de.myview.objectmodel.impl.BlockImpl@782c0ec8 de.myview.objectmodel.impl.BlockImpl@3bfeb2f3 de.myview.objectmodel.impl.BlockImpl@3e6d9d7a de.myview.objectmodel.impl.BlockImpl@7e4fec89 de.myview.objectmodel.impl.BlockImpl@668de7c6 de.myview.objectmodel.impl.BlockImpl@28aaa8ce de.myview.objectmodel.impl.BlockImpl@7a7e66ec de.myview.objectmodel.impl.BlockImpl@7bd4e68e de.myview.objectmodel.impl.BlockImpl@726e9de5 de.myview.objectmodel.impl.BlockImpl@fffb7be de.myview.objectmodel.impl.BlockImpl@63fe9ab de.myview.objectmodel.impl.BlockImpl@5a839f74 de.myview.objectmodel.impl.BlockImpl@5c84a074

## Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E92202

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">Manufacturer's declaration</a>
Engineering Data	<a href="#">CAD data – STEP</a>
Product Change Notification	<a href="#">20220214 Technical change to HDC housings</a> <a href="#">20220214 Technische Änderung bei HDC-Gehäusen</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a> <a href="#">FL FIELDWIRING EN</a>

Creation date June 3, 2024 5:00:08 PM CEST


Catalogue status 01.06.2024 / We reserve the right to make technical changes.

## HDC 06B DMDL 1LB

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

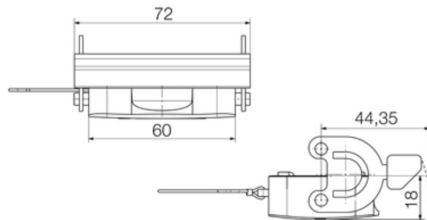

## HDC 06B DMDL 1LB

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Hood, Cable Entry at top



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 16D TOLU 1M32G	Version
Order No.	<a href="#">1787490000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248204830	
Qty.	1 pc(s).	
Type	HDC 06B TOLU 1PG13G	Version
Order No.	<a href="#">1670500000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, Standard, Size of cable entries: PG 13.5
GTIN (EAN)	4008190431587	
Qty.	1 pc(s).	
Type	HDC 16D TOLU 1PG21G	Version
Order No.	<a href="#">1652680000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, high, Size of cable entries: PG 21
GTIN (EAN)	4008190402754	
Qty.	1 pc(s).	
Type	HDC 16D TOLU 1M25G	Version
Order No.	<a href="#">1787500000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, high, Size of cable entries: M 25
GTIN (EAN)	4032248204847	
Qty.	1 pc(s).	
Type	HDC 06B TOLU 1M25G	Version
Order No.	<a href="#">1788110000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248205554	
Qty.	1 pc(s).	
Type	HDC 16D TOLU 1PG29G	Version
Order No.	<a href="#">1652700000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4008190402778	
Qty.	1 pc(s).	
Type	HDC 06B TOLU 1PG16G	Version
Order No.	<a href="#">1652640000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, Standard, Size of cable entries: PG 16
GTIN (EAN)	4008190402716	
Qty.	1 pc(s).	
Type	HDC 06B TOLU 1M20G	Version
Order No.	<a href="#">1788120000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, Standard, Size of cable entries: M 20
GTIN (EAN)	4032248205561	
Qty.	1 pc(s).	

## HDC 06B DMDL 1LB

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Hood, Cable Entry sideways



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 06B TSLU 1M25G	Version
Order No.	<a href="#">1788090000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4032248205530	lower side, Standard, Size of cable entries: M 25
Qty.	1 pc(s).	
Type	HDC 16D TSLU 1PG21G	Version
Order No.	<a href="#">1652560000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4008190402631	lower side, high, Size of cable entries: PG 21
Qty.	1 pc(s).	
Type	HDC 16D TSLU 1PG29G	Version
Order No.	<a href="#">1652580000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4008190402655	lower side, high, Size of cable entries: PG 29
Qty.	1 pc(s).	
Type	HDC 16D TSLU 1M25G	Version
Order No.	<a href="#">1787480000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4032248204823	lower side, high, Size of cable entries: M 25
Qty.	1 pc(s).	
Type	HDC 16D TSLU 1M32G	Version
Order No.	<a href="#">1787470000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4032248204816	lower side, high, Size of cable entries: M 32
Qty.	1 pc(s).	
Type	HDC 06B TSLU 1M20G	Version
Order No.	<a href="#">1788100000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4032248205547	lower side, Standard, Size of cable entries: M 20
Qty.	1 pc(s).	
Type	HDC 06B TSLU 1PG16G	Version
Order No.	<a href="#">1652520000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4008190402594	lower side, Standard, Size of cable entries: PG 16
Qty.	1 pc(s).	
Type	HDC 06B TSLU 1PG13G	Version
Order No.	<a href="#">1670530000</a>	HDC enclosures, Size: 3, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp,
GTIN (EAN)	4008190431617	lower side, Standard, Size of cable entries: PG 13.5
Qty.	1 pc(s).	