

HDC 24B DMDQ 4B0**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**IP65**

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Version	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cover for upper part of housing, Side-locking clamp on upper side, Standard
Order No.	1665650000
Type	HDC 24B DMDQ 4B0
GTIN (EAN)	4008190422677
Qty.	1 pc(s).

HDC 24B DMDQ 4B0

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height	22.5 mm	Height (inches)	0.886 inch
Width	43 mm	Width (inches)	1.693 inch
Net weight	87 g		

Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

Dimensions

Cable entry	For hoods	Height of housing B	22 mm
Total length housing	120 mm	Width housing C	43 mm

General data

EMC housings	No	Housing main material	diecast aluminium
Material of locking element		Protection degree	IP65 (in plugged condition)
Surface finish	Stainless steel, rust-proof		
	Powder coating		

Version

BG	8	Cable entry	For hoods
Clamp version	Side-locking clamp	Colour (RAL)	RAL 7035
Design		Design of housing	Cover for upper part of housing
	Standard		
Design of locking system	Side-locking clamp on upper side	Sealing	NBR
Size	8	Suitable for ModuPlug®	Yes
Top part/bottom part/lid	Cover	Type	Cover

Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-02-02
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Substance	Acetone
Chemical resistance	Conditionally resistant
Substance	Drilling oil
Chemical resistance	Resistant
Substance	Diesel
Chemical resistance	Resistant
Substance	Ethyl alcohol
Chemical resistance	Resistant
Substance	Transmission oil
Chemical resistance	Resistant
Substance	Hydraulic oil

HDC 24B DMDQ 4BO

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Chemical resistance	Resistant
Substance	Coolant
Chemical resistance	Resistant
Substance	Petroleum benzine
Chemical resistance	Resistant
Substance	Sweat
Chemical resistance	Resistant
Substance	Premium gasoline
Chemical resistance	Conditionally resistant
Substance	Water
Chemical resistance	Resistant
Substance	UV
Chemical resistance	Unstable
Substance	Ozone
Chemical resistance	Unstable

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	d447edfa-0214-4f34-b5ba-82eae491b46a
Chemical resistance	de.myview.objectmodel.impl.BlockImpl@4a9d511c de.myview.objectmodel.impl.BlockImpl@404a94e5 de.myview.objectmodel.impl.BlockImpl@1034bd55 de.myview.objectmodel.impl.BlockImpl@11d2ea60 de.myview.objectmodel.impl.BlockImpl@31674cf7 de.myview.objectmodel.impl.BlockImpl@259e0b82 de.myview.objectmodel.impl.BlockImpl@10f5d471 de.myview.objectmodel.impl.BlockImpl@16f2bde5 de.myview.objectmodel.impl.BlockImpl@1d795b38 de.myview.objectmodel.impl.BlockImpl@48ee810e de.myview.objectmodel.impl.BlockImpl@7606823e de.myview.objectmodel.impl.BlockImpl@7518148e de.myview.objectmodel.impl.BlockImpl@226f318e

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E92202

Downloads


Approval/Certificate/Document of Conformity	Manufacturer's declaration
Engineering Data	CAD data – STEP
Product Change Notification	20220214 Technical change to HDC housings 20220214 Technische Änderung bei HDC-Gehäusen
Technical Documentation	1665650000_HDC_24B_DMDQ_4BO_STP_Blatt_1.pdf
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN FL FIELDWIRING EN

HDC 24B DMDQ 4B0

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

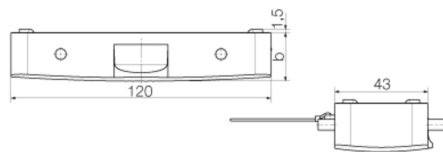

HDC 24B DMDQ 4B0

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Hood, Cable Entry sideways



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 64D TSBO 1PG21G	Version
Order No.	1661940000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on upper side, high, Size of cable entries: PG 21
GTIN (EAN)	4008190418472	
Qty.	1 pc(s).	
Type	HDC 64D TSBO 1M25G	Version
Order No.	1786800000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on upper side, high, Size of cable entries: M 25
GTIN (EAN)	4032248204045	
Qty.	1 pc(s).	
Type	HDC 64D TSBO 1PG29G	Version
Order No.	1661960000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on upper side, high, Size of cable entries: PG 29
GTIN (EAN)	4008190418496	
Qty.	1 pc(s).	
Type	HDC 64D TSBO 1M32G	Version
Order No.	1786790000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on upper side, high, Size of cable entries: M 32
GTIN (EAN)	4032248204038	
Qty.	1 pc(s).	
Type	HDC 24B TSBO 1PG29G	Version
Order No.	1661880000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on upper side, Standard, Size of cable entries: PG 29
GTIN (EAN)	4008190418410	
Qty.	1 pc(s).	
Type	HDC 24B TSBO 1M25G	Version
Order No.	1787780000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on upper side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248205226	
Qty.	1 pc(s).	
Type	HDC 24B TSBO 1M32G	Version
Order No.	1787770000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on upper side, Standard, Size of cable entries: M 32
GTIN (EAN)	4032248205219	
Qty.	1 pc(s).	
Type	HDC 24B TSBO 1PG21G	Version
Order No.	1661860000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on upper side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4008190418397	
Qty.	1 pc(s).	

HDC 24B DMDQ 4B0

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Hood, Cable Entry at top



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 64D TOBO 1PG29G	Version
Order No.	1662100000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on upper side, high, Size of cable entries: PG 29
GTIN (EAN)	4008190418625	
Qty.	1 pc(s).	
Type	HDC 64D TOBO 1PG21G	Version
Order No.	1662080000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on upper side, high, Size of cable entries: PG 21
GTIN (EAN)	4008190418601	
Qty.	1 pc(s).	
Type	HDC 24B TOBO 1PG29G	Version
Order No.	1662020000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on upper side, Standard, Size of cable entries: PG 29
GTIN (EAN)	4008190418540	
Qty.	1 pc(s).	
Type	HDC 24B TOBO 1M32G	Version
Order No.	1787830000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on upper side, Standard, Size of cable entries: M 32
GTIN (EAN)	4032248205271	
Qty.	1 pc(s).	