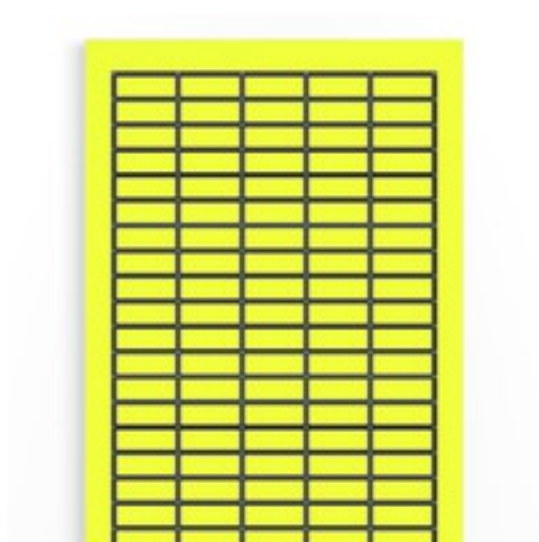


PAGETAB 28/11**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

PageTab are woven-fabric labels in sheet form. Except for the 8 x 20 version, all labels have a black border.

General ordering data

Version	Device markers, Device markers, 11 x 28 mm, yellow
Order No.	1686190000
Type	PAGETAB 28/11
GTIN (EAN)	4008190492601
Qty.	1 pc(s).

PAGETAB 28/11**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Depth	0.08 mm	Depth (inches)	0.003 inch
Height	11 mm	Height (inches)	0.433 inch
Width	28 mm	Width (inches)	1.102 inch
Net weight	12.4 g		

Temperatures

Operating temperature range	-29...93 °C
-----------------------------	-------------

General data

Adhesive	Permanent acrylic copolymer		
Colour	yellow		
Material	Acrylic-coated fibre webbing		
Material colour according to resistance code	4		
Number of markers per combination	1 Label sheet = 125 Device markers		
Number of markers per packaging unit	3,125		
Number of markers per packaging unit	Form of supply	Label sheet	
	Number of combinations per packaging unit	25	
	Number of markers per combination	125	
Number per sheet	125		
Operating temperature range	-29...93 °C		
Operating temperature range, max.	93 °C		
Operating temperature range, min.	-29 °C		
Printing	Neutral		
Version	Self-adhesive		
Width	28 mm		

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04

Approvals

ROHS	Conform
------	---------

Downloads

Catalogues	Catalogues in PDF-format
------------	--

Drawings

