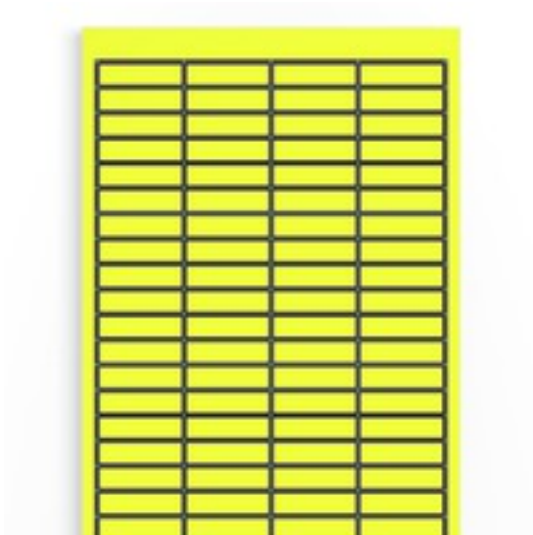


**PAGETAB 38/11****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Similar to illustration

PageTab are woven-fabric labels in sheet form. Except for the 8 x 20 version, all labels have a black border.

**General ordering data**

Version	Device markers, Device markers, 11 x 38 mm, yellow
Order No.	<a href="#">1686200000</a>
Type	PAGETAB 38/11
GTIN (EAN)	4008190492632
Qty.	25 pc(s).

**PAGETAB 38/11****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Depth	0.08 mm	Depth (inches)	0.003 inch
Height	11 mm	Height (inches)	0.433 inch
Width	38 mm	Width (inches)	1.496 inch
Net weight	12.36 g		

**Temperatures**

Operating temperature range	-29...93 °C
-----------------------------	-------------

**General data**

Adhesive	Permanent acrylic copolymer		
Colour	yellow		
Material	Acrylic-coated fibre webbing		
Material colour according to resistance code	4		
Number of markers per combination	1 Label sheet = 100 Device markers		
Number of markers per packaging unit	Number of combinations per packaging unit	25	
	Number of markers per combination	100	
	Form of supply	Label sheet	
Number of markers per packaging unit	2,500		
Number per sheet	100		
Operating temperature range	-29...93 °C		
Operating temperature range, max.	93 °C		
Operating temperature range, min.	-29 °C		
Printing	Neutral		
Version	Self-adhesive		
Width	38 mm		

**Classifications**

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Catalogues	<a href="#">Catalogues in PDF-format</a>
------------	--

**Drawings**

