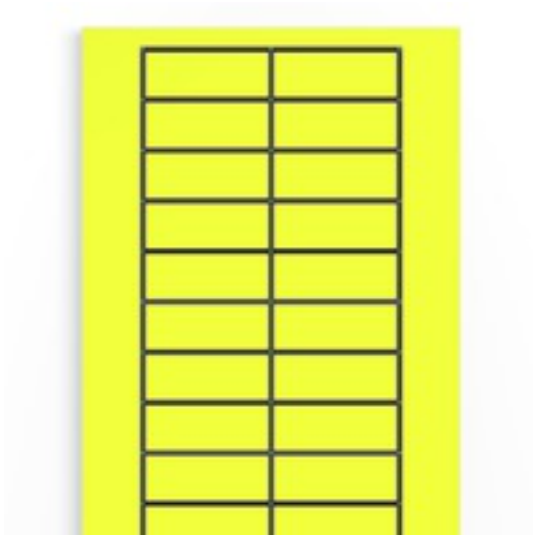


PAGETAB 56/22**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

PageTab are woven-fabric labels in sheet form. Except for the 8 x 20 version, all labels have a black border.

General ordering data

Version	Device markers, Device markers, 22 x 56 mm, yellow
Order No.	1686210000
Type	PAGETAB 56/22
GTIN (EAN)	4008190492649
Qty.	25 pc(s).

PAGETAB 56/22**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Depth	0.08 mm	Depth (inches)	0.003 inch
Height	22 mm	Height (inches)	0.866 inch
Width	56 mm	Width (inches)	2.205 inch
Net weight	11.24 g		

Temperatures

Operating temperature range	-29...93 °C
-----------------------------	-------------

General data

Adhesive	Permanent acrylic copolymer	
Colour	yellow	
Material	Acrylic-coated fibre webbing	
Material colour according to resistance code	4	
Number of markers per combination	1 Label sheet = 24 Device markers	
Number of markers per packaging unit	600	
Number of markers per packaging unit	Form of supply	Label sheet
	Number of combinations per packaging unit	25
	Number of markers per combination	24
Number per sheet	24	
Operating temperature range	-29...93 °C	
Operating temperature range, max.	93 °C	
Operating temperature range, min.	-29 °C	
Printing	Neutral	
Version	Self-adhesive	
Width	56 mm	

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04

Approvals

ROHS	Conform
------	---------

Downloads

Catalogues	Catalogues in PDF-format
------------	--

Drawings

