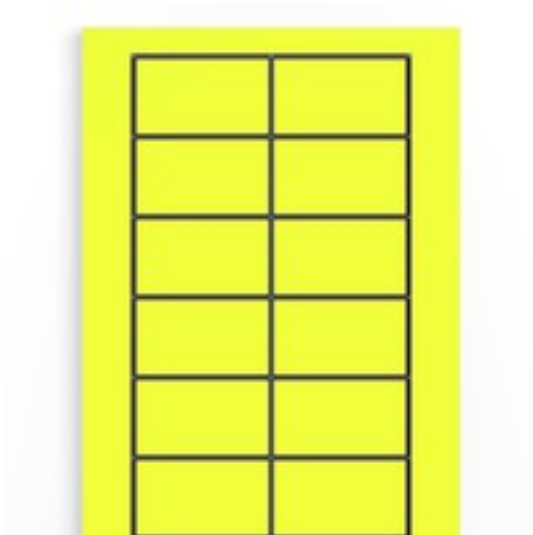


**PAGETAB 60/35****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Similar to illustration



PageTab are woven-fabric labels in sheet form. Except for the 8 x 20 version, all labels have a black border.

**General ordering data**

Version	Device markers, Device markers, 35 x 60 mm, yellow
Order No.	<a href="#">1686220000</a>
Type	PAGETAB 60/35
GTIN (EAN)	4008190492656
Qty.	25 pc(s).

**PAGETAB 60/35****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Depth	0.08 mm	Depth (inches)	0.003 inch
Height	35 mm	Height (inches)	1.378 inch
Width	60 mm	Width (inches)	2.362 inch
Net weight	8.88 g		

**Temperatures**

Operating temperature range	-29...93 °C
-----------------------------	-------------

**General data**

Adhesive	Permanent acrylic copolymer	
Colour	yellow	
Material	Acrylic-coated fibre webbing	
Material colour according to resistance code	4	
Number of markers per combination	1 Label sheet = 16 Device markers	
Number of markers per packaging unit	400	
Number of markers per packaging unit	Form of supply	Label sheet
	Number of combinations per packaging unit	25
	Number of markers per combination	16
Number per sheet	16	
Operating temperature range	-29...93 °C	
Operating temperature range, max.	93 °C	
Operating temperature range, min.	-29 °C	
Printing	Neutral	
Version	Self-adhesive	
Width	60 mm	

**Classifications**

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Catalogues	<a href="#">Catalogues in PDF-format</a>
------------	------------------------------------------

Drawings

