

ESG 7/20 SIRIUS MC NE TU**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | |
|--------------------|--|
| Version | ESG, Device markers x 20 mm, PA 66, Colour: Turquoise, pluggable |
| Order No. | 1736181696 |
| Type | ESG 7/20 SIRIUS MC NE TU |
| GTIN (EAN) | 4008190985967 |
| Qty. | 200 pc(s). |
| compatible printer | 2715590000 2438520000 2438510000 |

ESG 7/20 SIRIUS MC NE TU**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

| | | | |
|------------|--------|-----------------|------------|
| Depth | 0.8 mm | Depth (inches) | 0.031 inch |
| Height | 7 mm | Height (inches) | 0.276 inch |
| Width | 20 mm | Width (inches) | 0.787 inch |
| Net weight | 0.52 g | | |

Temperatures

| | |
|-----------------------------|--------------|
| Operating temperature range | -40...100 °C |
|-----------------------------|--------------|

General data

| | | |
|--------------------------------------|------------------------------|-----------|
| Application/manufacture | Siemens Sirius 3R | |
| Colour | Turquoise | |
| Halogen | No | |
| Material | PA 66 | |
| Number of markers per combination | 1 MultiCard = Device markers | |
| Number of markers per packaging unit | Form of supply | MultiCard |
| Number per roll | 40 | |
| Number per sheet | 40 | |
| Operating temperature range | -40... 100 °C | |
| Operating temperature range, max. | 100 °C | |
| Operating temperature range, min. | -40 °C | |
| UL 94 flammability rating | V-2 | |
| Version | pluggable | |
| Width | 20 mm | |

Device markers

| | |
|---------|----|
| Halogen | No |
|---------|----|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC001288 | ETIM 7.0 | EC001288 |
| ETIM 8.0 | EC001288 | ETIM 9.0 | EC001288 |
| ECLASS 9.0 | 27-40-06-29 | ECLASS 9.1 | 27-40-06-29 |
| ECLASS 10.0 | 27-40-06-29 | ECLASS 11.0 | 27-28-11-04 |
| ECLASS 12.0 | 27-28-11-04 | ECLASS 13.0 | 27-28-11-04 |

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads


| | |
|------------------|--|
| Engineering Data | CAD data – STEP |
| Catalogues | Catalogues in PDF-format |

ESG 7/20 SIRIUS MC NE TU

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

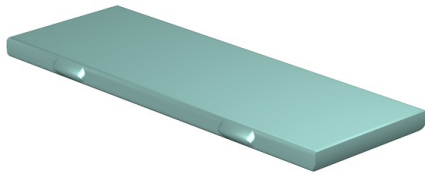

ESG 7/20 SIRIUS MC NE TU

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Accessories



General ordering data

| | | |
|------------|----------------------------|--|
| Type | SCHS3 K | Version |
| Order No. | 1753480000 | Device markers, Accessories x 10 mm, PVC, Colour: black, Self-adhesive |
| GTIN (EAN) | 4032248014347 | |
| Qty. | 1 pc(s). | |
| Type | SCHS4 K | Version |
| Order No. | 1753460000 | Device markers, Accessories x 10 mm, PVC, Colour: grey, Self-adhesive |
| GTIN (EAN) | 4032248014323 | |
| Qty. | 1 pc(s). | |

WKM for inlay tags



The halogen-free, transparent pocket of the WKM offers outstanding protection against environmental influences. Thanks to firm fixation with cable ties, it is suitable for almost all wire cross-sections.

The pre-printed tags are simply inserted into the WKM holder and secured with a clip. WKM cable markers are the right solution for maximum efficiency in on-site marking.

Your advantage when using WKM cables

- Paper and polyester labels can be printed individually with conventional office printers
- The robust design in combination with MultiCard ELS tags guarantees maximum protection against environmental influences

General ordering data

| | | |
|------------|----------------------------|--|
| Type | WKM 8/20 | Version |
| Order No. | 1753490000 | WKM, Conductor and cable markers, 7 - 115 mm, 20 x 8 mm, Wire and cable markers, Transparent |
| GTIN (EAN) | 4032248010615 | |
| Qty. | 50 pc(s). | |