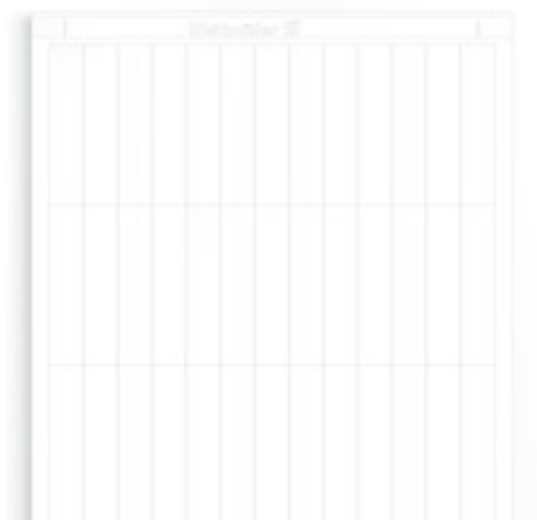


**LM WO 15/140 WS****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Similar to illustration



Self-adhesive polyester labels which are suitable for A4 office laser printer.

**General ordering data**

Version	LaserMark, Conductor and cable markers, 16.2 - 36.4 mm, 15 x 140 mm, white
Order No.	<a href="#">1773880000</a>
Type	LM WO 15/140 WS
GTIN (EAN)	4032248144501
Qty.	10 pc(s).

## LM WO 15/140 WS

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	0.025 mm	Depth (inches)	0.001 inch
Height	15 mm	Height (inches)	0.591 inch
Width	140 mm	Width (inches)	5.512 inch
Net weight	10.2 g		

## Temperatures

Operating temperature range	-40...150 °C
-----------------------------	--------------

## General data

Adhesive	Acrylate		
Colour	white		
Halogen	No		
Material	Polyester film		
Material colour according to resistance code	9		
Number of markers per combination	1 Label sheet = 26 Conductor and cable markers		
Number of markers per packaging unit	Number of markers per combination	26	
	Number of combinations per packaging unit	10	
	Form of supply	Label sheet	
Number of markers per packaging unit	260		
Number per sheet	26		
Operating temperature range	-40... 150 °C		
Operating temperature range, max.	150 °C		
Operating temperature range, min.	-40 °C		
Size of labelling field	15 x 70 mm		
Type of printing	neutral		
UL 94 flammability rating	V-0		
Version	Self-adhesive		
Width	140 mm		

## Conductor and cable markers

Conductor O.D.	16.2 - 36.4 mm	Conductor O.D., max.	36.4 mm
Conductor O.D., min.	16.2 mm	Conductor cross-section, max.	150 mm <sup>2</sup>
Conductor cross-section, min.	70 mm <sup>2</sup>	Cross-section for connected wire	70 - 150 mm <sup>2</sup>
Halogen	No	Text field height	70 mm
Text field width	14.98 mm		

## Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ETIM 9.0	EC001530
ECLASS 9.0	27-40-04-01	ECLASS 9.1	27-40-04-01
ECLASS 10.0	27-40-04-01	ECLASS 11.0	27-28-11-02
ECLASS 12.0	27-28-11-02	ECLASS 13.0	27-28-11-02

## Environmental Product Compliance

REACH SVHC	/
------------	---

## LM WO 15/140 WS

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

### Approvals

ROHS

Conform

### Downloads

Engineering Data

[CAD data – STEP](#)

Engineering Data

[Zuken E3.S](#)

Catalogues

[Catalogues in PDF-format](#)

