

**HDC 64D TOBU 1M32G****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

Version	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
Order No.	<a href="#">1786830000</a>
Type	HDC 64D TOBU 1M32G
GTIN (EAN)	4032248204076
Qty.	1 pc(s).

## HDC 64D TOBU 1M32G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Height	76 mm	Height (inches)	2.992 inch
Width	59 mm	Width (inches)	2.323 inch
Net weight	328 g		

## Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

## Dimensions

Cable entry	w. thread	Height of housing B	76 mm
Total length housing	120 mm	Width housing C	43 mm

## General data

EMC housings	No	Housing main material	diecast aluminium
Material of locking element		Protection degree	IP65 (in plugged condition)
Surface finish	Stainless steel, rust-proof		
	Powder coating		

## Version

BG	8	Cable entry	w. thread
Clamp version	Side-locking clamp	Colour (RAL)	RAL 7035
Design		Design of housing	Cable entry from top, Plug housing
	high		
Design of locking system	Side-locking clamp on lower side	Internal thread	M 32
Number of cable entry on top	1	Number of cable entry sideways	0
Size	8	Size of cable entries	M 32
Suitable for ModuPlug®	Yes	Top part/bottom part/lid	upper part
Type	Plug		

## Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-02-02
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Substance	Acetone
Chemical resistance	Conditionally resistant
Substance	Drilling oil
Chemical resistance	Resistant
Substance	Diesel
Chemical resistance	Resistant
Substance	Ethyl alcohol
Chemical resistance	Resistant
Substance	Transmission oil
Chemical resistance	Resistant

Creation date July 25, 2024 12:41:26 AM CEST

**HDC 64D TOBU 1M32G****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data**

Substance	Hydraulic oil
Chemical resistance	Resistant
Substance	Coolant
Chemical resistance	Resistant
Substance	Petroleum benzine
Chemical resistance	Resistant
Substance	Sweat
Chemical resistance	Resistant
Substance	Premium gasoline
Chemical resistance	Conditionally resistant
Substance	Water
Chemical resistance	Resistant
Substance	UV
Chemical resistance	Unstable
Substance	Ozone
Chemical resistance	Unstable

**Environmental Product Compliance**

REACH SVHC	Lead 7439-92-1
SCIP	d447edfa-0214-4f34-b5ba-82eae491b46a
Chemical resistance	de.myview.objectmodel.impl.BlockImpl@3e08fd1b de.myview.objectmodel.impl.BlockImpl@3dce7a9b de.myview.objectmodel.impl.BlockImpl@7c6501a8 de.myview.objectmodel.impl.BlockImpl@5579e1dc de.myview.objectmodel.impl.BlockImpl@2ce03e4d de.myview.objectmodel.impl.BlockImpl@623493e8 de.myview.objectmodel.impl.BlockImpl@3608b647 de.myview.objectmodel.impl.BlockImpl@2c65c65b de.myview.objectmodel.impl.BlockImpl@1da87cc de.myview.objectmodel.impl.BlockImpl@47b7efcc de.myview.objectmodel.impl.BlockImpl@347ed3f3 de.myview.objectmodel.impl.BlockImpl@362b9c39 de.myview.objectmodel.impl.BlockImpl@639a99d7
RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6bl

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E92202

## HDC 64D TOBU 1M32G

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Technical data

## Downloads

Approval/Certificate/Document of Con-  
formity

[Manufacturer's declaration](#)

Engineering Data

[CAD data – STEP](#)

Product Change Notification

[20220214 Technical change to HDC housings](#)

[20220214 Technische Änderung bei HDC-Gehäusen](#)

Technical Documentation

[1786830000 HDC\\_64D\\_TOBU\\_1M32G\\_STP\\_Blatt\\_1.pdf](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures

[FL FIELDWIRING EN](#)

[FL FIELDWIRING EN](#)

### HDC 64D TOBU 1M32G

**Weidmüller Interface GmbH & Co. KG**


Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

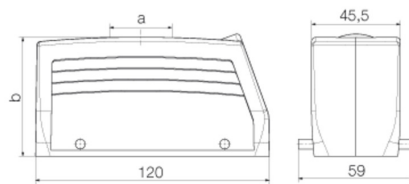

## HDC 64D TOBU 1M32G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Coupling hood



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 24B KBU 1PG21G	Version
Order No.	<a href="#">1661720000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side,
GTIN (EAN)	4008190418274	Standard, Size of cable entries: PG 21
Qty.	1 pc(s).	
Type	HDC 64D KBU 1PG29G	Version
Order No.	<a href="#">1661810000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high,
GTIN (EAN)	4008190418359	Size of cable entries: PG 29
Qty.	1 pc(s).	
Type	HDC 24B KBU 1PG29G	Version
Order No.	<a href="#">1661730000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side,
GTIN (EAN)	4008190418281	Standard, Size of cable entries: PG 29
Qty.	1 pc(s).	
Type	HDC 24B KBU 1M25G	Version
Order No.	<a href="#">1787920000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side,
GTIN (EAN)	4032248205363	Standard, Size of cable entries: M 25
Qty.	1 pc(s).	
Type	HDC 64D KBU 1M32G	Version
Order No.	<a href="#">1786960000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high,
GTIN (EAN)	4032248204205	Size of cable entries: M 32
Qty.	1 pc(s).	
Type	HDC 64D KBU 1M32G N	Version
Order No.	<a href="#">2559910000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high,
GTIN (EAN)	4050118677416	Size of cable entries: M 32
Qty.	1 pc(s).	

## HDC 64D TOBU 1M32G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Bulkhead housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 24B ABU	Version
Order No.	<a href="#">1212400000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Bulkhead housing, Side-locking clamp on lower side, Side-locking clamp not replaceable, Standard
GTIN (EAN)	4008190083939	
Qty.	1 pc(s).	
Type	HDC 24B ABU N	Version
Order No.	<a href="#">2488600000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Bulkhead housing, Side-locking clamp on lower side, Standard
GTIN (EAN)	4050118541533	
Qty.	1 pc(s).	

## Cover



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 24B DMDQ 2QB N	Version
Order No.	<a href="#">2559760000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cover for upper part of housing, Side-locking clamp on lower side, Standard
GTIN (EAN)	4050118676754	
Qty.	1 pc(s).	

## HDC 64D TOBU 1M32G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	HDC 24B DMDQ 2QB	Version
Order No.	<a href="#">1665640000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cover for upper part of housing, Side-locking clamp on lower side, Standard
GTIN (EAN)	4008190422660	
Qty.	1 pc(s).	

## Base housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 24B SBU 2M25G	Version
Order No.	<a href="#">1787870000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248205318	
Qty.	1 pc(s).	
Type	HDC 24B SBU 1PG21G N	Version
Order No.	<a href="#">2560750000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4050118676747	
Qty.	1 pc(s).	
Type	HDC 64D SBU 1M25G	Version
Order No.	<a href="#">1904340000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 25
GTIN (EAN)	4032248585601	
Qty.	1 pc(s).	
Type	HDC 64D SBU 2PG29G	Version
Order No.	<a href="#">1661630000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4008190418182	
Qty.	1 pc(s).	
Type	HDC 64D SBU 2M32G	Version
Order No.	<a href="#">1786880000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248204120	
Qty.	1 pc(s).	
Type	HDC 64D SBU 2M25G	Version
Order No.	<a href="#">1786890000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 25
GTIN (EAN)	4032248204137	
Qty.	1 pc(s).	
Type	HDC 64D SBU 2PG29G N	Version
Order No.	<a href="#">2560790000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4050118894103	
Qty.	1 pc(s).	

Creation date July 25, 2024 12:41:26 AM CEST



## HDC 64D TOBU 1M32G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	HDC 64D SBU 1M32G	Version
Order No.	<a href="#">1904350000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248585298	
Qty.	1 pc(s).	
Type	HDC 24B SBU 1M25G N	Version
Order No.	<a href="#">2560960000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4050118673227	
Qty.	1 pc(s).	
Type	HDC 64D SBU 2M32G N	Version
Order No.	<a href="#">2550540000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4064675005087	
Qty.	1 pc(s).	
Type	HDC 24B SBU 2PG21G	Version
Order No.	<a href="#">1661520000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4008190418076	
Qty.	1 pc(s).	
Type	HDC 64D SBU 1M32G N	Version
Order No.	<a href="#">2561050000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4050118680195	
Qty.	1 pc(s).	
Type	HDC 24B SBU 1M25G	Version
Order No.	<a href="#">1901150000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248521258	
Qty.	1 pc(s).	
Type	HDC 64D SBU 2M25G N	Version
Order No.	<a href="#">2561060000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4050118680508	
Qty.	1 pc(s).	
Type	HDC 24B SBU 1PG21G	Version
Order No.	<a href="#">1661510000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4008190418069	
Qty.	1 pc(s).	
Type	HDC 64D SBU 2PG21G	Version
Order No.	<a href="#">1661590000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: PG 21
GTIN (EAN)	4008190418144	
Qty.	1 pc(s).	
Type	HDC 24B SBU 2M25G N	Version
Order No.	<a href="#">2560970000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4050118676730	
Qty.	1 pc(s).	