

HDC 48B TOLU 1M40G**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**IP65**

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Version	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, End-locking clamp, lower side, Standard, Size of cable entries: M 40
Order No.	1788340000
Type	HDC 48B TOLU 1M40G
GTIN (EAN)	4032248205875
Qty.	1 pc(s).

HDC 48B TOLU 1M40G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	151 mm	Depth (inches)	5.945 inch
Height	94 mm	Height (inches)	3.701 inch
Width	90 mm	Width (inches)	3.543 inch
Net weight	532 g		

Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

Dimensions

Cable entry	w. thread	Height of housing B	94 mm
Total length housing	132 mm	Width housing C	90 mm

General data

EMC housings	No	Housing main material	diecast aluminium
Material of locking element		Protection degree	IP65 (in plugged condition)
	Stainless steel, rust-proof		
Surface finish	Powder coating	Tightening torque	1.2 Nm

Version

BG	12	Cable entry	w. thread
Clamp version	End-locking clamp	Colour (RAL)	RAL 7035
Design		Design of housing	Cable entry from top, Plug housing
	Standard		
Design of locking system	End-locking clamp, lower side	Internal thread	M 40
Number of cable entry on top	1	Number of cable entry sideways	0
Size	12	Size of cable entries	M 40
Suitable for ModuPlug®	Yes	Tightening torque	1.2 Nm
Top part/bottom part/lid	upper part	Type	Plug

Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-02-02
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Substance	Acetone
Chemical resistance	Conditionally resistant
Substance	Drilling oil
Chemical resistance	Resistant
Substance	Diesel
Chemical resistance	Resistant
Substance	Ethyl alcohol
Chemical resistance	Resistant
Substance	Transmission oil

Creation date July 24, 2024 10:55:59 PM CEST

Catalogue status 13.07.2024 / We reserve the right to make technical changes.

HDC 48B TOLU 1M40G**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data**

Chemical resistance	Resistant
Substance	Hydraulic oil
Chemical resistance	Resistant
Substance	Coolant
Chemical resistance	Resistant
Substance	Petroleum benzine
Chemical resistance	Resistant
Substance	Sweat
Chemical resistance	Resistant
Substance	Premium gasoline
Chemical resistance	Conditionally resistant
Substance	Water
Chemical resistance	Resistant
Substance	UV
Chemical resistance	Unstable
Substance	Ozone
Chemical resistance	Unstable

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	d447edfa-0214-4f34-b5ba-82eae491b46a
Chemical resistance	de.myview.objectmodel.impl.BlockImpl@72ec706c de.myview.objectmodel.impl.BlockImpl@13a93024 de.myview.objectmodel.impl.BlockImpl@2b8333 de.myview.objectmodel.impl.BlockImpl@540ac98b de.myview.objectmodel.impl.BlockImpl@45f4ac76 de.myview.objectmodel.impl.BlockImpl@1f869cfc de.myview.objectmodel.impl.BlockImpl@43e8b624 de.myview.objectmodel.impl.BlockImpl@412c6943 de.myview.objectmodel.impl.BlockImpl@215bfa0c de.myview.objectmodel.impl.BlockImpl@a11e3a7 de.myview.objectmodel.impl.BlockImpl@c4e2d57 de.myview.objectmodel.impl.BlockImpl@2e8a3bec de.myview.objectmodel.impl.BlockImpl@50ff3fab
RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6bl

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E92202

HDC 48B TOLU 1M40G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Approval/Certificate/Document of Conformity

[Manufacturer's declaration](#)

Engineering Data

[CAD data – STEP](#)

Product Change Notification

[20220214 Technical change to HDC housings](#)

[20220214 Technische Änderung bei HDC-Gehäusen](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures

[FL FIELDWIRING EN](#)


[FL FIELDWIRING EN](#)

HDC 48B TOLU 1M40G

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

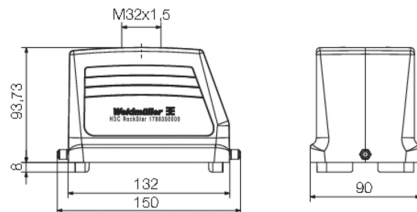

HDC 48B TOLU 1M40G

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Base housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 48B SDLU 2PG29G	Version
Order No.	1667560000	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: PG 29
GTIN (EAN)	4008190424763	
Qty.	1 pc(s).	
Type	HDC 48B SDLU 1M32G	Version
Order No.	1904150000	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: M 32
GTIN (EAN)	4032248585700	
Qty.	1 pc(s).	
Type	HDC 48B SDLU 2M40G	Version
Order No.	1983500000	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: M 40
GTIN (EAN)	4032248687787	
Qty.	1 pc(s).	
Type	HDC 48B SDLU 1PG29G	Version
Order No.	1799810000	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: PG 29
GTIN (EAN)	4032248247035	
Qty.	1 pc(s).	
Type	HDC 48B SDLU 2M32G	Version
Order No.	1788390000	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: M 32
GTIN (EAN)	4032248205929	
Qty.	1 pc(s).	
Type	HDC 48B SLU 2M32G	Version
Order No.	1788370000	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, Size of cable entries: M 32
GTIN (EAN)	4032248205905	
Qty.	1 pc(s).	
Type	HDC 48B SLU 1M32G	Version
Order No.	1904190000	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, Size of cable entries: M 32
GTIN (EAN)	4032248585779	
Qty.	1 pc(s).	
Type	HDC 48B SDLU 2M50G	Version
Order No.	1983510000	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: M 50
GTIN (EAN)	4032248687770	
Qty.	1 pc(s).	

HDC 48B TOLU 1M40G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	HDC 48B SLU 2M40G	Version
Order No.	1788360000	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, Size of cable entries: M 40
GTIN (EAN)	4032248205899	
Qty.	1 pc(s).	
Type	HDC 48B SLU 1PG29G	Version
Order No.	1651100000	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, Size of cable entries: PG 29
GTIN (EAN)	4008190299705	
Qty.	1 pc(s).	

Bulkhead housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 48B ALU	Version
Order No.	1295600000	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Bulkhead housing, End-locking clamp, lower side, Standard, without cover
GTIN (EAN)	4050118092066	
Qty.	1 pc(s).	
Type	HDC 48B ADLU	Version
Order No.	1222900000	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Bulkhead housing, End-locking clamp, lower side, Standard, with cover
GTIN (EAN)	4008190138004	
Qty.	1 pc(s).	