

SAI-Y-5S- M12/M12**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**General ordering data**

| | |
|------------|----------------------------|
| Version | Y connector, M12 / M12 |
| Order No. | 1826880000 |
| Type | SAI-Y-5S- M12/M12 |
| GTIN (EAN) | 4032248330393 |
| Qty. | 1 pc(s). |

SAI-Y-5S- M12/M12

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

| | |
|------------|--------|
| Net weight | 22.9 g |
|------------|--------|

Connection data

| | | | |
|-------------------------------------|------------|-------------------------------------|-------------------|
| Group outlet - plug-in connector | M12 pin | Single outlet 1 - plug-in connector | M12 socket |
| Single outlet 2 - plug-in connector | M12 socket | Tightening torque | M12: 0.8 - 1.2 Nm |

Technical data customisable plug-in connectors

| | | | |
|------------------------------|--------------|-----------------------|-----|
| Coding | A-coded | Housing main material | PBT |
| Number of poles | 5 | Pollution severity | 3 |
| Protection degree | IP67 | Rated current | 4 A |
| Rated voltage | 24 V | Shield connection | No |
| Temperature range of housing | -25...+90 °C | | |

Standards

| | |
|--------------------|-----------------|
| Connector standard | IEC 61076-2-101 |
|--------------------|-----------------|

General data

| | | | |
|------------------------------|--------------|-----------------------|-----|
| Coding | A-coded | Conductor O.D. | - |
| Connection thread | M12 / M12 | Housing main material | PBT |
| Number of poles | 5 | Pollution severity | 3 |
| Protection degree | IP67 | Rated current | 4 A |
| Rated voltage | 24 V | Shield connection | No |
| Temperature range of housing | -25...+90 °C | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC002925 | ETIM 7.0 | EC002925 |
| ETIM 8.0 | EC002925 | ETIM 9.0 | EC002925 |
| ECLASS 9.0 | 27-44-01-06 | ECLASS 9.1 | 27-44-01-06 |
| ECLASS 10.0 | 27-44-01-06 | ECLASS 11.0 | 27-44-01-06 |
| ECLASS 12.0 | 27-44-01-06 | ECLASS 13.0 | 27-44-01-06 |

Environmental Product Compliance

| | |
|------------|---|
| REACH SVHC | / |
|------------|---|

Approvals

Approvals



| | |
|------|---------|
| ROHS | Conform |
|------|---------|

SAI-Y-5S- M12/M12

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

| | |
|------------------|--|
| Engineering Data | CAD data – STEP |
| Catalogues | Catalogues in PDF-format |
| Brochures | FL FIELDWIRING EN FL FIELDWIRING EN |


SAI-Y-5S- M12/M12

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany


www.weidmueller.com

Drawings

Dimensioned drawing

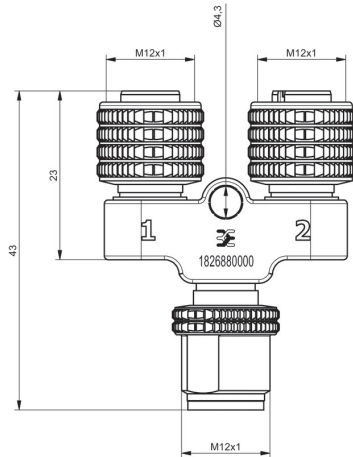

Dimensioned drawing

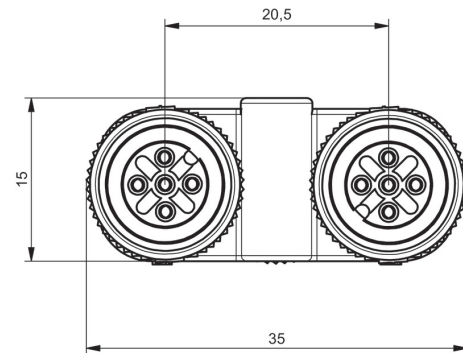

Wiring diagram

