

THM MT30X 25.9/7.1 WS**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

The THM labels offer brilliant printing quality thanks to the thermal transfer technology. Different materials and the user-friendly printing system under Windows optimise every marking effort.

- High-quality polyester labels in various colours or inexpensive paper labels are available
- Labels are automatically positioned in the printer for perfectly centred prints on each label.

General ordering data

Version	THM, Device markers, 7.1 x 25.9 mm, white
Order No.	1891770000
Type	THM MT30X 25.9/7.1 WS
GTIN (EAN)	4032248504510
Qty.	1 pc(s).
compatible printer	2599430000 2599440000

THM MT30X 25.9/7.1 WS

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	0.08 mm	Depth (inches)	0.003 inch
Height	7.1 mm	Height (inches)	0.28 inch
Width	25.9 mm	Width (inches)	1.02 inch
Net weight	184 g		

Temperatures

Operating temperature range	-40...150 °C
-----------------------------	--------------

General data

Adhesive	Acrylate adhesive	
Approval acc. to UL 969	Yes	
Colour	white	
Halogen	No	
Material	Polyester	
Material colour according to resistance code	9	
Number of markers per combination	1 Label reel = Device markers	
Number of markers per packaging unit	Form of supply	Label reel
Number per roll	5,000	
Operating temperature range	-40...150 °C	
Operating temperature range, max.	150 °C	
Operating temperature range, min.	-40 °C	
Printing method	Thermal transfer	
UL 94 flammability rating	V-0	
Version	Self-adhesive, halogen-free	
Width	25.9 mm	

Device markers

Halogen	No
---------	----

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04
ECLASS 14.0	27-28-11-04		

Environmental Product Compliance

REACH SVHC	/
RoHS Compliance Status	Compliant without exemption

Approvals

ROHS	Conform
------	---------

THM MT30X 25.9/7.1 WS

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Engineering Data

[CAD data – STEP](#)

Catalogues


[Catalogues in PDF-format](#)

THM MT30X 25.9/7.1 WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

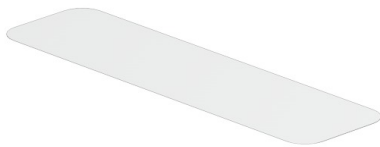

THM MT30X 25.9/7.1 WS**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM 110/360 SW	Version
Order No.	2005070000	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 pc(s).	