

IE-PH-V05M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

HDC plug-in connector according to IEC 61076-3-106
ver.5 in metal, empty housing

General ordering data

Version	Empty enclosure, Plug housing, Variant 5 to IEC 61076-3-106, IP67
Order No.	1962540000
Type	IE-PH-V05M
GTIN (EAN)	4032248644674
Qty.	10 pc(s).

IE-PH-V05M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	78 mm	Depth (inches)	3.071 inch
Height	26.7 mm	Height (inches)	1.051 inch
Width	26.7 mm	Width (inches)	1.051 inch
Net weight	77.5 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Colour	Miscellaneous	Housing main material	diecast aluminium
Plugging cycles	750	Protection degree	IP67

General standards

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-106 Var. 5
-------------------------	---------	--------------------	------------------------

Classifications

ETIM 6.0	EC001031	ETIM 7.0	EC001031
ETIM 8.0	EC001031	ETIM 9.0	EC001031
ECLASS 9.0	27-18-27-02	ECLASS 9.1	27-18-27-02
ECLASS 10.0	27-18-27-02	ECLASS 11.0	27-18-27-02
ECLASS 12.0	27-18-27-02	ECLASS 13.0	27-19-01-04
ECLASS 14.0	27-19-01-04		

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	4f3aae94-c2bc-4010-b63b-5b114ba6bd55
RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6bl, 6c

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E316369

IE-PH-V05M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Approval/Certificate/Document of Conformity	GOST Approval DUXR.E316369
Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN FL FIELDWIRING EN PI PROFINET CABLING EN


IE-PH-V05M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

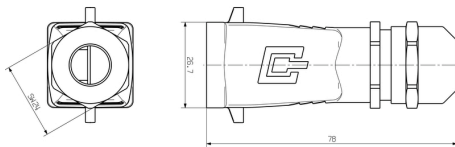

IE-PH-V05M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Dust caps**

For protecting your devices against dust and dirt.

General ordering data

Type	IE-PP-V05M	Version
Order No.	1968920000	Flange-mounted housing, protective cap
GTIN (EAN)	4032248692668	
Qty.	1 pc(s).	

Empty housingsHDC plug-in connector according to IEC 61076-3-106
ver.5 in metal, empty housing**General ordering data**

Type	IE-PH-AD-V05M-RJ45	Version
Order No.	1993540000	Spare insert holder, Variant 5 to IEC 61076-3-106
GTIN (EAN)	4050118378610	
Qty.	1 pc(s).	

IE-PH-V05M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****RJ45**

RJ45 inserts for plug-in connectors ver.1 / 4 / 5 / 14,
HDC and junction boxes IE-OM...; IE-OP...; IE-CC...

General ordering data

Type	IE-PI-RJ45-TH	Version
Order No.	1962720000	Plug insert RJ45 IDC, Plug insert RJ45, crimp
GTIN (EAN)	4032248644834	
Qty.	10 pc(s).	
Type	IE-PI-RJ45-FH	Version
Order No.	1962730000	Plug insert RJ45 IDC, Plug insert RJ45, no tools required, TIA-568A,
GTIN (EAN)	4032248654017	EIA/TIA T568 B, PROFINET
Qty.	10 pc(s).	